

Zinc 90° Cable Connectors

For Armored Cable and Flexible Metallic Conduit

Application:

Used with a locknut to terminate steel or aluminum flexible metal conduit and armored cable to enclosure to form a 90° bend

Features:

- Assembled with die cast locknut and tri-combo screws

Standard Materials:

Zinc Die Cast



UL Listed:

E155411


CSA File No. LR57925



Squeeze Type



Type C40Z

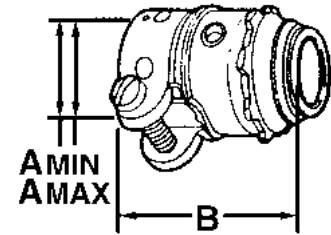


CATALOG NUMBER	TRADE SIZE	DIM. A MIN.	DIM. A MAX	DIM. B	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100	NAED MFG #78-5994 UPC/DCI #
C25Z	3/8"	0.440	0.750	0.180	50	500	7	32252
C35Z	1/2"	0.635	1.085	2.140	25	250	10	33516
C36Z	3/4"	0.830	1.380	2.380	10	100	13	33616
C37Z	1"	1.330	1.570	2.800	5	50	20	33716
C38Z	1-1/4"	1.625	1.940	3.930	10	40	29	33816
C39Z	1-1/2"	1.400	2.400	6.050	-	10	39	33916
C40Z	2"	1.400	2.400	6.050	-	5	46	34016

Squeeze Type – Insulated Throat



Type C40ZT

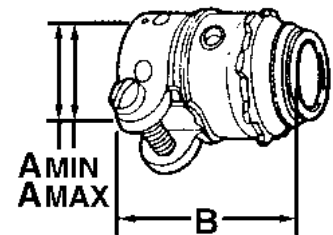

CATALOG NUMBER	TRADE SIZE	DIM. A MIN.	DIM. A MAX	DIM. B	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100	NAED MFG #78-5994 UPC/DCI #
C25ZT	3/8"	0.440	0.750	0.180	50	500	7	32567
C35ZT	1/2"	0.635	1.085	2.140	25	250	10	33567
C36ZT	3/4"	0.830	1.380	2.380	10	100	13	33667
C37ZT	1"	1.330	1.570	2.800	5	50	20	33767
C38ZT	1-1/4"	1.625	1.940	3.930	10	40	29	33867
C39ZT	1-1/2"	1.400	2.400	6.050	-	10	39	33967
C40ZT	2"	1.400	2.400	6.050	-	5	46	34067