


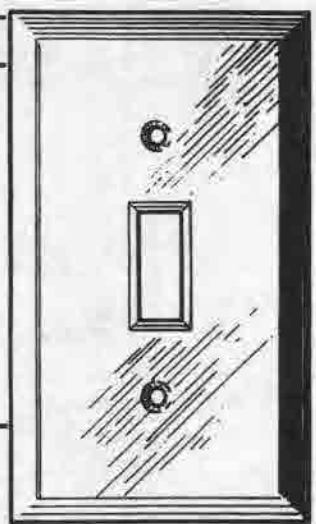











General Construction Finishes















 
 
 
 


For color photos of finishes see inside front cover.

STANDARD SHAPE

See page A84 for ordering Custom Plates not found in this listing.

	CHROME PLATED	WHITE SEMI-GLOSS	STAIN-LESS TYPE 302 (.035") Spec. Grade Satin Finish (302SS)	STAIN-LESS TYPE 430 (.030") Satin Finish (SS)	BROWN WRINKLE	IVORY WRINKLE
 1 Toggle Switch (1T)	Polished Steel (CA) 83071	Painted Steel (WA) 86071	83071	97071	Painted Steel (DB) 98071	Painted Steel (DI) 99071
 2 Toggle Switches (2T)	83072	86072	93072	97072	98072	99072
 3 Toggle Switches (3T)	83073	86073	93073	97073	98073	99073
 4 Toggle Switches (4T)	83074	86074	93074	97074	98074	99074
 5 Toggle Switches (5T)	83075	86075	93075	97075	98075	99075
 6 Toggle Switches (6T)	83076	86076	93076	97076	98076	99076
 7 Toggle Switches (7T)	83077	86077	93077	97077	98077	99077
 8 Toggle Switches (8T)	83078	86078	93078	97078	98078	99078
 9 Toggle Switches (9T)	83079	86079	93079	97079	98079	99079
 10 Toggle Switches (10T)	83080	86080	93080	97080	98080	99080
 1 Duplex Receptacle (10DR)	83101	86101	93101	97101	98101	99101
 2 Duplex Receptacles (20DR)	83102	86102	93102	97102	98102	99102








General Construction Finishes

	CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
 3 Duplex Receptacles (30DR)	83103	86103	93103	97103	98103	99103
 4 Duplex Receptacles (40DR)	83104	86104	93104	97104	98104	99104
 5 Duplex Receptacles (50DR)	83105	86105	93105	97105	98105	99105
 6 Duplex Receptacles (60DR)	83106	86106	93106	97106	98106	99106
 1 Single Recept. (1.405") (10R)	83091	86091	93091	97091	98091	99091
 2 Single Recept. (1.405") (20R)	83092	86092	93092	97092	98092	99092
 3 Single Recept. (1.405") (30R)	83093	86093	93093	97093	98093	99093
 1 Blank with Mounting Strap (Device Mntg. 2.375") (1BDE)	83121	86121	93121	97121	98121	99121
 2 Blanks with Mounting Straps (Device Mntg. 2.375") (2BDE)	83122	86122	93122	97122	98122	99122
 3 Blanks with Mounting Straps (Device Mntg. 2.375") (3BDE)	83123	86123	93123	97123	98123	99123
 1 Blank (Box Mntg. 3.281") (1B)	83151	86151	93151	97151	98151	99151
 2 Blanks (Box Mntg. 3.281") (2B)	83152	86152	93152	97152	98152	99152
 3 Blanks (Box Mntg. 3.281") (3B)	83153	86153	93153	97153	98153	99153
 4 Blanks (Box Mntg. 3.281") (4B)	83154	86154	93154	97154	98154	99154
 5 Blanks (Box Mntg. 3.281") (5B)	83155	86155	93155	97155	98155	99155
 6 Blanks (Box Mntg. 3.281") (6B)	83156	86156	93156	97156	98156	99156
 7 Blanks (Box Mntg. 3.281") (7B)	83157	86157	93157	97157	98157	99157
 8 Blanks (Box Mntg. 3.281") (8B)	83158	86158	93158	97158	98158	99158



















General Construction Finishes

		CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
	9 Blanks (Box Mntg. 3.281") (9B)	83159	86159	93159	97159	98159	99159
	10 Blanks (Box Mntg. 3.281") (10B)	83160	86160	93160	97160	98160	99160
	Block Duplex/GFI Recept. (SRM)	83401	86401	93401	97401	98401	99401
	2 Block Duplex/GFI Recepts. (2SRM)	83402	86402	93402	97402	98402	99402
	3 Block Duplex/GFI Recepts. (3SRM)	83403	86403	93403	97403	98403	99403
	4 Block Duplex/GFI Recepts. (4SRM)	83404	86404	93404	97404	98404	99404
	5 Block Duplex/GFI Recepts. (5SRM)	83405	86405	93405	97405	98405	99405
	6 Block Duplex/GFI Recepts. (6SRM)	83406	86406	93406	97406	98406	99406
	7 Block Duplex/GFI Recepts. (7SRM)	83407	86407	93407	97407	98407	99407
	8 Block Duplex/GFI Recepts. (8SRM)	83408	86408	93408	97408	98408	99408
	9 Block Duplex/GFI Recepts. (9SRM)	83409	86409	93409	97409	98409	99409
	10 Block Duplex/GFI Recepts. (10SRM)	83410	86410	93410	97410	98410	99410
	One 5/8" ID Phone (Box Mntg. 3.281") (01)*	83201	86201	93201	97201	98201	99201
	Two 5/8" ID Phones (Box Mntg. 3.281") (02)*	83202	86202	93202	97202	98202	99202
	One 5/8" ID Phone with Metal Bushing (Box Mntg. 3.281") (61)*	83591	86591	93591	97591	98591	99591
	One Phone .5" with .375 ID Grommet and Mounting Strap (Device Mntg. 2.375")*	83181	86181	93181	97181	98181	99181
	One Phone 1.405" with 1" ID Plastic Bushing (Box Mntg. 3.281") (71)*	83581	86581	93581	97581	98581	99581
















 
General Construction Finishes

	CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
 One 20A TL Recept. 1.620" ID Hole (3R)	83111	86111	93111	97111	98111	99111
 Two 20A TL Recepts. 1.620" ID Hole Must Use 3 Gang Plate (23R)	83113	86113	93113	97113	98113	99113
 One 30A 3 & 4 Wire TL Recept. 1.730" ID Hole (3330R)	83229	86229	93229	97229	98229	99229
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole (3D)	83221	86221	93221	97221	98221	99221
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole 2 Gang Plate (23D)	83222	86222	93222	97222	98222	99222
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole (N23D)	83227	86227	93227	97227	98227	99227
 30/50/60A 3 & 4 Wire Receptacles 2.480" ID Hole (5R)	83223	86223	93223	97223	98223	99223
 30/50/60A 4 Wire for Leviton 278 & 279 Recepts. 2.625" ID Hole (L5R)	83225	86225	93225	97225	98225	99225
 30/50/60A 4 Wire Offset Receptacles 2.275" ID Hole (N5RR)	83226	86226	93226	97226	98226	99226
 30/50/60A 4 Wire Receptacles 2.255" ID Hole (P5R)	83228	86228	93228	97228	98228	99228
 Louver, Horizontal (Device Mntg. 2.375") (LH)	83630	86630	93630	97630	98630	99630
 Louver, Vertical (Device Mntg. 2.375") (LV)	83631	86631	93631	97631	98631	99631
 2 Louvers (Device Mntg. 2.375") (2LV)	83632	86632	93632	97632	98632	99632
 Interchangeable 1 Hole Horizontal (71A)	83011X	86011X	93011X	97011X	98011X	99011X
 Interchangeable 1 Hole Per Gang, Horizontal (72A)	83012X	86012X	93012X	97012X	98012X	99012X
 Interchangeable 2 Holes (71B)	83021X	86021X	93021X	97021X	98021X	99021X
 Interchangeable 2 Holes Per Gang(72B)	83022X	86022X	93022X	97022X	98022X	99022X
 Interchangeable 2 Holes Per Gang(73B)	83023X	86023X	93023X	97023X	98023X	99023X

General Construction Finishes

	CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
 Interchangeable 3 Holes (71C)	83031X	86031X	93031X	97031X	98031X	99031X
 Interchangeable 3 Holes Per Gang (72C)	83032X	86032X	93032X	97032X	98032X	99032X
 Interchangeable 1 Hole Vertical (71G)	83041X	86041X	93041X	97041X	98041X	99041X
 Interchangeable 1 Hole Horizontal, 2 Holes (71A-71B)	83052X	86052X	93052X	97052X	98052X	99052X
 Toggle Switch, Duplex Recept. (1T-10DR)	83532	86532	93532	97532	98532	99532
 Toggle Switch, Interchangeable 2 Holes (1T-71B)	83062X	86062X	93062X	97062X	98062X	99062X
 Toggle Switch, Interchangeable 3 Holes (1T-71C)	83132X	86132X	93132X	97132X	98132X	99132X
 Toggle Switch, Single Recept. (1.405" ID Hole) (1T-10R)	83512	86512	93512	97512	98512	99512
 Toggle Switch, 1/2" ID Phone (Box Mntg. 3.281") (1T-01)	83472	86472	93472	97472	98472	99472
 Toggle Switch, Blank (Box Mntg. 3.281") (1T-1B)	83522	86522	93522	97522	98522	99522
 Toggle Switch, Block Duplex/GFI Recept. (1T-SRM)	83432	86432	93432	97432	98432	99432
 Duplex Recept., Blank (Box Mntg. 3.281") (10DR-1B)	83542	86542	93542	97542	98542	99542
 Duplex Recept., 1/2" ID Phone (Box Mntg. 3.281") (10DR-01)	83582	86582	93582	97582	98582	99582
 Duplex Recept., Single Recept. (1.405" ID Hole) (10DR-10R)	83572	86572	93572	97572	98572	99572
 Duplex Recept., Block Duplex/GFI Recept. (10DR-SRM)	83672	86672	93672	97672	98672	99672
 Duplex Recept., Interchangeable 2 Holes (10DR-71B)	83142X	86142X	93142X	97142X	98142X	99142X
 Duplex Recept., Interchangeable 3 Holes (10DR-71C)	83172X	86172X	93172X	97172X	98172X	99172X
 Duplex Recept., 20A TL Recept. (1.620" ID Hole) (10DR-3R)	83390	86390	93390	97390	98390	99390

General Construction Finishes

	CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
 Duplex Recept., 30A Range/Dryer Recept. (2.125" ID Hole) (10DR-3D)	83180	86180	93180	97180	98180	99180
 Single Recept. (1.405" ID Hole), Blank (Box Mntg. 3.281") (10R-1B)	83552	86552	93552	97552	98552	99552
 Block Duplex/GFI Recept., Blank (Box Mntg. 3.281") (SRM-1B)	83422	86422	93422	97422	98422	99422
 Toggle Switch, Centered 2 Gang Plate (1T-2G)	83772	86772	93772	97772	98772	99772
 Duplex Recept., Centered 2 Gang Plate (10DR-2G)	83773	86773	93773	97773	98773	99773
 Single Recept. (1.405" ID Hole), Centered 2 Gang Plate (10R-2G)	83774	86774	93774	97774	98774	99774
 3/4" ID Phone (Box Mntg. 3.281"), Centered 2 Gang Plate (01-2G)	83775	86775	93775	97775	98775	99775
 2 Toggle Switches, Duplex Receptacle (2T-10DR)	83543	86543	93543	97543	98543	99543
 2 Toggle Switches, Blank (Box Mntg. 3.281") (2T-1B)	83533	86533	93533	97533	98533	99533
 2 Toggle Switches, Block Duplex/GFI Recept. (2T-SRM)	83443	86443	93443	97443	98443	99443
 Toggle Switch, 2 Block Duplex/GFI Recepts. (1T-2SRM)	83453	86453	93453	97453	98453	99453
 Toggle Switch, 2 Blanks (Box Mntg. 3.281") (1T-2B)	83133	86133	93133	97133	98133	99133
 Toggle Switch, 2 Duplex Recepts. (1T-20DR)	83553	86553	93553	97553	98553	99553
 Toggle Switch, Block Duplex, Duplex Recept. (1T-SRM-10DR)	83503	86503	93503	97503	98503	99503
 Duplex Recept., 2 Blanks (Box Mntg. 3.281") (10DR-2B)	83423	86423	93423	97423	98423	99423
 Blank (Box Mntg. 3.281"), Duplex Recept., Blank (Box Mntg. 3.281") (1B-10DR-1B)	83193	86193	93193	97193	98193	99193

General Construction Finishes

	CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
Blank (Box Mntg. 3.281"), 2 Duplex Recept. (1B-20DR)	83163	86163	93163	97163	98163	99163
Single Recept. (1.405" ID Hole), 2 Duplex Recept. (10R-20DR)	83593	86593	93593	97593	98593	99593
Toggle Switch, Blank (Box Mntg. 3.281"), Duplex Recept. (1T-1B-10DR)	83233	86233	93233	97233	98233	99233
3 Toggle Switches, Duplex Recept. (3T-10DR)	83554	86554	93554	97554	98554	99554
3 Toggle Switches, Block Duplex/GFI Recept. (3T-SRM)	83454	86454	93454	97454	98454	99454
Toggle Switch, 3 Block Duplex/GFI Rec. (1T-3SRM)		86654		97654		99654
3 Toggle Switches, Blank (Box Mntg. 3.281") (3T-1B)	83544	86544	93544	97544	98544	99544
2 Toggle Switches, 2 Duplex Recept. (2T-20DR)	83564	86564	93564	97564	98564	99564
2 Toggle Switches, 2 Blanks (Box Mntg. 3.281") (2T-2B)	83574	86574	93574	97574	98574	99574
Toggle Switch, 3 Duplex Recept. (1T-30DR)	83584	86584	93584	97584	98584	99584
2 Duplex Recept., 2 Blanks (Box Mntg. 3.281") (20DR-2B)	83164	86164	93164	97164	98164	99164
4 Toggle Switches, Duplex Recept. (4T-10DR)	83565	86565	93565	97565	98565	99565
4 Toggle Switches, Block Duplex/GFI Recept. (4T-SRM)	83465	86465	93465	97465	98465	99465
4 Toggle Switches, Blank (Box Mntg. 3.281") (4T-1B)	83555	86555	93555	97555	98555	99555
3 Toggle Switches, 2 Duplex Recept. (3T-20DR)	83575	86575	93575	97575	98575	99575
5 Toggle Switches, Duplex Recept. (5T-10DR)	83576	86576	93576	97576	98576	99576
4 Toggle Switches, 2 Duplex Recept. (4T-20DR)	83196	86196	93196	97196	98196	99196