

VX2414 SERIES (1200 CFM)

VX2414 T Series

ABS Cyclac® Plastic Dome (grey, brown, black)
galvanized steel venturi construction

VX2414 AM Series

Galvanized Steel Dome (mill, brown, black, weathered grey)
galvanized steel venturi construction

VX2414 AA Series (pictured)

Duradome® .040 Spun Aluminum (mill, brown, black, weathered grey)
aluminum venturi construction



VX1000 SERIES (1080 CFM)

VX1000 Series (brown pictured)

ABS Cyclac® Plastic Dome (grey, brown, black)
galvanized steel venturi construction

VX1000 AM Series

Galvanized Steel Dome (mill, brown, black, weathered grey)
galvanized steel venturi construction



GABLE MOUNT POWER ATTIC VENTILATORS

- **Completely preassembled**
- **Easy installation—no holes in roof required**
- **Fits behind existing louvers or order with optional shutter**


3 MODELS WITH THESE FEATURES:

- Precision balanced fan blades
- Engineered motor mount for minimum vibration and extended motor life
- Adjustable thermostat

VX2500 (1650 CFM)

VX2516 (1600 CFM)

VX2515 (1300 CFM)

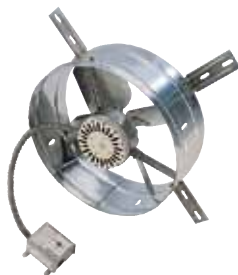

VX1818 (Optional Shutter)

Fully Automatic Shutter with high impact, one-piece ABS Cyclac® frame. Felt-padded, .020 gauge aluminum louvers for quiet operation. Preassembled.

Be sure to order shutter (below) unless installing behind existing louvers.

Model	CFM	Attic Size Sq Ft	Motor AMPS	Fan Size	Intake Sq Inches	Warranty
VX2500	1650	2500	2.1 PSC	14"	600	lifetime
VX2516	1600	2400	4.5	14"	600	2 yrs
VX2515	1300	1850	2.6	14"	600	2 yrs
VX1818	Automatic Shutter for all fans (22" w x 23" h x 3" d)					