



# 4300 Series Low Profile Fan Forced Wall Heater - With Wall Box

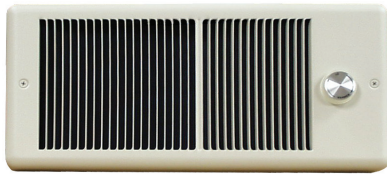

WITH IN-BUILT THERMOSTAT

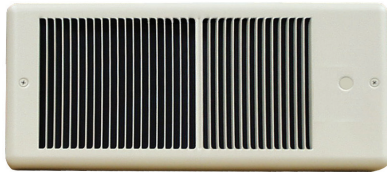

WITHOUT IN-BUILT THERMOSTAT

## Features

- Available in ivory or white.
- Powder coated 20 Gauge steel front.
- Manual reset thermal limit.
- Finned tubular steel element.
- Weight 9 lbs.
- Propeller style fan blade - 2200 RPM / 70 CFM
- Rough in dimensions: 14-1/2" Wide, 7-1/8" High, 3-1/2" Deep
- Grill dimensions: 16-3/4" Wide, 7-5/8" High
- Unit not approved for ceiling mount applications.
- Unit can be positioned to allow left, right or top discharge.



Manufactured in U.S.A.

## Standard Models

IVORY		WHITE		VOLTS	WATTS	MAX BTU's	AMPS	LIST
UPC 686334	MODEL	UPC 686334	MODEL					
<b>DOUBLE POLE IN-BUILT THERMOSTAT (RANGE 50° - 90°F)</b>								
327695	F4320T2RP	327749	F4320T2RPW	208	2000	6826	9.6	240
327701	HF4375T2RP	327756	HF4375T2RPW	240/208	750 / 562	2560 / 1920	3.1 / 2.7	
327718	HF4310T2RP	327763	HF4310T2RPW		1000 / 750	3413 / 2560	4.2 / 3.6	
327725	HF4315T2RP	327770	HF4315T2RPW		1500 / 1125	5120 / 3840	6.3 / 5.4	
327732	HF4320T2RP	327787	HF4320T2RPW		2000 / 1500	6826 / 5120	8.3 / 7.2	
<b>International Models - DOUBLE POLE IN-BUILT THERMOSTAT (RANGE 50° - 90°F)</b>								
----	----	396448	M4375T2RPi	220	630	2150	2.9	240
----	----	396455	M4310T2RPi		840	2869	3.8	
----	----	396462	M4315T2RPi		1260	4300	5.7	
----	----	396479	M4320T2RPi		1680	5733	7.6	
<b>Standard Models - SINGLE POLE INBUILT THERMOSTAT (RANGE 50° - 90°F)</b>								
327794	E4375TRP	327879	E4375TRPW	120	750	2560	6.25	225
327800	E4310TRP	327886	E4310TRPW		1000	3413	8.33	
327817	E4315TRP	327893	E4315TRPW		1500	5120	12.5	
327824	F4320TRP	327909	F4320TRPW	208	2000	6826	9.6	
327831	HF4375TRP	327916	HF4375TRPW	240/208	750 / 562	2560 / 1920	3.1 / 2.7	
327848	HF4310TRP	327923	HF4310TRPW		1000 / 750	3413 / 2560	4.2 / 3.6	
327855	HF4315TRP	327930	HF4315TRPW		1500 / 1125	5120 / 3840	6.3 / 5.4	
327862	HF4320TRP	327947	HF4320TRPW		2000 / 1500	6826 / 5120	8.3 / 7.2	
<b>NO IN-BUILT THERMOSTAT</b>								
327954	E4375RP	328036	E4375RPW	120	750	2560	6.25	204
327961	E4310RP	328043	E4310RPW		1000	3413	8.33	
327978	E4315RP	328050	E4315RPW		1500	5120	12.5	
327985	F4320RP	328067	F4320RPW	208	2000	6826	9.6	
327992	HF4375RP	328074	HF4375RPW	240/208	750 / 562	2560 / 1920	3.1 / 2.7	
328005	HF4310RP	328081	HF4310RPW		1000 / 750	3413 / 2560	4.2 / 3.6	
328012	HF4315RP	328098	HF4315RPW		1500 / 1125	5120 / 3840	6.3 / 5.4	
328029	HF4320RP	328104	HF4320RPW		2000 / 1500	6826 / 5120	8.3 / 7.2	

## Accessories

UPC 686334	IVORY MODEL	UPC 686334	WHITE MODEL	ACCESSORY OPTIONS	WT. LBS.	LIST
327657	4300EX8	328456	4300EX8W	1" SEMI RECESSING EXTENDER	2	43
327664	4300EX16	328463	4300EX16W	2" SEMI RECESSING EXTENDER	3	46
327671	4300EX32	328470	4300EX32W	4" SURFACE MOUNTING FRAME	4	49
327688	4300P	328487	4300PW	WALL PLATE ADAPTOR (OD 21.5" x 12.25")	1	31
FIELD INSTALLED THERMOSTATS		329774	43T	SINGLE POLE THERMOSTAT 50° - 90° F	1	46
		329781	43T2	DOUBLE POLE THERMOSTAT 50° - 90° F	1	52