

GROUND CLAMPS

FOR BARE WIRE

APPLICATION

Used to connect bare copper wire to water pipe, rebar, ground rod or copper water tubing for grounding

STANDARD MATERIALS



Bronze with Steel Screws



UL LISTED
E93683
CSA file No. LR57925



With Steel Screws

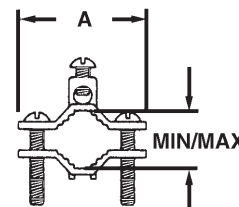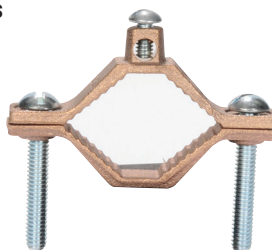

TYPE 34B

CATALOG NUMBER	TRADE SIZE	WIRE SIZE		DIM A	MIN.	MAX.	UNIT PACK	MASTER PACK	LBS. / 100 PCS.	UPC #
		MIN	MAX							
10B	1/2" - 1"	10 SOL.	2 STR.	2.430	0.500	1.380	25	250	19	41054
34B	1-1/4" - 2"	10 SOL.	2 STR.	2.275	0.675	1.850	-	50	40	43414
35A	2-1/2" - 4"	10 SOL.	2 STR.	6.350	2.700	5.900	-	10	135	43514
36A	4" - 6"	10 SOL.	2 STR.	8.000	4.000	7.900	-	5	160	43614

APPLICATION

Used to connect bare copper wire to water pipe, rebar, ground rod or copper water tubing for grounding

STANDARD MATERIALS



Bronze with Bronze Screws



UL LISTED
E93683
CSA file No. LR57925



With Bronze Screws for Direct Burial

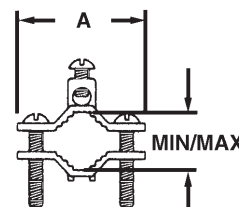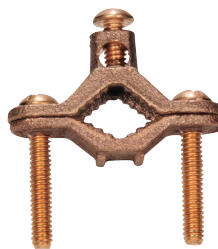

TYPE 10 BR

CATALOG NUMBER	TRADE SIZE	WIRE SIZE		DIM A	MIN.	MAX.	UNIT PACK	MASTER PACK	LBS. / 100 PCS.	UPC #
		MIN	MAX							
10BR	1/2" - 1"	10 SOL.	2 STR.	3.600	1.065	2.680	25	250	21	41084

APPLICATION

Used to connect bare copper wire to water pipe, ground rod or copper water tubing for grounding.

STANDARD MATERIALS


Zinc Die Cast with Steel Screws



UL LISTED
E93683
CSA file No. LR57925



Zinc Die Cast

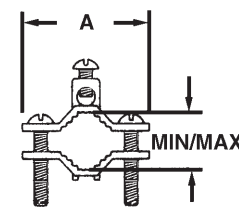

TYPE 10BG

CATALOG NUMBER	TRADE SIZE	WIRE SIZE		DIM A	MIN.	MAX.	UNIT PACK	MASTER PACK	LBS. / 100 PCS.	UPC #
		MIN	MAX							
10BG	1/2" - 1"	8 SOL.	2 STR.	2.220	0.545	1.575	25	250	17	41074
*10BB	1/2" - 1"	8 SOL.	2 STR.	2.400	0.625	2.000	25	250	17	41064

*Brass Colored Zinc Plated

GROUND CLAMPS

FOR ARMORED CABLE

APPLICATION

Used to connect armored cable to water pipe for grounding.

FEATURES

- Special pressure bar grips armored cable insulation to decrease chances of grounding conductor being pulled out

STANDARD MATERIALS


Solid Brass with Steel Screws



UL LISTED
E93683
CSA file No. LR57925



With Steel Screws

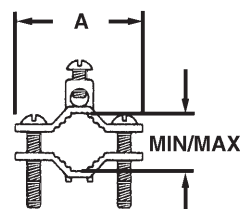

TYPE 35B

CATALOG NUMBER	TRADE SIZE	WIRE SIZE		DIM A	MIN.	MAX.	UNIT PACK	MASTER PACK	LBS. / 100 PCS.	UPC #
		MIN	MAX							
35B	2-1/2" - 4"	8 SOL.	4 STR.	6.350	2.700	5.900	-	10	150	43524

APPLICATION

Integral cast, lay-in lug style direct burial ground clamps are for making connection with #10AWG solid to #2 AWG stranded copper wire to 1/2" to 1" ground water pipe or 3/8" to 1" rebar. Clamps meet both UL and NEC requirements for burial in earth or embedment in concrete. Typical installations include swimming pool and service grounding.

FEATURES

- Combines FOUR clamps into ONE
- It eliminates, rebar clamp, clamp with steel screws, clamp with brass screws, and direct burial clamp
- Configure any job in 1/3 the time by presetting clamps with lay-in feature

STANDARD MATERIALS


Bronze Alloy with Stainless Steel Screws

Patent Pending



UL LISTED
E93683
Listed for Direct Burial
in Earth & Concrete

Patent Pending Direct Burial-Ground Clamp for Rebar

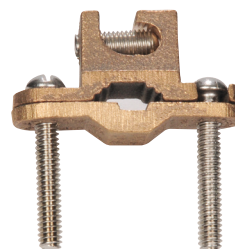

TYPE RBC-50

CATALOG NUMBER	PIPE RANGE	REBAR RANGE	GROUND ROD RANGE	WIRE RANGE	MECHANICAL CONNECTION/ SPLICE	UNIT PACK	MASTER PACK	LBS. / 100 PCS.	UPC #
RBC-50	1/2" - 1"	3/8" - 1"	1/4" - 1"	#10 SOL - #2 STR	TWO #8 SOL	25	250	21	66101