



Indoor/Outdoor

**52" Patio Fan  
Airpro**

**Ceiling Fans**



Type \_\_\_\_\_

-20 -30 -33 -80

P2502

**Finish**

Catalog No	Finish				Dimensions (Inches)			
	Antique Bronze	White	Cobblestone	Forged Black	A	B	C	D
P2502	-20	-30	-33	-80	52	17-3/8	12-3/16	4
<b>Blades</b>								
Side 1	Oak	White	Oak	Toasted Oak				
Side 2	Oak	White	Oak	Toasted Oak				

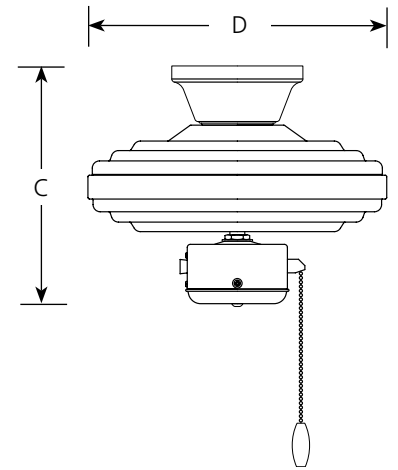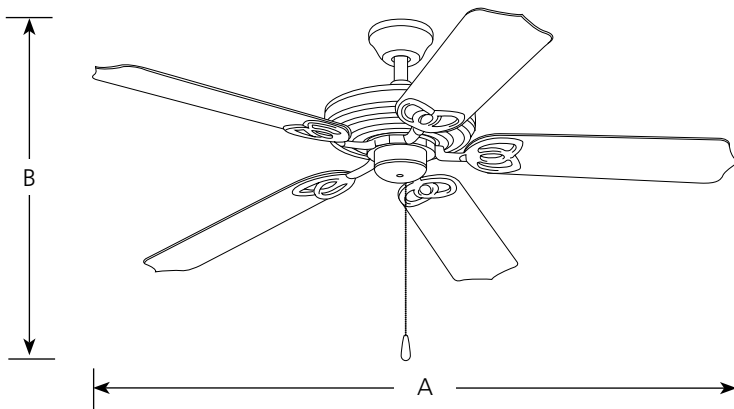

**Specifications:**

General

- 15 year limited warranty
- Steel construction
- Antique Bronze (-20) is either painted or acid finish
- White (-30) and Cobblestone (-33) are painted finishes
- Stainless steel hardware

Blades

- Five blades
- 12 degree pitch
- Sure Connect blade attachment system
  - Screws preinstalled in blades for attachment to motor arms
  - Special guides align blades to motor arms
  - Preinstalled rubber isolation pads minimize vibration noise
- ABS all-weather blade material

Motor

- Triple capacitor speed control; manual reverse control
- 153mm dia x 17.5mm high
- Pull chain on forged black (-80) is antique brass chain with medium oak fob

Mounting

- Dual ceiling mounting on downrod, or close to ceiling
- A 1-1/16" x 4-1/4" downrod is included. Longer accessory downrods can be ordered separately
- Quick-Install canopy installs without removing outlet box screws and securely holds fan for wiring during installation
- Canopy covers standard recessed 4" octagonal outlet box. Note: An outlet box assembly designed for fan installation is required (not included)
- Mounting hardware is included

Electrical

- 72" lead wires included
- Pre-wired

High Speed Energy Information

- Airflow—5,061 cfm
- Energy consumption—56 watts (excluding lights)
- Airflow efficiency—90 cfm/watt

Labeling

- UL/CUL wet location listed

Progress Lighting  
701 Millennium Blvd.  
Greenville, South Carolina  
29607

www.progresslighting.com

Rev. 3/11