


STRAIGHT BLADE RECEPTACLES

USB Chargers with Tamper-Resistant Receptacles 2 Pole, 3 Wire Grounding 15 & 20A, 125V & 120V

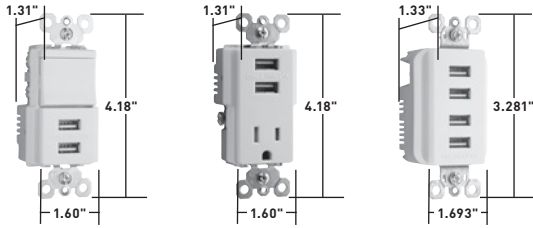

TM83USBW

TM8USBW

TM8USB4W

Features

- Charge multiple USB powered devices at the same time.
- Allow users to plug USB cables directly without AC adapters or transformer style plugs.
- Back and side wire terminals.
- Compatible with USB 2.0 and 3.0 devices.
- Accepts standard Pass & Seymour Decorator wall plates.
- Compact design.
- All AC outlets are tamper-resistant.
- Meets 2011 NEC standards.

CATALOG NUMBER	RATING		COLOR	TOTAL CHARGING CAPACITY	3rd PARTY COMPLIANCE	
	A.	V.			UL	ETL
USB CHARGER WITH TAMPER-RESISTANT RECEPTACLE						
TM8USBICC6	15	125	Ivory	2.1 Amp		•
TM8USBWCC6	15	125	White	2.1 Amp		•
TM8USBKCC6	15	125	Black	2.1 Amp		•
TM8USBLACC6	15	125	Light Almond	2.1 Amp		•
TM8USBNICC6	15	125	Nickel	2.1 Amp		•
TM8USBTICC6	15	125	Titanium	2.1 Amp		•
USB CHARGER WITH SINGLE POLE/3-WAY SWITCH						
TM83USBICC6	15	120	Ivory	2.1 Amp		•
TM83USBWCC6	15	120	White	2.1 Amp		•
TM83USBKCC6	15	120	Black	2.1 Amp		•
TM83USBLACC6	15	120	Light Almond	2.1 Amp		•
TM83USBNICC6	15	120	Nickel	2.1 Amp		•
TM83USBTICC6	15	120	Titanium	2.1 Amp		•
USB QUAD CHARGER						
TM8USB4ICC6			Ivory	4.2 Amp	•	
TM8USB4WCC6			White	4.2 Amp	•	
TM8USB4KCC6			Black	4.2 Amp	•	
TM8USB4LACC6			Light Almond	4.2 Amp	•	
TM8USB4NICC6			Nickel	4.2 Amp	•	
TM8USB4TICC6			Titanium	4.2 Amp	•	