

Watertight Conduit Hubs

For Threaded Rigid Conduit and IMC

Application:

To secure threaded rigid service entrance conduit to box or enclosure. Insulated throat rated 105° C. BUNA-N sealing ring completely encircles knockout to prevent contaminants from entering enclosure.

Features:

- Assembled with 105°C rated flame retardant Lexan throat insulator and BUNA-N sealing ring.
- UL Listed and CSA Certified for use in wet locations.
- Meets NEMA sealing requirements for Type 2, 3, 3R, 4, 4X, 5, 12, and 13 enclosures.
- Certified for use in hazardous locations, Class II, Groups E, F, G and Class III.

Standard Materials:

Zinc Die Cast



UL Listed:
E198258



CSA Certified: C5F17

Note:

Minimum wall thickness that can be accommodated is 1/2

Application:

General Purpose Fitting. Insulated Throat form with Bonding Screw.

Features:

- Male thread type
- Tapered female thread for rigid conduit and IMC
- Recessed O-ring seal assures watertight and dust tight connections.
- Insulated throat and bonding locknut is suitable for service entrance application.
- Suitable for use in hazardous locations as follows: Class I, Div. 2 Class II, Div. 1, 2 Class III, Div. 1, 2 Per NEC 501-4 (b), 502-4 (a), 503-3 (a)

Material/Finish:

Malleable Iron/Zinc Plated




UL Listed:
E198258

Zinc Die Cast



Type TWH20

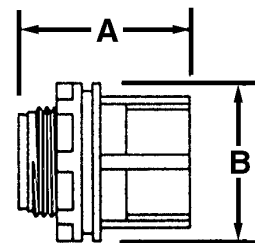


CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100 PCS.	NAED MFG #78-5994 UPC/DCI #
TWH10	1/2"	1.450	1.210	25	250	16	70010
TWH20	3/4"	1.570	1.430	25	250	22	70020
TWH30	1"	1.865	1.850	10	100	41	70030
TWH40	1-1/4"	1.985	2.280	5	25	55	70040
TWH50	1-1/2"	2.040	2.555	2	20	68	70050
TWH60	2"	2.150	3.060	2	20	95	70060
TWH70	2-1/2"	2.550	3.580	-	10	165	70070
TWH80	3"	2.625	4.190	-	5	216	70080
TWH90	3-1/2"	2.655	4.780	-	5	260	70090
TWH100	4"	2.680	5.355	-	5	338	70100

Malleable Iron



Type CHM50

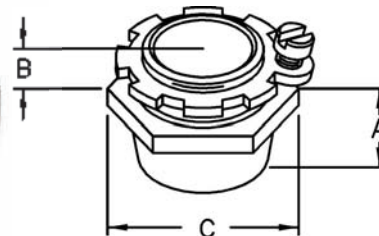

CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	DIM C	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100 PCS.	NAED MFG #78-5994 UPC/DCI #
CHM50	1/2"	0.813	0.625	1.500	25	250	18	70870
CHM75	3/4"	0.938	0.625	1.813	25	250	25	70871
CHM100	1"	1.063	0.750	2.063	10	100	39	70872
CHM125	1-1/4"	1.250	0.750	2.625	5	25	54	70873
CHM150	1-1/2"	1.250	0.813	3.125	2	20	64	70874
CHM200	2"	1.250	0.813	3.563	2	20	98	70875
CHM250	2-1/2"	1.625	1.188	4.125	-	10	196	70876
CHM300	3"	1.750	1.250	4.938	-	5	282	70877
CHM350	3-1/2"	1.813	1.313	5.750	-	5	351	70878
CHM400	4"	1.938	1.375	6.188	-	5	395	70879
CHM500	5"	2.063	1.438	7.625	-	1	717	70880
CHM600	6"	2.125	1.563	8.813	-	1	888	70881