

## Heavy Duty Covers

For weatherproof safety, this heavy duty die cast aluminum cover fits round boxes. Supplied with heavy foam rubber gasket and four #10-24 brass screws.

- Finish:
- White
  - Natural
  - Bronze



## Die Cast Round Covers

Die cast round covers with one or three 1/2" holes. Fit 4" round boxes. Supplied with thick foam rubber gasket and two #10-24 brass screws. 3 hole cover comes with one die cast 1/2" close-up plug.

- Finish:
- Bronze
  - Black
  - Silver Gray
  - White
  - Verde Green



## Polycarbonate Tuff Covers

Corrosionproof round four hole cover. Tough polycarbonate with molded-in color. Fourth hole is perfect for motion sensor mounting. Fits 4" round boxes. Rectangular cover with three 1/2" threaded holes. Fits FS, cast and recessed single outlet boxes. Supplied with thick foam rubber gasket. One molded 1/2" close-up plug and (2) brass screws.



- Finish:
- Black
  - White



## Die Cast Rectangular Covers

Die cast rectangular covers with one or three 1/2" threaded holes. Fits FS, cast and recessed single outlet boxes. Supplied with thick foam rubber gasket and two #6-32 brass screws. 3 hole cover comes with one die cast 1/2" close-up plug.

- Finish:
- Bronze
  - Black
  - Silver Gray
  - White
  - Verde Green



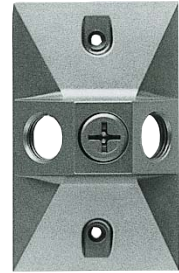
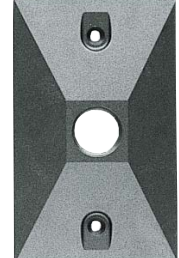


Diam.	Tap	Natural	Bronze	White
3"	blank	X3C		
4"	blank	XC		
4"	1/2"	XC1	XC1A	XC1W
4"	3/4"	XC2		

Finish	1 Hole	3 Hole
Bronze	C100A	C103A
Black	C100B	C103B
Silver Gray	C100	C103
White	C100W	C103W
Verde Green	C100VG	C103VG

Finish	Round 4 Hole	Rect. 3 Hole
Black	C4TB	R3TB
White	C4TW	R3TW

Finish	1 Hole	3 Hole
Bronze	R14-1A	R14-3A
Black	R14-1B	R14-3B
Silver Gray	R14-1	R14-3
White	R14-1W	R14-3W
Verde Green	R14-1VG	R14-3VG

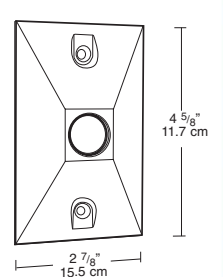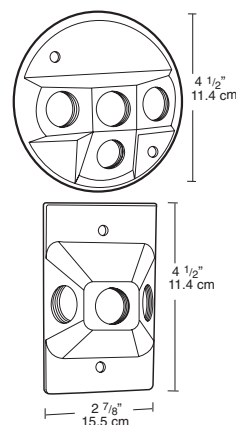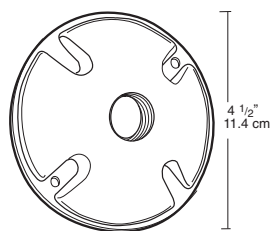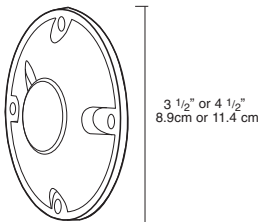

# WEATHERPROOF COVERS



Mount floodlights and sensors easily and securely on color matched heavy duty covers with threaded holes.

1/8" thick weatherseal gasket is closed cell silicone rubber for long lasting seal that won't crumple or break

Thick **RAB** Gasket  
Actual size

"others"

Strong, corrosionproof polycarbonate

Brass screws provided



Die cast aluminum covers are color matched to RAB lighting fixtures

Fourth hole is perfect for motion sensor mounting

Close-up plugs allow Phillips or slotted screwdrivers for easy installation



## New! Improved! EZ-Plate Universal Mounting Plate

Die cast sensor & floodlight mounting plate fits round, rectangular, octagonal, recessed & surface mount boxes. Lower hole offers better sensor mounting position. 3 close-up plugs, thick, weatherproof gaskets, universal mounting bar and Hanging Helper Hook provided.

- Finish:
- Bronze
  - Black
  - Silver Gray
  - White
  - Verde Green




Gaskets glued to plates for easy installation.



Larger wiring hole!

Installing Outdoor Lighting is EZ with the RAB EZ Plate!

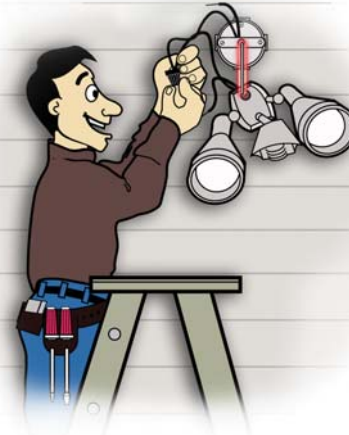

Fits All Boxes!



Recessed Round   Recessed Octagonal   Recessed Rectangular   Surface Round   Surface Rectangular

## Catalog Numbers

Finish	4 Hole
Bronze	CU4A
Black	CU4B
Silver Gray	CU4
White	CU4W
Verde Green	CU4VG



RAB's distinctive see-thru Weatherproof packaging has all the information you need and keeps parts organized

## Specifications

**UL Listing:**  
Suitable for wet locations

**Covers:**  
Precision die cast aluminum or molded polycarbonate plastic with 1/2" threaded holes.

**Screws:**  
10-24 Brass Round Head Phillips/slotted

**Gasket:**  
1/8" thick closed cell silicone rubber for long lasting seal won't crumple or break.

Thick **RAB** Gasket      "others"  
Actual size

**Replacement Plugs:**  
Available for round and rectangular covers and boxes:



	1/2"	3/4"	1"
Natural	R9	R10	R13*
Silver Gray	R9S	R10S	
Black	R9B	R10B	
Bronze	R9A	R10A	
White	R9W	R10W	
Verde Green	R9VG	R10VG	

\* only slotted

## Info Online 24/7

**Spec Sheets**  
[www.rabweb.com](http://www.rabweb.com) > click "PRODUCTS"

**Patents:**  
The designs of RAB products are protected under U.S. and international intellectual property laws.

## Dimensions

