


Model: 160

120V Track MR16 Luminaire

WAC LIGHTING

Responsible Lighting®

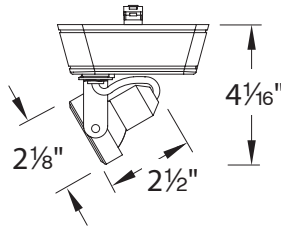

Fixture Type:

Catalog Number:

Project: _____

Location: _____

PRODUCT DESCRIPTION

Low Voltage luminaire with die-cast aluminum construction and swivel yoke for precise aiming.

FEATURES

- Available with LED lamp option
- Swivel yoke for easy aiming
- 350° horizontal rotation and 90° vertical tilt
- Mesh back vent for heat dissipation
- Clear lens included (Halogen version)
- Dimmable
- 5 year WAC Lighting product warranty

SPECIFICATIONS

Construction: Die-cast aluminum track head with polycarbonate transformer case and track adapter. Bi-pin ceramic socket for MR16 lamp.

Finish: Powder coat paint. Available in Black (BK) and White (WT).

Transformer: 12V; 1W minimum load.

Lamp: 160 model uses 12V MR16, 50W max lamp (not included).
 160L model uses 12V MR16, 75W max (not included).
 160LED model uses a 12V, 9W MR16 LED lamp (included).
 490 lumens, 3000K CCT, 50,000 hour rated life, CRI: 90.


Dimming: With electronic low voltage (ELV) dimmer, LED lamp dims to 15%; Halogen lamp dims to 1%.

Standards: UL & CUL Listed.

ORDER NUMBER

System	Model #	Power	Lamp	Finish
LHT L Track	160LED	9W	LED	BK Black
HHT H Track	160	50W	Halogen	WT White
JHT J/J2 Track	160L	75W	Halogen	

FINISHES

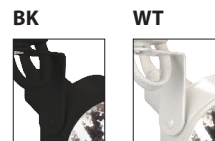

- -

Example: LHT-160LED-WT

ACCESSORIES

Color Lens	LENS-16-	AMB Amber	BLU Blue	GRN Green	RED Red	YEL Yellow	UV Filter	Frosted Lens	Spread Lens	Beam Elongating Lens	Honeycomb Louver
							LENS-16-UVF	LENS-16-FR	LENS-16-SPR	LENS-16-BEL	LENS-16-HCL

WAC Lighting
 www.waclighting.com
 Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center
 44 Harbor Park Drive • Port Washington, NY 11050
 Phone (516) 515.5000 • Fax (516) 515.5050

Western Distribution Center
 1750 Archibald Avenue • Ontario, CA 91760
 Phone (800) 526.2588 • Fax (800) 526.2585