


# SECURITY WALL PLATES

Featuring the Safety Ground-Tab  
1, 2 and 3 Gang Configurations  
UL Listed

# HUBBELL

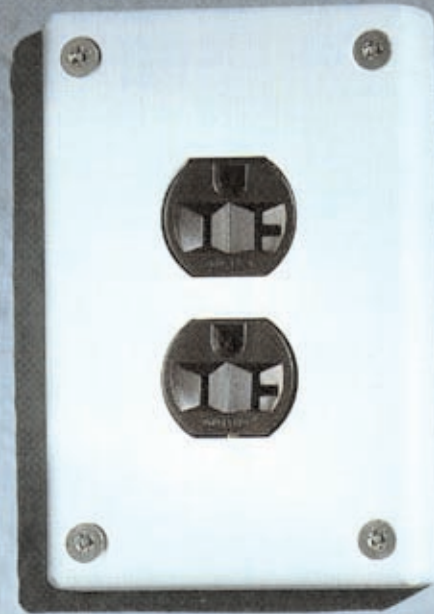

The SWP series of security wall plates are designed to be used where there is the potential for severe use or unauthorized access to the wiring device or box cavity behind the plate. Typical applications include correctional facilities, government and educational institutions, military facilities, unattended structures and hospitals.

These plates are UL Listed to UL 514A and allows installation compliance with NEC® 410-56(e) and CEC 26-700(11)(a) which require the receptacle face to protrude .015” beyond the surface of the cover. Hubbell also added a “Safety Ground-Tab” to insure the grounding integrity of the entire installation.

## Features


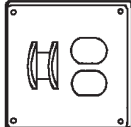

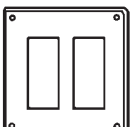
 
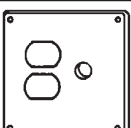
 
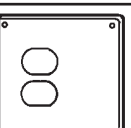

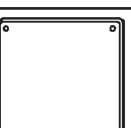
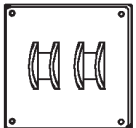
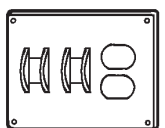
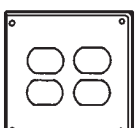
 
- 14 gauge one piece, cold rolled steel cover plate
- Polyester powder finish over zinc plated steel
- Safety Ground-Tab
- Stainless steel T20 TORX® screws with center pin reject

## Benefits

- Virtually indestructible cover.
- Thick finish provides durable, long lasting protection; zinc plating provides corrosion resistance.
- Provides integral bonding path to ground and compliance to NEC® and CEC.
- Stainless steel, tamper resistant cover plate screws virtually eliminate unauthorized access to junction boxes and conductors.




## Ordering Information- Security Wall Plates

Catalog Number	Description	Catalog Number	Description
SWP1	 Single Toggle Switch	SWP18	 2 Gang Switch/ Duplex Receptacle
SWP8	 Single Duplex Receptacle	SWP262	 2 Gang, Double GFCI/Style Line® Device
SWP26	 Single GFCI/ Style Line® Device	SWP812	 2 Gang, Duplex Receptacle, Telephone or TV
SWP12	 Single Telephone or TV Opening (.64")	SWP813	 2 Gang, Duplex Receptacle, Blank
SWP13	 Single Blank	SWP23	 2 Gang, Blank
SWP2	 2 Gang Double Toggle Switch	SWP28	 3 Gang, Switch, Switch, Duplex Receptacle
SWP82	 2 Gang Double Duplex Receptacle	SWPBIT	 T-20 TORX Bit with Center Pin Reject and Handle

### Dimensions

	A	B	C	D	E	F	G	H
1 Gang	3.77"	5.52"	.55"	3.37"	5.13"	1.00"	4.63"	2.88"
(mm)	(95.76)	(140.21)	(13.97)	(85.60)	(130.30)	(25.40)	(117.60)	(73.15)
2 Gang	5.52"	5.52"	.55"	5.13"	5.13"	1.00"	4.63"	4.63"
(mm)	(140.21)	(140.21)	(13.97)	(130.30)	(130.30)	(25.40)	(117.60)	(117.60)
3 Gang	7.39"	5.52"	.55"	7.00"	5.13"	1.00"	4.63"	6.50"
(mm)	(187.71)	(140.21)	(13.97)	(177.80)	(130.30)	(25.40)	(117.60)	(165.10)

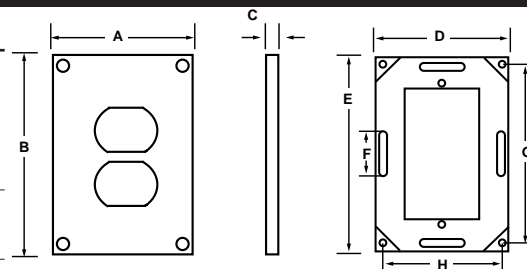

### Typical Specification - Hubbell SWP8

Tamper resistant wall plate single gang duplex receptacle shall be of the following construction:

**Cover plate:** One piece #14 cold rolled zinc plated steel with Safety Ground-Tab or equivalent redundant ground feature. Plate shall have a five stage baked white polyester powder enamel finish. Gloss: 85%, reflectance: 93%, hardness minimum: 2H and pass 600 hour salt spray test.

**Back plate:** #10 cold rolled galvanized steel. Plate assembly shall use four (4) #8-32 X 1/2" stainless steel T-20 TORX head screws with center pin reject. Plate must be UL listed to UL 514A or UL 514D and comply with NEC® 410-56(e).



### Wiring Device - Kellems

Hubbell Incorporated (Delaware) • 185 Plains Road • Milford, CT 06460-2420 • (203) 882-4800 • FAX (800) 255-1031  
World Wide Web URL: <http://www.hubbell-wiring.com>

#### Worldwide Locations

Hubbell Canada (905) 839-1138, Fax (905) 839-9108  
Hubbell Ltd. England (441) 234-855444, Fax (441) 234-854008  
Hubbell-Taian Co., Ltd., (886) 2 567-5995, Fax (886) 2 567-4853  
Hubbell Int'l. Inc., Korea Branch (82) 2 607-1362, Fax (82) 2 603-7386

Hubbell de Mexico, S.A. de C.V. (52) 5 575-2022, Fax (52) 5 559-8626  
Caribe Sales Agencies, Puerto Rico (809) 720-7185, Fax (809) 789-2796  
Hubbell S.E. Asia Pte., Ltd., (65) 382-1600, Fax (65) 382-3727  
Hubbell Inc. Middle East (971) 4 369-763, Fax (971) 4 360-541