


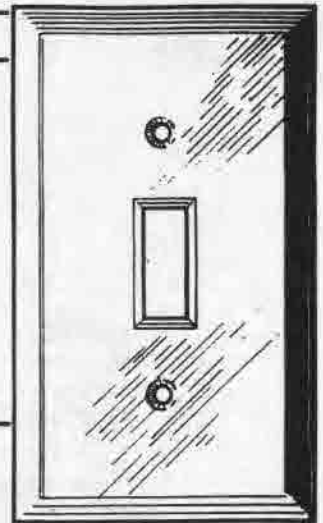











Architectural





















For color photos of finishes see inside front cover.

STANDARD SHAPE

See page A84 for ordering Custom Plates not found in this listing.

	ALUMINUM (.040") Satin Finish (SAL)	ALUMINUM (.050") Clear Anodized (5AA)	POLISHED BRASS (.040") High Polish U.S. #3 (4PB)	POLISHED STAINLESS (.035") High Polish U.S. #32 (302SP)	STAINLESS TYPE 302 (.060") Satin Finish U.S. #32D (3026SS)	SATIN BRASS (.040") Satin Finish U.S. #4 (4BB)	SATIN BRASS (.060") Satin Finish U.S. #4 (6BB)
 1 Toggle Switch (1T)	62071	95071	64071	68071	70071	94071	96071
 2 Toggle Switches (2T)	62072	95072	64072	68072	70072	94072	96072
 3 Toggle Switches (3T)	62073	95073	64073	68073	70073	94073	96073
 4 Toggle Switches (4T)	62074	95074	64074	68074	70074	94074	96074
 5 Toggle Switches (5T)	62075	95075	64075	68075	70075	94075	96075
 6 Toggle Switches (6T)	62076	95076	64076	68076	70076	94076	96076
 7 Toggle Switches (7T)	62077	95077	64077	68077		94077	
 8 Toggle Switches (8T)	62078	95078	64078	68078		94078	
 9 Toggle Switches (9T)	62079	95079	64079	68079		94079	
 10 Toggle Switches (10T)	62080	95080	64080	68080		94080	
 1 Duplex Receptacle (10DR)	62101	95101	64101	68101	70101	94101	96101
 2 Duplex Receptacles (20DR)	62102	95102	64102	68102	70102	94102	96102



















Architectural • Standard

	SATIN ALUMINUM	CLEAR ALUMINUM	POLISHED BRASS	POLISHED STAINLESS	STAINLESS TYPE 302 (.060")	SATIN BRASS (.040")	SATIN BRASS (.060")
 3 Duplex Receptacles (30DR)	62103	95103	64103	68103	70103	94103	96103
 4 Duplex Receptacles (40DR)	62104	95104	64104	68104	70104	94104	96104
 5 Duplex Receptacles (50DR)	62105	95105	64105	68105	70105	94105	96105
 6 Duplex Receptacles (60DR)	62106	95106	64106	68106	70106	94106	96106
 1 Single Recept. (1.405") (10R)	62091	95091	64091	68091	70091	94091	96091
 2 Single Recept. (1.405") (20R)	62092	95092	64092	68092	70092	94092	96092
 3 Single Recept. (1.405") (30R)	62093	95093	64093	68093	70093	94093	96093
 1 Blank with Mounting Strap (Device Mntg. 2.375") (1BDE)	62121	95121	64121	68121	70121	94121	96121
 2 Blanks with Mounting Straps (Device Mntg. 2.375") (2BDE)	62122	95122	64122	68122	70122	94122	96122
 3 Blanks with Mounting Straps (Device Mntg. 2.375") (3BDE)	62123	95123	64123	68123	70123	94123	96123
 1 Blank (Box Mntg. 3.281") (1B)	62151	95151	64151	68151	70151	94151	96151
 2 Blanks (Box Mntg. 3.281") (2B)	62152	95152	64152	68152	70152	94152	96152
 3 Blanks (Box Mntg. 3.281") (3B)	62153	95153	64153	68153	70153	94153	96153
 4 Blanks (Box Mntg. 3.281") (4B)	62154	95154	64154	68154	70154	94154	96154
 5 Blanks (Box Mntg. 3.281") (5B)	62155	95155	64155	68155	70155	94155	96155
 6 Blanks (Box Mntg. 3.281") (6B)	62156	95156	64156	68156	70156	94156	96156
 7 Blanks (Box Mntg. 3.281") (7B)	62157	95157	64157	68157	N/A	94157	N/A
 8 Blanks (Box Mntg. 3.281") (8B)	62158	95158	64158	68158	N/A	94158	N/A



















Architectural • Standard

	SATIN ALUMINUM	CLEAR ALUMINUM	POLISHED BRASS	POLISHED STAINLESS	STAINLESS TYPE 302 (.060")	SATIN BRASS (.040")	SATIN BRASS (.060")
9 Blanks (Box Mntg. 3.281") (9B)	62159	95159	64159	68159	N/A	94159	N/A
10 Blanks (Box Mntg. 3.281") (10B)	62160	95160	64160	68160	N/A	94160	N/A
Block Duplex/GFI Recept. (SRM)	62401	95401	64401	68401	70401	94401	96401
2 Block Duplex/GFI Recepts. (2SRM)	62402	95402	64402	68402	70402	94402	96402
3 Block Duplex/GFI Recepts. (3SRM)	62403	95403	64403	68403	70403	94403	96403
4 Block Duplex/GFI Recepts. (4SRM)	62404	95404	64404	68404	70404	94404	96404
5 Block Duplex/GFI Recepts. (5SRM)	62405	95405	64405	68405	70405	94405	96405
6 Block Duplex/GFI Recepts. (6SRM)	62406	95406	64406	68406	70406	94406	96406
7 Block Duplex/GFI Recepts. (7SRM)	62407	95407	64407	68407	N/A	94407	N/A
8 Block Duplex/GFI Recepts. (8SRM)	62408	95408	64408	68408	N/A	94408	N/A
9 Block Duplex/GFI Recepts. (9SRM)	62409	95409	64409	68409	N/A	94409	N/A
10 Block Duplex/GFI Recepts. (10SRM)	62410	95410	64410	68410	N/A	94410	N/A
One 5/8" ID Phone (Box Mntg. 3.281") (01)*	62201	95201	64201	68201	70201	94201	96201
Two 5/8" ID Phones (Box Mntg. 3.281") (02)*	62202	95202	64202	68202	70202	94202	966202
One 5/8" ID Phone with Metal Bushing (Box Mntg. 3.281") (61)*	62591	95591	64591	68591	70591	94591	96591
One Phone .5" with .375 ID Grommet and Mounting Strap (Device Mntg. 2.375")*	62181	95181	64181	68181	70181	94181	96181
One Phone 1.405" with 1" ID Plastic Bushing (Box Mntg. 3.281") (71)*	62581	95581	64581	68581	70581	94581	96581
















 
Architectural • Standard

	SATIN ALUMINUM	CLEAR ALUMINUM	POLISHED BRASS	POLISHED STAINLESS	STAINLESS TYPE 302 (.060")	SATIN BRASS (.040")	SATIN BRASS (.060")
 One 20A TL Recept. 1.620" ID Hole (3R)	62111	95111	64111	68111	70111	94111	96111
 Two 20A TL Recepts. 1.620" ID Hole, Must Use 3 Gang Plate (23R)	62113	95113	64113	68113	70113	94113	96113
 One 30A 3 & 4 Wire TL Recept. 1.730" ID Hole (3330R)	62229	95229	64229	68229	70229	94229	96229
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole (3D)	62221	95221	64221	68221	70221	94221	96221
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole 2 Gang Plate (23D)	62222	95222	64222	68222	70222	94222	96222
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole (N23D)	62227	95227	64227	68227	70227	94227	96227
 30/50/60A 3 & 4 Wire Receptacles 2.480" ID Hole (5R)	62223	95223	64223	68223	70223	94223	96223
 30/50/60A 4 Wire for Leviton 278 & 279 Recepts. 2.625" ID Hole (L5R)	62225	95225	64225	68225	70225	94225	96225
 30/50/60A 4 Wire Offset Receptacle 2.275" ID Hole (N5RR)	62226	95226	64226	68226	70226	94226	96226
 30/50/60A 4 Wire Receptacle 2.255" ID Hole (P5R)	62228	95228	64228	68228	70228	94228	96228
 Louver, Horizontal (Device Mntg. 2.375") (LH)	62630	95630	64630	68630	N/A	94630	N/A
 Louver, Vertical (Device Mntg. 2.375") (LV)	62631	95631	64631	68631	N/A	94631	N/A
 2 Louvers (Device Mntg. 2.375") (2LV)	62632	95632	64632	68632	N/A	94632	N/A
 Interchangeable 1 Hole Horizontal (71A)	62011X	95011X	64011X	68011X	70011X	94011X	96011X
 Interchangeable 1 Hole Per Gang, Horizontal (72A)	62012X	95012X	64012X	68012X	70012X	94012X	96012X
 Interchangeable 2 Holes (71A)	62021X	95021X	64021X	68021X	70021X	94021X	96021X
 Interchangeable 2 Holes Per Gang (72B)	62022X	95022X	64022X	68022X	70022X	94022X	96022X
 Interchangeable 2 Holes Per Gang (73B)	62023X	95023X	64023X	68023X	70023X	94023X	96023X















Architectural • Standard

	SATIN ALUMINUM	CLEAR ALUMINUM	POLISHED BRASS	POLISHED STAINLESS	STAINLESS TYPE 302 (.060")	SATIN BRASS (.040")	SATIN BRASS (.060")
 Interchangeable 3 Holes (71C)	62031X	95031X	64031X	68031X	70031X	94031X	96031X
 Interchangeable 3 Holes Per Gang (72C)	62032X	95032X	64032X	68032X	70032X	94032X	96032X
 Interchangeable 1 Hole Vertical (71G)	62041X	95041X	64041X	68041X	70041X	94041X	96041X
 Interchangeable 1 Hole Horizontal, 2 Holes (71A-71B)	62052X	95052X	64052X	68052X	70052X	94052X	96052X
 Toggle Switch, Duplex Recept. (1T-10DR)	62532	95532	64532	68532	70532	94532	96532
 Toggle Switch Interchangeable 2 Holes (1T-71B)	62062X	95062X	64062X	68062X	70062X	94062X	96062X
 Toggle Switch Interchangeable 3 Holes (1T-71C)	62132X	95132X	64132X	68132X	70132X	94132X	96132X
 Toggle Switch, Single Recept. (1.405" ID Hole (1T-10R)	62512	95512	64512	68512	70512	94512	96512
 Toggle Switch, 3/8" ID Phone (Box Mntg. 3.281" (1T-01)	62472	95472	64472	68472	70472	94472	96472
 Toggle Switch, Blank (Box Mntg. 3.281" (1T-1B)	62522	95522	64522	68522	70522	94522	96522
 Toggle Switch, Block Duplex/GFI Recept. (1T-SRM)	62432	95432	64432	68432	70432	94432	96432
 Duplex Recept., Blank (Box Mntg. 3.281" (10DR-1B)	62542	95542	64542	68542	70542	94542	96542
 Duplex Recept., 3/8" ID Phone (Box Mntg. 3.281" (10DR-01)	62582	95582	64582	68582	70582	94582	96582
 Duplex Recept., Single Recept. (1.405" ID Hole (10DR-10R)	62572	95572	64572	68572	70572	94572	96572
 Duplex Recept., Block Duplex/GFI Recept. (10DR-SRM)	62672	95672	64672	68672	70672	94672	96672
 Duplex Recept., Interchangeable 2 Holes (10DR-71B)	62142X	95142X	64142X	68142X	70142X	94142X	96142X
 Duplex Recept., Interchangeable 3 Holes (10DR-71C)	62172X	95172X	64172X	68172X	70172X	94172X	96172X
 Duplex Recept., 20A TL Recept. (1.620" ID Hole (10DR-3R)	62390	95390	64390	68390	70390	94390	96390

Architectural • Standard

	SATIN ALUMINUM	CLEAR ALUMINUM	POLISHED BRASS	POLISHED STAINLESS	STAINLESS TYPE 302 (.060")	SATIN BRASS (.040")	SATIN BRASS (.060")
 Duplex Recept., 30A Range/Dryer Recept. (2.125" ID Hole) (10DR-3D)	62180	95180	64180	68180	70180	94180	96180
 Single Recept. (1.405" ID Hole) Blank (Box Mntg. 3.281") (10R-1B)	62552	95552	64552	68552	70552	94552	96552
 Block Duplex/GFI Recept. Blank (Box Mntg. 3.281") (SRM-1B)	62422	95422	64422	68422	70422	94422	96422
 Toggle Switch, Centered 2 Gang Plate (1T-2G)	62772	95772	64772	68772	70772	94772	96772
 Duplex Recept., Centered 2 Gang Plate (10DR-2G)	62773	95773	64773	68773	70773	94773	96773
 Single Recept. (1.405" ID Hole), Centered 2 Gang Plate (10R-2G)	62774	95774	64774	68774	70774	94774	96774
 1/2" ID Phone (Box Mntg. 3.281"), Centered 2 Gang Plate (01-2G)	62775	95775	64775	68775	70775	94775	96775
 2 Toggle Switches, Duplex Receptacle (2T-10DR)	62543	95543	64543	68543	70543	94543	96543
 2 Toggle Switches, Blank (Box Mntg. 3.281") (2T-1B)	62533	95533	64533	68533	70533	94533	96533
 2 Toggle Switches, Block Duplex/GFI Recept. (2T-SRM)	62443	95443	64443	68443	70443	94443	96443
 Toggle Switch, 2 Block Duplex/GFI Recepts. (1T-2SRM)	62453	95453	64453	68453	70453	94453	96453
 Toggle Switch, 2 Blanks (Box Mntg. 3.281") (1T-2B)	62133	95133	64133	68133	70133	94133	96133
 Toggle Switch, 2 Duplex Recepts. (1T-20DR)	62553	95553	64553	68553	70553	94553	96553
 Toggle Switch, Block Duplex, Duplex Recept. (1T-SRM-10DR)	62503	95503	64503	68503	70503	94503	96503
 Duplex Recept., 2 Blanks (Box Mntg. 3.281") (10DR-2B)	62423	95423	64423	68423	70423	94423	96423
 Blank (Box Mntg. 3.281"), Duplex Recept., Blank (Box Mntg. 3.281") (1B-10DR-1B)	62193	95193	64193	68193	70193	94193	96193

Architectural • Standard

	SATIN ALUMINUM	CLEAR ALUMINUM	POLISHED BRASS	POLISHED STAINLESS	STAINLESS TYPE 302 (.060")	SATIN BRASS (.040")	SATIN BRASS (.060")
 Blank (Box Mntg. 3.281"), 2 Duplex Recept. (1B-20DR)	62163	95163	64163	68163	70163	94163	96163
 Single Recept. (1.405" ID Hole), 2 Duplex Recept. (10R-20DR)	62593	95593	64593	68593	70593	94593	96593
 Toggle Switch, Blank (Box Mntg. 3.281"), Duplex Recept. (1T-1B-10DR)	62233	95233	64233	68233	70233	94233	96233
 3 Toggle Switches, Duplex Recept. (3T-10DR)	62554	95554	64554	68554	70554	94554	96554
 3 Toggle Switches, Block Duplex/GFI Recept. (3T-SRM)	62454	95454	64454	68454	70454	94454	96454
 3 Toggle Switches, Blank (Box Mntg. 3.281") (3T-1B)	62544	95544	64544	68544	70544	94544	96544
 2 Toggle Switches, 2 Duplex Recept. (2T-20DR)	62564	95564	64564	68564	70564	94564	96564
 2 Toggle Switches, 2 Blanks (Box Mntg. 3.281") (2T-2B)	62574	95574	64574	68574	70574	94574	96574
 Toggle Switch, 3 Duplex Recept. (1T-30DR)	62584	95584	64584	68584	70584	94584	96584
 2 Duplex Recept., 2 Blanks (Box Mntg. 3.281") (20DR-2B)	62164	95164	64164	68164	70164	94164	96164
 4 Toggle Switches, Duplex Recept. (4T-10DR)	62565	95565	64565	68565	70565	94565	96565
 4 Toggle Switches, Block Duplex/GFI Recept. (4T-SRM)	62465	95465	64465	68465	70465	94465	96465
 3 Toggle Switches, 2 Duplex Recept. (3T-20DR)	62575	95575	64575	68575	70575	94575	96575
 5 Toggle Switches, Duplex Recept. (5T-10DR)	62576	95576	64576	68576	70576	94576	96576