



End Bells

Size (in.)	Part Number	Product Code	OD (in.)	OL (in.)
1/2	MEB05	078288	1.250	1.000
3/4	MEB07	078289	1.500	1.000
1	MEB10	078290	1.745	1.120
1-1/4	MEB12	078291	2.085	1.200
1-1/2	MEB15	078292	2.950	1.500
2	MEB20	078293	3.050	1.440
2-1/2	MEB25	078294	3.585	1.790
3	MEB30	078295	3.865	1.910
3-1/2	MEB35	078296	4.437	2.093
4	MEB40	078297	4.870	2.175
5	MEB50	078298	6.187	2.375
6	MEB60	078299	7.187	2.562
8	MEB80	077652	-	-

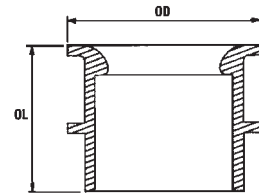

End Caps

Size (in.)	Part Number	Product Code	A (in.)	B (in.)
1/2	EC05	078314	1.410	1.000
3/4	EC07	078315	1.630	1.125
1	EC10	078316	1.860	1.187
1-1/4	EC12	078317	2.005	1.275
1-1/2	EC15	078318	2.115	1.500
2	EC20	078319	2.445	1.812
2-1/2	EC25	078320	2.915	2.125
3	EC30	078321	3.050	2.375
3-1/2	EC35	078322	2.150	2.625
4	EC40	078323	3.260	3.050
5	EC50	078324	4.375	3.000
6	EC60	078325	5.180	4.125
8	EC80	178191	-	-

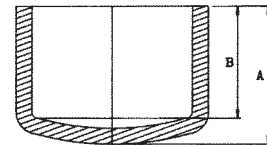

CONDUIT FITTINGS

Fabricated Swedge Reducer Couplings Sp x Sp



Size (in.)	Part Number	Product Code
2 x 1-1/4	SW2012	078398
2 x 1-1/2	SW2015	078399
2-1/2 x 2	SW2520	078400
3 x 2	SW3020	078401
3 x 2-1/2	SW3025	078402
3-1/2 x 3	SW3530	078404
4 x 3	SW4030	078407
4 x 3-1/2	SW4035	078408
5 x 4	SW5040	078409
6 x 5	SW6050	078410


Other sizes available on request. Contact Kraloy customer service.

Tapered Conduit Plugs



Size (in.)	Part Number	Product Code
2 - 2-1/2	UTP20	078424
3 - 3-1/2	UTP30	078425
4	UTP40	078427
5	UTP50	078428
6	UTP60	078429
8	UTP80	077648

Expansion Joints

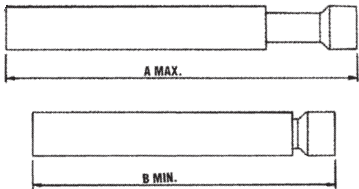

Size (in.)	Part Number	Product Code	A Max (in.)	B Min (in.)
1/2	EJ05	078328	12.00	8.00
3/4	EJ07	078329	12.00	8.00
1	EJ10	078330	12.50	8.50
1-1/4	EJ12	078331	13.00	9.00
1-1/2	EJ15	078332	13.00	9.00
2	EJ20	078333	13.25	9.25
2-1/2	EJ25	078334	22.25	14.25
3	EJ30	078336	22.25	14.25
3-1/2	EJ35	078337	22.90	14.90
4	EJ40	078338	22.90	14.90
5	*EJ50	078339	34.00	26.00
6	*EJ60	078340	34.00	26.00

* indicates Fabricated fittings

Slip Meter Risers (NEC Article 300)

Size (in.)	Part Number	Product Code
2' slip sleeve / 2" TA	SMR20TA	068371
2' slip sleeve / 2-1/2" TA	SMR25TA	068372
2' slip sleeve / 3" TA	SMR30TA	068373
2' slip sleeve / 4" TA	SMR40TA	068374



Expansion Joint c/w Terminal Adapter

Size (in.)	Part Number	Product Code
2" x 4" of travel	EJ35TA	077680
2-1/2" x 12" of travel	EJ40TA	077398
3" x 8" of travel	EJ45TA	077681
4" x 8" of travel	EJ55TA	077682



One Piece Expansion Joints

Size (in.)	Part Number	Product Code
1/2	OPEJ05	078240
3/4	OPEJ07	078209
1	OPEJ10	078208
1-1/4	OPEJ12	078204
1-1/2	OPEJ15	078045
2	OPEJ20	078388



Expansion and Deflection Fittings Assemblies

Size (in.)	Part Number	Product Code
2	SE-J-35	077889
3	SE-J-45	077890
4	SE-J-55	077891



CONDUIT FITTINGS

Pipe Straps, PVC 2 Hole





Size (in.)	Part Number	Product Code
1/2	PS05	078375
3/4	PS07	078376
1	PS10	078377
1-1/4	PS12	078378
1-1/2	PS15	078379
2	PS20	078380
2-1/2	PS25	178108
3	PS30	178109
4	PS40	178110

Pipe Straps, PVC Coated Steel 2 Hole



Size (in.)	Part Number	Product Code
2	PSC20	078190
2-1/2	PSC25	078191
3	PSC30	078192
3-1/2	PSC35	078193
4	PSC40	078194
5	PSC50	078195
6	PSC60	078196

Conduit Clamps & Spacers

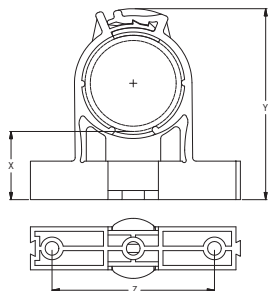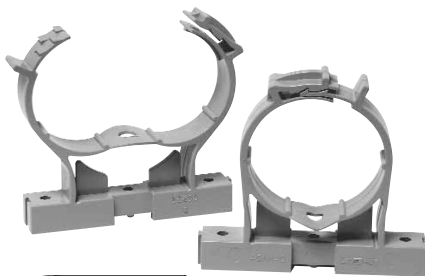


Size (in.)	Part Number	Product Code	X (in.)	Y (in.)	Z (in.)
1/2	CCS10	278106	1.191	2.414	1.824
3/4	CCS15	278095	1.195	2.660	2.106
1	CCS20	278096	1.215	2.962	2.443
1-1/4	CCS25	278097	1.182	3.300	2.855
1-1/2	CCS30	278098	1.193	3.600	3.170
2	CCS35	278099	1.195	4.135	3.785
Base	CCS-B	278107	-	-	-

Type 'LB' Access Fittings

Size (in.)	Part Number	Product Code	L1 (in.)	L2 (in.)	H (in.)	J (in.)	Q (in.)
1/2	LB05	078140	4.285	3.290	1.500	1.175	1.312
3/4	LB07	078141	4.970	3.980	1.625	1.375	1.500
1	LB10	078142	5.900	4.656	2.010	1.665	1.750
1-1/4	LB12	078143	7.650	6.060	2.510	1.910	2.450
1-1/2	LB15	078144	7.812	6.180	2.520	2.187	2.468
2	LB20	078145	9.970	8.055	3.455	2.500	3.062
2-1/2	LB25	078146	13.750	11.843	4.625	3.375	4.625
3	LB30	078147	14.250	11.843	4.625	3.405	4.625
3-1/2	LB35	078148	15.500	12.750	5.450	4.210	5.445
4	LB40	078149	15.500	12.750	5.450	4.210	5.445


Includes: Gasket, Cover & Screws

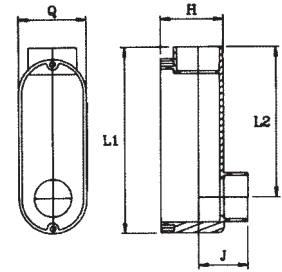

Type 'LR' Access Fittings

Size (in.)	Part Number	Product Code	L1 (in.)	L2 (in.)	H (in.)	J (in.)	Q (in.)
1/2	LR05	078164	4.625	3.615	1.490	1.405	1.310
3/4	LR07	078165	5.260	4.265	1.665	1.540	1.500
1	LR10	078166	6.125	4.875	2.000	1.812	1.750
1- 1/4	LR12	078167	8.125	6.500	2.500	2.250	2.500
1-1/2	LR15	078168	8.187	6.500	2.750	2.312	2.500
2	LR20	078169	10.562	8.625	3.500	2.687	3.125
2-1/2	LR25	078170	13.812	12.125	4.625	5.562	4.625
3	LR30	078171	14.250	12.125	4.625	5.562	4.625
3-1/2	LR35	078172	15.656	14.250	5.484	6.203	5.468
4	LR40	078173	15.500	14.250	5.484	6.203	5.468


Includes: Gasket, Cover & Screws

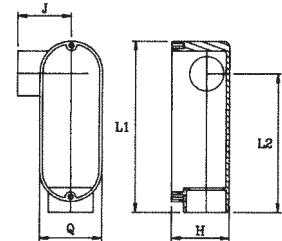

Type 'LL' Access Fittings


Size (in.)	Part Number	Product Code	L1 (in.)	L2 (in.)	H (in.)	J (in.)	Q (in.)
1/2	LL05	078152	4.625	3.500	1.500	1.375	1.312
3/4	LL07	078153	5.250	4.260	1.675	1.545	1.500
1	LL10	078154	6.170	4.925	2.000	1.820	1.750
1-1/4	LL12	078155	8.187	6.500	2.500	2.250	2.500
1-1/2	LL15	078156	8.250	6.500	2.750	2.312	2.500
2	LL20	078157	10.500	8.625	3.500	2.687	3.125
2-1/2	LL25	078158	13.875	12.125	4.625	5.562	4.625
3	LL30	078159	14.250	12.125	4.625	5.562	4.625
3-1/2	LL35	078160	15.656	14.250	5.484	6.203	5.468
4	LL40	078161	15.500	14.250	5.484	6.203	5.468

Includes: Gasket, Cover & Screws

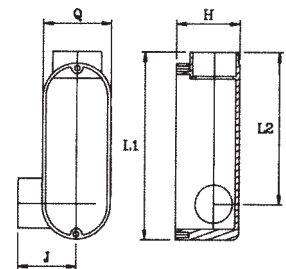

CONDUIT FITTINGS


Type 'T' Access Fittings

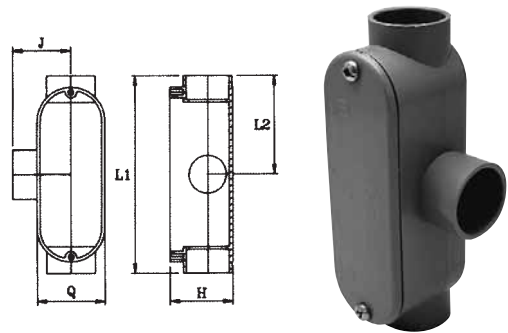

Size (in.)	Part Number	Product Code	L1 (in.)	L2 (in.)	H (in.)	J (in.)	Q (in.)
1/2	T05	078176	4.565	2.275	1.500	1.315	1.315
3/4	T07	078177	5.330	2.685	1.625	1.490	1.490
1	T10	078178	6.390	3.195	2.000	1.770	1.740
1-1/4	T12	078179	9.125	6.500	2.500	2.250	2.500
1-1/2	T15	078180	9.250	6.500	2.750	2.312	2.500
2	T20	078181	11.375	8.625	3.500	2.687	3.125
2-1/2	T25	078182	17.125	12.125	4.625	5.562	4.625
3	T30	078183	17.562	12.125	4.625	5.562	4.625
3-1/2	T35	078184	19.125	14.250	5.484	6.203	5.468
4	T40	078185	19.125	14.250	5.484	6.203	5.468

Includes: Gasket, Cover & Screws


Type 'C' Access Fittings

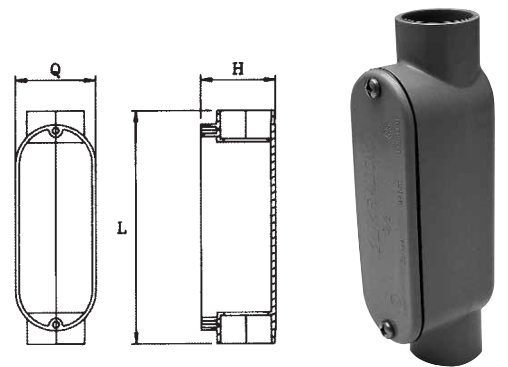

Size (in.)	Part Number	Product Code	L (in.)	H (in.)	Q (in.)
1/2	C05	078116	5.230	1.490	1.330
3/4	C07	078117	5.880	1.675	1.510
1	C10	078118	6.937	2.000	1.750
1-1/4	C12	078119	9.125	2.500	2.500
1-1/2	C15	078120	9.250	2.750	2.500
2	C20	078121	11.437	3.500	3.125
2-1/2	C25	078122	17.125	4.625	4.625
3	C30	078123	17.652	4.625	4.625
3-1/2	C35	078124	19.125	5.484	5.468
4	C40	078125	19.125	5.484	5.468

Includes: Gasket, Cover & Screws

Type 'E' Access Fittings

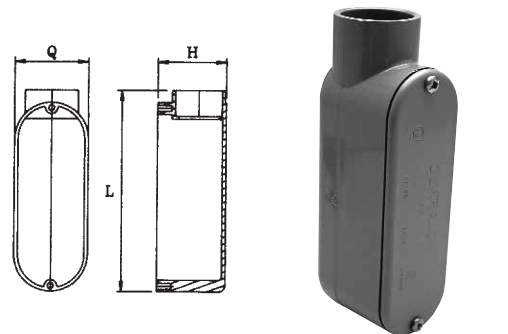

Size (in.)	Part Number	Product Code	L (in.)	H (in.)	Q (in.)
1/2	E05	078128	4.635	1.500	1.312
3/4	E07	078129	5.250	1.675	1.515
1	E10	078130	6.170	2.000	1.750
1-1/4	E12	078131	8.187	2.500	2.500
1-1/2	E15	078132	8.250	2.750	2.500
2	E20	078133	10.500	3.500	3.125
2-1/2	E25	078134	13.875	4.625	4.625
3	E30	078135	14.250	4.625	4.625
3-1/2	E35	078136	15.656	5.484	5.468
4	E40	078137	15.500	5.484	5.468

Includes: Gasket, Cover & Screws

Service Entrance Fittings

Size (in.)	Part Number	Product Code
1/2	MH05	078302
3/4	MH07	078303
1	MH10	078304
1-1/4	MH12	078305
1-1/2	MH15	078306
2	MH20	078307
2-1/2	MH25	078308
3	MH30	078309
3-1/2	MH35	078310
4	MH40	078311



Offset Terminal Adapters

Size S x H (in)	Part Number	Product Code	OL (in)
1-1/4	MO12	078351	4.240
2	MO20	078352	4.360



Pull Elbow

Size (in.)	Part Number	Product Code
1/2 & 3/4	PULEL0705	078386

The new “two-in-one” access pull elbow reduces your inventory costs (3/4" hub fitting supplied with 3/4" x 1/2" reducers). The pull elbow is approved for wet location use and is manufactured from high impact, nonconducting and noncorroding PVC.




CONDUIT FITTINGS

Nonmetallic Strain Relief Connectors

Kraloy's Nonmetallic Strain Relief Connectors are supplied with all the components you need for a complete connection. The connector body, a selection of grommets and compression rings accepting a range of cord dimensions, a sealing 'O' ring and metallic locknut are all supplied in one package. Available in 1/2" and 3/4" threaded hub and 3/4" PVC socket solvent weld configurations to accommodate a variety of applications.

Threaded Strain Relief Connector

Size (in.)	Part Number	Product Code
1/2	TSRCU05	278100
3/4	TSRCU07	278101

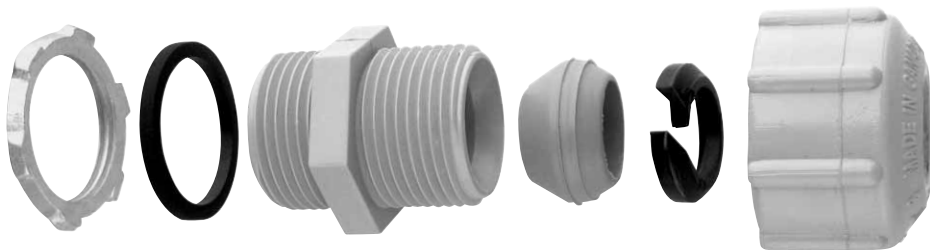

Strain Relief Connector



Size (in.)	Part Number	Product Code
3/4	SRCU07	278102
c/w 4 Grommets - 3/4" solvent weld male end		
3/4	SRC15	077985
c/w 6 Grommets - 3/4" solvent weld male end		

Grommet Dimensions


Grommet	from	to
	Ø = .240"	Ø = .315"
	Ø = .320"	Ø = .415"
	Ø = .420"	Ø = .515"
	Ø = .520"	Ø = .615"

Note: All four grommets and corresponding compression rings are supplied with TSRCU05, TSRCU07 & SRCU07.

COVERS & COVER PLATES


F Series - Single Gang Plates

Description	Part Number	Product Code
Duplex Receptacle	DRC15/10	078889
Toggle Switch	TSC15/10	078898
Single Receptacle	20RC15/10	078882
Single Receptacle	20-3RC15/10	078913
Single Receptacle	30-3RC15/10	078914
Blank c/w Gasket	FSKIT	078241

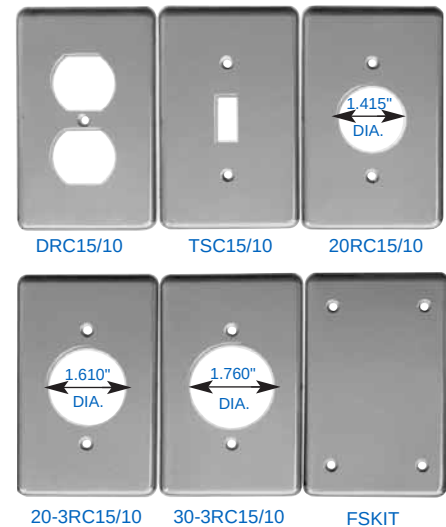


F Series - Double Gang Plates

Description	Part Number	Product Code
Blank Cover c/w Gasket	BRC20-2-U	278085
Double Switch	TSC20-2-U	278088
Double Duplex Receptacle	DRC20-2-U	278086
Combo Switch Duplex Rec.	TSDC20-2-U	278089
Foam Gasket with Adhesive	GASKF20-2-U	172650

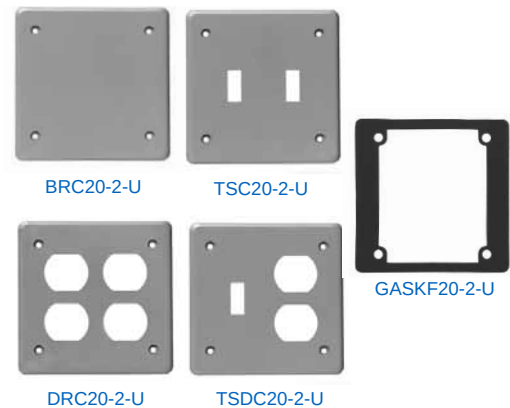

F Series - Triple Gang Plates

Description	Part Number	Product Code
Triple Receptacle	DRC20-3	278070
Combo Switch Receptacle	DSDR20-3	278071
Triple Switch	TSC20-3	278072
Combo Switch Receptacle	TSDC20-3	278073
Blank Cover c/w Gasket	BRC20-3	077748
Gasket for 3 Gang 'F' Boxes	GASK20-3	077749

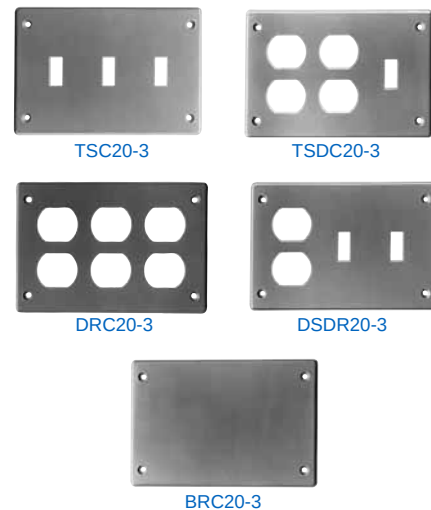

COVERS & COVER PLATES



Weatherproof Single Gang Covers

Description	(in)	Part Number	Product Code
Plunger-style Switch Cover		VPT15/10	078899
Toggle Switch Cover		VSC15/10	078900
Grey Toggle Switch Cover		WTG15/10	078903
Grey Duplex Receptacle		WDR15/10	078901
White Duplex Receptacle		RWDR15/10	078843
Grey Ground Fault Receptacle		WGF15/10	078902
White Ground Fault Receptacle		RWGF15/10	078844
Single Receptacle Device 15 AMP	1.375	WTL15	078904
Single Receptacle Device 20 AMP	1.625	WTL20	078905
30 AMP Twist-Lock	1.722	WTL30	078906
50 AMP Twist-Lock	2.187	WTL50	078909
Grey Double Door Duplex Receptacle		WDRE15/10	078326
White Double Door Duplex Receptacle		RWDRE15/10	078383
Gasket for W Series Cover (except WDRE & RWDRE)		GASKW	077755
Gasket for WDRE & RWDRE Covers		GASKDD	072225



Weatherproof Double Gang Covers


Description	Part Number	Product Code
Toggle Switch Cover	VSC20-2-U	278090
Combination Switch Cover & GFI Receptacle	VSRC20-2-U	278092
Combination Switch Cover & Duplex Receptacle	VSDR20-2-U	278091
Double Door GFCI Cover	VSGG20-2	078327
Double Door Duplex Cover	VSDD20-2	078335
Gasket for Double Gang 'F' Boxes (except VSGG20-2 & VSDD20-2)	GASK20-2-U	172650
Gasket for VSGG20-2 & VSDD20-2 Double Gangs	GASKV20-2	072227

** All covers are universal and will fit on most PVC and metal boxes.
 * Gaskets are included with all weatherproof covers.

BOXES


F-Series Single Gang Boxes

Size (in.)	Part Number	Cubic Inch Capacity	Product Code	L (in.)	W (in.)	D (in.)
1/2	FSE05	17.5	078229	4.58	2.82	2.0
3/4	FSE07	17.5	078230	4.58	2.82	2.0
1/2	FSC05	17.0	078226	4.58	2.82	2.0
3/4	FSC07	17.0	078227	4.58	2.82	2.0
1/2	FSS05	17.0	078232	4.58	2.82	2.0
3/4	FSS07	17.0	078233	4.58	2.82	2.0
1/2	FSCC05	16.3	078235	4.65	2.85	2.0
3/4	FSCC07	16.3	078236	4.65	2.85	2.0

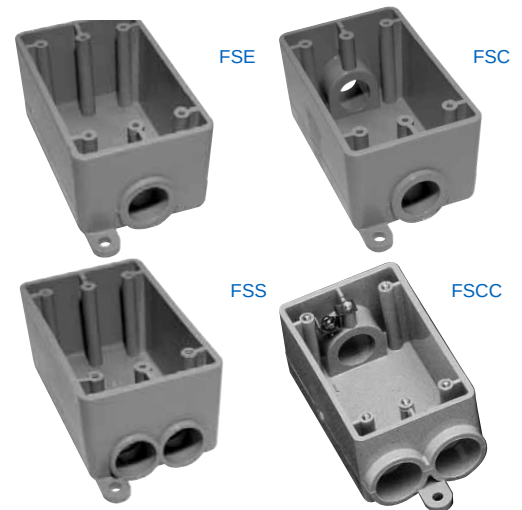



F-Series Single Gang Deep Boxes

Size (in.)	Part Number	Cubic Inch Capacity	Product Code	L (in.)	W (in.)	D (in.)
1/2, 3/4, 1	FSCD050710	26.0	278051	4.58	2.82	2.76
1/2, 3/4, 1	FSED050710	26.8	278050	4.58	2.82	2.76
BLANK	FD	29.0	078215	4.54	2.79	2.91

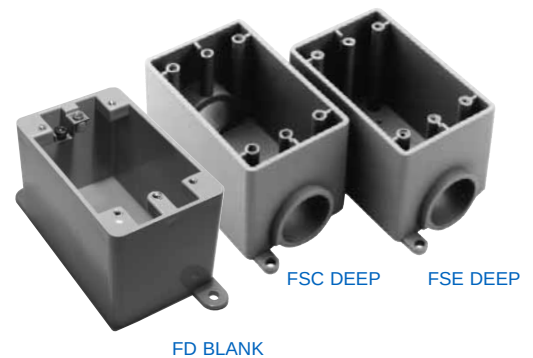


F-Series Double Gang Boxes

Size (in.)	Part Number	Cubic Inch Capacity	Product Code	H (in.)	W (in.)	E (in.)
1/2, 3/4, 1	FSE-2-050710-U	38.5	278082	4.62	4.62	2.5
1/2, 3/4, 1	FSS-2-050710-U	37.0	278087	4.62	4.62	2.5
1/2, 3/4, 1	FSC-2-050710-U	37.0	278083	4.62	4.62	2.5
1/2, 3/4, 1	FSCC-2-050710-U	35.0	278084	4.62	4.62	2.5
BLANK	FD-2-U	47.5	278038	4.75	4.75	3.0

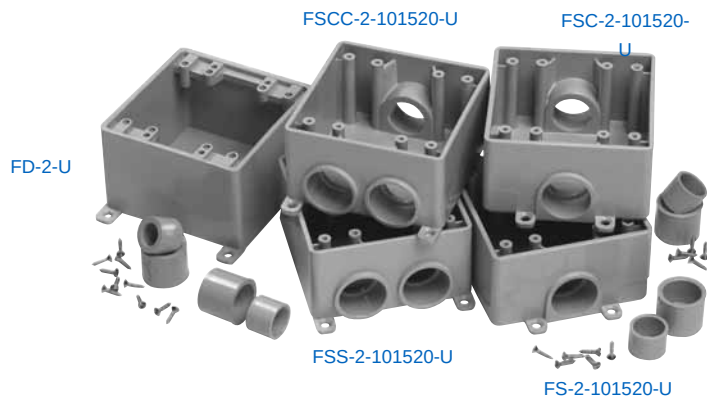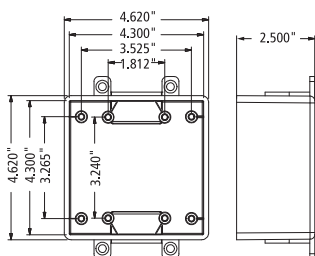


BOXES

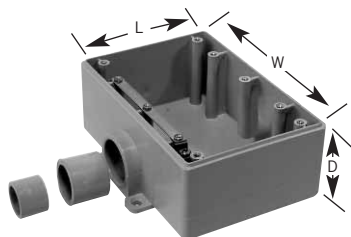

FSE-3-050710



FD-3

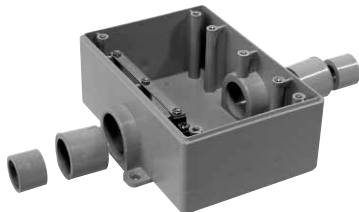

FSS-3-050710

F-Series Triple Gang Boxes

Size (in.)	Part Number	Cubic Inch Capacity	Product Code	L (in.)	W (in.)	D (in.)
1/2, 3/4, 1	FSE-3-050710	56.0	278067	4.50	6.06	2.5
1/2, 3/4, 1	FSC-3-050710	54.0	278068	4.50	6.06	2.5
BLANK	FD-3	56.0	278069	4.1	6.73	3.1

Octagonal Boxes



Size (in)	Hub Size (in)	Part Number	Product Code
4 x 1 1/2	1/2 + 3/4	OB401505/07	078414
4 X 2 1/8	1	OB402010	078415

Octagonal Box Extension Rings



Size (in)	Part Number	Product Code
1	XR20	077989
2	XR35	077990

*LFB150T complete with 1/2 threaded" hole in center of cover

Threaded Round Boxes



Size (in)	Part Number	Product Code
4 - 3/4" Threaded Hubs	LFB150C	077250
4 - 3/4" Threaded Hubs	LFB150T *	077251

*LFB150T complete with 1/2 threaded" hole in center of cover

Junction Boxes

Size (in.)	Part Number	Part Number	A sq.	B sq.	C (inches)	D	H	T
◇ 4 x 4 x 2	JB442	078242	4.375	4.000	2.020	2.200	4	0.187
◇◇ 4 x 4 x 4	JB444	078243	4.375	4.000	4.000	4.187	4	0.187
◇◇◇ 4 x 4 x 6	JB446	078244	4.000	3.675	6.000	6.225	4	0.225
◇◇◇ 5 x 5 x 2	JB552	078245	5.000	4.680	2.000	2.000	4	0.155
◇◇ 6 x 6 x 4	JB664	078246	6.375	6.000	4.000	4.187	4	0.187
◇◇ 6 x 6 x 6	JB666	078247	6.375	6.000	6.000	6.187	4	0.187
◇◇ 8 x 8 x 4	JB884	078248	8.812	8.000	4.000	4.187	4	0.187
◇◇ 8 x 8 x 7	JB887	078249	8.812	8.000	7.000	7.175	4	0.250
◇◇ 12 x 12 x 4	JB12124	078250	12.687	12.000	4.000	4.250	8	0.250
◇◇ 12 x 12 x 6	JB12126	078251	12.687	12.000	6.000	6.250	8	0.250
◇◇◇ 12 x 12 x 8	JB12128	078252	12.580	12.085	8.025	8.250	8	0.225

◇NEMA 1, 2, 3, 3R, 4, 4X, 5, 6P


◇◇NEMA 1, 2, 4, 4X, 5 6, 6P

◇◇◇NEMA 1, 2, 3, 4, 4X, 6P, 12 & 13

Note: Boxes include cover, gasket and screws.



External mounting feet are supplied with all sizes except JB444 and JB446.

Fabricated Junction Boxes are available upon request. Contact your Kraloy Customer Service Representative for more information.

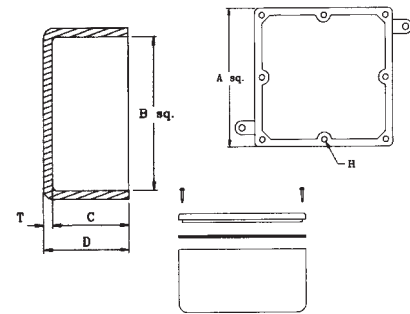

Junction Box Adapters

Size (in.)	Part Number	Product Code	ID (in.)	OD (in.)	L (in.)	OL (in.)
1/2	JBA05	078276	0.605	1.125	0.812	1.000
3/4	JBA07	078277	0.807	1.375	0.937	1.125
1	JBA10	078278	1.060	1.625	1.120	1.325
1-1/4	JBA12	078279	1.355	1.975	1.125	1.325
1-1/2	JBA15	078280	1.560	2.330	1.100	1.370
2	JBA20	078281	2.030	2.890	1.315	1.650
2-1/2	JBA25	078282	2.450	3.375	1.843	2.156
3	JBA30	078283	3.030	4.000	2.093	2.406
3-1/2	JBA35	078284	3.150	3.500	2.125	2.525
4	JBA40	078285	4.016	5.000	2.375	2.687

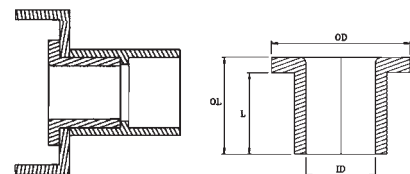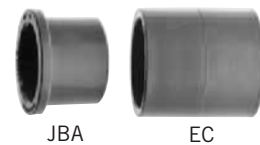


BOXES

Nonmetallic Floor Box, Cover & Metal Cover Adapter

Installation is quick and simple with our nonmetallic floor box and covers, saving both time and money over similar metallic assemblies.

Kraloy's floor box and duplex receptacle covers are constructed from high impact, noncorroding and nonconducting PVC. The flush mount covers are available in custom colors and are shipped with a leveling ring. Metal cover adapter kits are also available, allowing you to adapt to metal floor plates. Our 6" deep floor box allows flexibility for various concrete floor pours, while our 4 3/4" width offers easy access and ample wire room. The box comes complete with 2 - 1" and 2 - 3/4" hub openings.

All boxes are shipped complete with reducer plugs (2 - 1 x 3/4, 3 - 3/4 x 1/2) for added versatility.

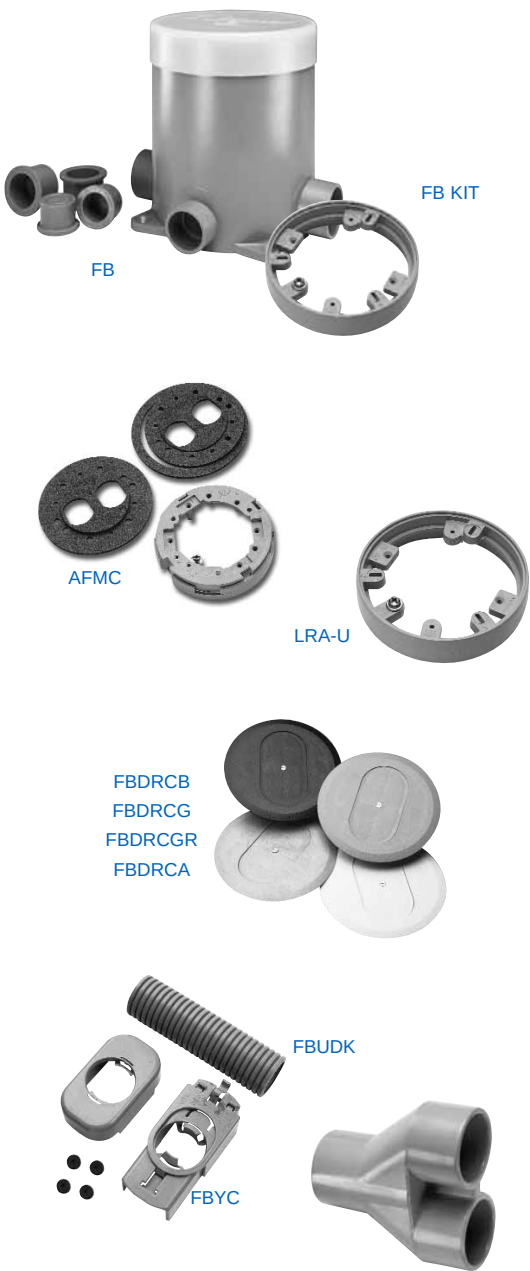

Description	Part Number	Product Code
Floor Box Base	FB	078876
(includes disposable protective cap & reducer plugs) suitable for slab-on-grade or below grade, and wood floor construction		
Floor Box Kit	FBKIT	078908
c/w Universal leveling ring adapter, disposable protective cap and reducer plugs		
Metal Cover Adapter Kit	AFMC	078875
(includes leveling ring, metal cover adapter ring & two shim gaskets for height adjustment)		
Universal Leveling Ring Adapter	LRA-U	078446
Floor Box Duplex Receptacle Cover (Nonmetallic)		
c/w leveling ring and blank cover & gasket. Accepts standard duplex receptacle (not included)		
Brown	FBDRCB	078877
Gold	FBDRCG	078878
Grey	FBDRCGr	078618
Light Almond	FBDRCA	078841
Tri-Service Universal Divider Kit	FBUDK	078993
(includes upper & lower dividers, riser tube & four grommets) Kit partitions the round PVC floor box to permit power, communication and/or data cabling in one location and within the same box		
Y Connector	FBYC	078928
use y connector to feed through (in/out) or to bring a parallel run of 3/4" conduit to the same hub		

Round Floor Box Stand

This simple yet innovative Round Floor Box Stand is equipped with several height brackets which accommodate the different rebar and post-tension cable heights and slab depths. When installed together, the Floor Box and Stand can be used in 5-1/2" to 10" slab depths.

Features:


- Four adjustable heights
- Raises entrance hubs to rebar height
- Minimizes footprint on concrete form
- Withstands tough job site conditions
- Easy to install
- Cost effective

The Round Floor Box easily snaps into the Stand on one of the four convenient height brackets at 2-1/2", 3", 3-1/2" and 4". By raising the Floor Box off the concrete form, the footprint is minimized which reduces the amount of time the contractor spends finishing the concrete surface. In addition, the various Stand heights allow the ENT to enter the Box in a flat and straight path, resulting in less effort by the contractor when pulling in the electrical cable.



Part Number	Product Code
FBS-KIT	178269

Brass Cover Plates

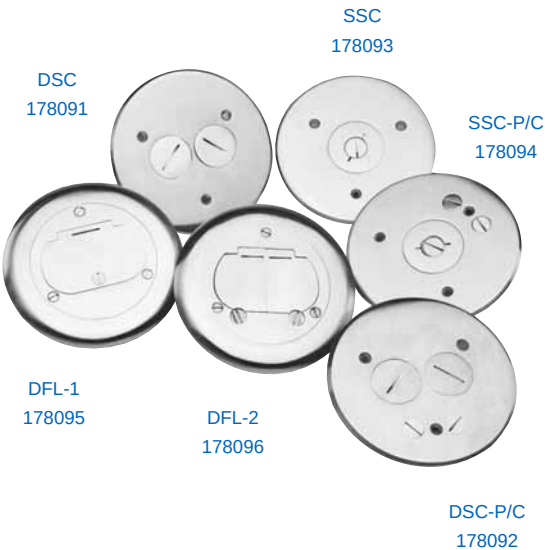

- Brass cover plates offer a one-piece design measuring 5-3/4" diameter
- Available in a variety of styles accommodating power (single or duplex receptacle) and communication needs
- Mount to FB Box using LRA-U Leveling Ring Adapter

DFL-2
Brass cover plate with dual flip-lid opening for a duplex receptacle 5-3/4" diameter.
Product Code: 178096

DSC
Brass cover plate with two screw plug (1-1/2") openings for a duplex receptacle 5-3/4" diameter.
Product Code: 178091

DSC-P/C
Brass cover plate with two screw plug (1-1/2") openings and two screw plug (1/2") openings for data/communication, 5-3/4" diameter.
Product Code: 178092


SSC
Brass cover plate with a combination (2" - 1/2") screw plug opening for single receptacle or data/communication, 5-3/4" diameter.
Product Code: 178093

SSC-P/C
Brass cover plate with a combination (2" - 1/2") screw plug opening for single receptacle and two screw plug (1/2") openings for data/communication, 5-3/4" diameter.
Product Code: 178094



CONDUIT INTERLOCKING SPACERS


Intermediate Vertical-Lok Spacers

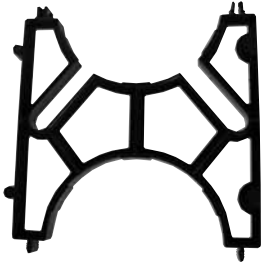

Kraloy conduit interlocking spacers are available in a variety of spacing dimensions for all conduit sizes. Our most popular sizes are offered with unique rebar holder slots for quick reinforcing bar installation and the bases have support holes for securing the base spacers to the trench bottom.

Kraloy conduit spacers manufactured with the rebar holder slots can accommodate a maximum rebar diameter of 5/8" for the 2" conduit size and 7/8" for all other conduit size spacers. All conduit spacers provide a 3" clearance from the trench base to the bottom of the first conduit.

Kraloy recommends the installation of a spacer every 5 to 6 feet along the raceway length to provide the proper and even support of the conduit assembly.

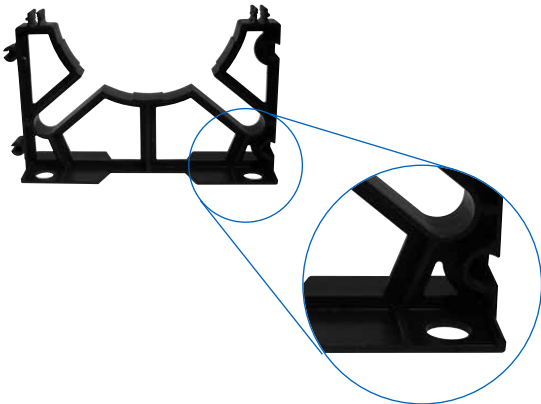

Size (in.)	Part Number	Product Code
2 x 1-1/2	IV2015	029550
2 x 2	IV2020	029551
2 x 3	IV2030	029552
* 3 x 1-1/2	IV3015	029553
3 x 2	IV3020	029554
3 x 3	IV3030	029555
* 4 x 1	IV4010	029556
4 x 1-1/2	IV4015	029557
4 x 2	IV4020	029558
4 x 3	IV4030	029559
* 5 x 1-1/2	IV5015	029560
5 x 2	IV5020	029561
5 x 3	IV5030	029562
6 x 1-1/2	IV6015	029563
6 x 2	IV6020	029564
6 x 3	IV6030	029565
* 8 x 2	IV8020	029294

* Do not have rebar slots or base holes

Base Vertical-Lok Spacers

Size (in.)	Part Number	Product Code
2 x 1-1/2	BV2015	029566
2 x 2	BV2020	029567
2 x 3	BV2030	029568
* 3 x 1-1/2	BV3015	029569
3 x 2	BV3020	029570
3 x 3	BV3030	029571
* 4 x 1	BV4010	029572
4 x 1-1/2	BV4015	029573
4 x 2	BV4020	029574
4 x 3	BV4030	029575
* 5 x 1-1/2	BV5015	029576
5 x 2	BV5020	029577
5 x 3	BV5030	029578
6 x 1-1/2	BV6015	029579
6 x 2	BV6020	029580
6 x 3	BV6030	029581
* 8 x 2	BV8020	029293

* Do not have rebar slots or base holes



Nonmetallic Vapor Proof Incandescent Light Fixtures

Kraloy's "lighting you can trust" is constructed of noncorroding, nonconductive, high impact glass reinforced polyester resin. It features a one-piece fixture base with threaded hub entry offering a 15 cubic inch volume. Kraloy's fixture is approved for use with 75°C (167°F) wiring and rated for use with 150 Watt A21 medium base incandescent lamp. Integral molded mounting feet provide for easy installation and ensure a secure support.

Description - Fixture c/w:	Part Number	Hub	Product Code
Clear Glass Globe	LVPE 150-10/15	1/2" - 3/4"	078666
Heat Resistant Clear Glass Globe	LVPE150HRC	1/2" - 3/4"	078716
Heat Resistant Red Glass Globe	LVPE150HRR	1/2" - 3/4"	078736
Heat Resistant Blue Glass Globe	LVPE150HRB	1/2" - 3/4"	078738
Heat Resistant Green Glass Globe	LVPE150HRG	1/2" - 3/4"	078748
Heat Resistant Amber Glass Globe	LVPE150HRA	1/2" - 3/4"	078749
Clear Glass Globe & Clamp-on Guard	LVPE 150-0507G	1/2" - 3/4"	278036
Light Fixture w/ Polycarbonate Globe (Approved for use with 60W Max Type A lamp).	LVPE 150-PCC	1/2" - 3/4"	278033
Nonmetallic Clamp-on Guard	LVPEG 150		077558


Replacement Globes + HR Globes		
Standard Clear Glass Globe	LGC150	077247
Heat Resistant Clear Glass Globe	LG150T	077909
Heat Resistant Red Glass Globe	LCGR150T	077239
Heat Resistant Blue Glass Globe	LCGB150T	077910
Heat Resistant Green Glass Globe	LCGG150T	077241
Heat Resistant Amber Glass Globe	LCGA150T	077242
Polycarbonate Clear Globe	LPCC 19	077911

Note: Lamp is not supplied with fixture.

Please refer to our Sceptalight brochure for our Wet, Hazardous and Marine Location rated non-metallic light fixtures.



GLOBE OPTIONS

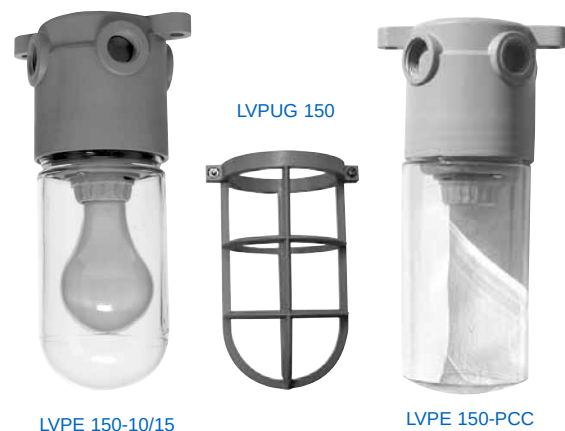

CONDUIT CEMENT



Clear Conduit Cement

Use **Clear Conduit Solvent Cement Medium Bodied** to create solid, waterproof joints when connecting electrical PVC conduit pipe. The cement is approved for use with rigid PVC conduit such as Kraloy's Rigid PVC conduit & fittings, Kwikon ENT and fittings, and Duct & fittings.

Size (in.)	Product Code	Units per Case
Pint	078798	12
Quart	078799	12
Gallon	078105	4

Average Number of Joints per Pint or Quart of Cement

Nominal Pipe Size (inches)	Number of Joints per Pint	Number of Joints per Quart
1/2	350	700
3/4	200	400
1	150	300
1-1/4	110	220
1-1/2	80	160
2	45	90
2-1/2	40	80
3	35	70
3-1/2	30	60
4	24	48
5	10	20
6	8	16

Cements and Primers

Size (in.)	Description	Product Code	Low VOC
1/2 Pint	Medium Bodied Grey Cement	078082	no
Pint	Medium Bodied Grey Cement	078083	no
Quart	Medium Bodied Grey Cement	078096	no
* Gallon	Medium Bodied Grey Cement	078097	no
Pint	Cold Weather Cement	078503	no
Quart	Cold Weather Cement	078886	no
Pint	ENT Cement	078501	no
Quart	ENT Cement	078186	yes
1/2 Pint	Clear Regular Bodied Solvent Cement	078883	yes
Pint	Clear Regular Bodied Solvent Cement	078884	yes
Quart	Clear Regular Bodied Solvent Cement	078885	yes
* Gallon	Clear Regular Bodied Solvent Cement	078887	yes
Pint	Purple Primer	078050	yes
Quart	Purple Primer	078054	yes
Gallon	Purple Primer	078062	yes
1/2 Pint	Clear Conduit Primer	078163	yes
Pint	Clear Conduit Primer	078174	yes
Quart	Clear Conduit Primer	078175	yes

All cements and primers come with applicator caps except were indicated with *

TOOL & REPAIR KITS


EPR Kits for Conduit Repair

EPR Kits are the first total repair systems for broken and damaged PVC conduit. They offer fast and easy repairs for damaged conduit caused by actions such as earth excavation, horizontal and core drilling.


With unique interlocking joints, the EPR Kits' two half shell bell by bell pieces simply close around the installed wire and cable. Using standard PVC solvent cement, EPR Kits are quickly and easily assembled and connected, restoring the conduit to its original form.

EPR Kits are manufactured of high-impact and non-conductive PVC, ensuring a life long quality repair for your system.

Size (in)	Part Number	Product Code	Length (in)
1-1/4	EPR25	077976	24
1-1/2	EPR30	077971	24
2	EPR35	077972	24
2-1/2	EPR40	077973	24
3	EPR45	077974	24
4	EPR55	077975	24
5	EPR60	077977	24
6	EPR65	077979	24

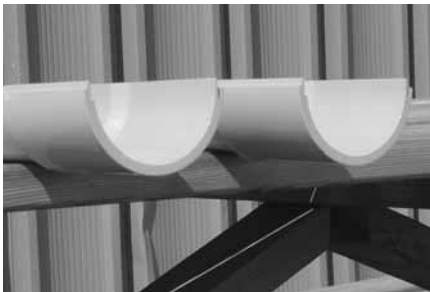

Step 1

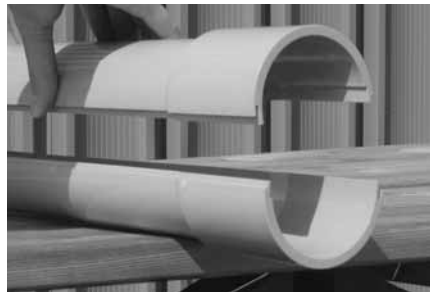

Step 2



Step 3

[illegible]

[illegible]

This image shows a full page of blank handwriting practice paper. It features 20 evenly spaced, horizontal blue lines running across the width of the page. The lines are thin and light blue, providing a guide for letter height and placement. There are no margins, text, or other markings on the paper.

CUSTOMER SERVICE CENTER

1055 Wilton Grove Road
London, Ontario N6A 4K3

Tel: (519) 681-2140
Toll Free: (800) 265-1815
Fax: (519) 681-2156

www.kraloyfittings.com

Kraloy has been an industry leader for over 40 years supplying the electrical trade with a comprehensive offering of nonmetallic PVC fittings. Kraloy offers adapters, couplings, elbows, access fittings, boxes, cover plates, expansion fittings and spacers – virtually any fitting required to complete the PVC conduit system.

Check out the full Kraloy product offering on our web site www.kraloyfittings.com or contact us directly for information.

Only when you specify Kraloy by name are you guaranteed The Fitting Choice.

Kraloy is proud to offer these quality brands.

 **KRALOY®**
PVC CONDUIT FITTINGS

 **KWIKON®**
ENT & FITTINGS

Sceptalight™
Nonmetallic Light Fixtures

 **KWIKFLEX®**
LIQUIDTIGHT FLEXIBLE NONMETALLIC CONDUIT & FITTINGS

 **KWIKPATH®**
COMMUNICATION RACEWAY SYSTEMS

Products are manufactured by IPEX Electrical Inc. and distributed in the United States by Kraloy, a division of Multi Fittings Corp.

Kraloy® is a trademark of Multi Fittings Corp.

Kwikon®, Kwikflex® and Sceptalight™ are trademarks of IPEX Branding Inc.

DISTRIBUTED BY:

www.kraloyfittings.com

This literature is published in good faith and is believed to be reliable. However, Kraloy does not represent and/or warrant in any manner the information and suggestions contained in this brochure. Data presented is the result of laboratory tests and field experience. Kraloy maintains a policy of ongoing product improvement. This may result in modifications of features and/or specifications without notice.

 **KRALOY®**