

SOCKETS

Porcelain Sockets




RECEPTACLE
22264
CANDELABRA BASE
75 WATTS
125 VOLTS
HEIGHT - 7/8"



RECEPTACLE
22273
STANDARD BASE
660 WATTS
250 VOLTS
HEIGHT - 1 1/2"




SOCKET EXTENDER
22150
STANDARD BASE
660 WATTS
250 VOLTS
EXTENSION - 1 1/4"
OVERALL LENGTH - 2 1/2"

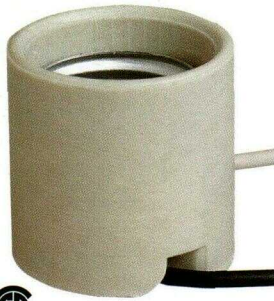

KEYLESS SOCKET
1 SCREW SURFACE MOUNT
22218 -7" WIRE LEADS
STANDARD BASE
660 WATTS
250 VOLTS
18 GAUGE, 105'LEADS
HEIGHT - 1 5/8"



FIXTURE
22370- 10" WIRE LEADS
STANDARD BASE
3/8-IP HICKEY
18 GAUGE, 105'LEADS
660 WATTS
250 VOLTS
HEIGHT - 2"

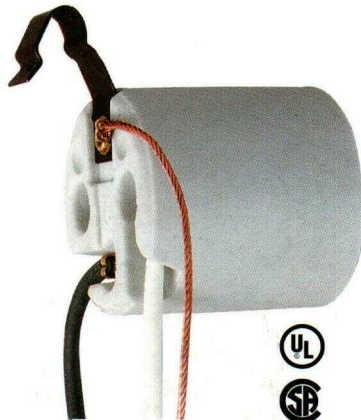

FIXTURE
22372 - 9" WIRE LEADS
STANDARD BASE
FITS 3/8" x 1/2" HOLE
18 GAUGE, ISO' LEADS
660 WATTS
250 VOLTS
HEIGHT - 2"



NEW



SNAP-IN PORCELAIN SOCKET
22276
660 WATTS
250 VOLTS
HEIGHT - 1 1/16"



SNAP-IN
22212 - 6" WIRE LEADS
FITS 1 1/2" HOLE
18 GAUGE, 125'LEADS
660 WATTS
250 VOLTS
HEIGHT - 1 3/4"

