

INVISILED® ACCESSORIES

Indoor mounting accessories

WAC LIGHTING

Responsible Lighting®

		5 feet	LED-T-CH	Aluminum Channel	Includes a diffuser, two end caps, and five screws	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		2 pcs	LED-T-CH-EC	End caps for Aluminum Channel		Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		5 feet	LED-T-CH1	Deep Aluminum Channel	Includes a diffuser, two end caps, and five screws	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		2 pcs	LED-T-CH1-EC	End caps for Deep Aluminum Channel		Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		5 feet	LED-T-CH2	45° Angled Aluminum Channel	Includes a diffuser, two end caps, and five screws	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		2 pcs	LED-T-CH2-EC	End caps for 45° Angled Aluminum Channel		Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		2 pcs	LED-T-CL3-PT	2 Adjustable Clips	Used to mount any aluminum channel Includes 2 pieces, 4 screws	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		2 pcs	LED-T-CL2-PT	2 Adjustable Clips	Used to mount any aluminum channel Adjusts 50° from center either way Includes 2 pieces, 4 screws	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		3 feet	LED-T-RC	Retrofit Channel	Can be bent to create fixed curves	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		10 pcs	LED-T-CL	Clip	Holds an indoor tape from the underside Includes 10 pieces, 10 screws	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
		10 pcs	LED-T-CL1	Curve Clip	Runs over an indoor tape to secure the angled tape Includes 10 pieces, 10 screws	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette

LED-T-_____

Example: **LED-T-CL3-PT**

WAC Lighting
www.waclighting.com
Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive • Port Washington, NY 11050
Phone (516) 515.5000 • Fax (516) 515.5050





Western Distribution Center
1750 Archibald Avenue • Ontario, CA 91760
Phone (800) 526.2588 • Fax (800) 526.2585

INVISIBLE® ACCESSORIES

Outdoor mounting accessories

WAC LIGHTING

Responsible Lighting®

	5 feet	LED-TO24-CH5	Clear Channel	Rigid, non-flexible channel for mounting to a straight, solid surface.	Pro Outdoor Palette Outdoor
	10 pcs	LED-TO24-C1	Mounting Clip 1	For installation on non-flat surfaces where there is no edge contact. 2 clips per ft are recommended for straight runs.	Pro Outdoor Palette Outdoor
	10 pcs	LED-TO24-C2	Mounting Clip 2	For installation on non-flat surfaces, allows for contact on one edge. 2 clips per ft are recommended for straight runs.	Pro Outdoor Palette Outdoor
	10 pcs	LED-TO24-C3	Mounting Clip 3	For installation on non-flat surfaces, allows for contact on both edges. 2 clips per ft are recommended for straight runs.	Pro Outdoor Palette Outdoor

LED-TO24-_____

Example: **LED-TO24-C2**

WAC Lighting
www.waclighting.com
Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive • Port Washington, NY 11050
Phone (516) 515.5000 • Fax (516) 515.5050

Western Distribution Center
1750 Archibald Avenue • Ontario, CA 91760
Phone (800) 526.2588 • Fax (800) 526.2585

INVISILED® ACCESSORIES

Indoor non-color changing electronic accessories

WAC LIGHTING

Responsible Lighting®

Type	Model	Input	Output	Max Run	Dim	Compatibility
Remote	 EN-2460-RB2-T EN-24100-RB2-T	120VAC	24VAC / 60W	30 feet	ELV	Includes a 6 foot lead wire Pro, Pro2, Pro3, LITE, Classic
		120VAC	24VAC / 96W	40 feet	ELV	
Plug-in	 EN-2460-P-AR-T EN-24100-P-AR-T	120VAC	24VAC / 60W	30 feet	ELV	Includes a 6 foot lead wire Pro, Pro2, Pro3, LITE, Classic
		120VAC	24VAC / 96W	40 feet	ELV	
Remote 277V	 EN-24100-277-RB2-T	277VAC	24VDC / 96W	40 feet	0-10V	Includes a 6 foot lead wire Pro, Pro2, Pro3, LITE, Classic
Touch Panel and Motion Sensor	 CT-6A-R2	Includes a Touch Panel, an Occupancy Sensor, and a Controller AC/DC input at 12V(60W Max) or 24V(96W Max) Connect on secondary side of driver/transformer			Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette	
Lead Wire	 LED-TC-P-2 LED-TC-P-12	2 ft	Alternative lengths for plug-in power supplies		Pro, Pro2, Pro3, LITE, Classic	
		12 ft				
Extension Cable	 LED-TC-EXT-144	12 ft	Extends distance between a hard wired power supply or wiring box to a tape section		Pro, Pro2, Pro3, LITE, Classic	
Low Voltage Wiring Box With Feed	 LED-TC-B-2	L: 1½ in W: ¾ in H: 7⁄8 in	Neatly houses up to two wires with 2" female feed		Pro, Pro2, Pro3, LITE, Classic	
Low Voltage Wiring Box	 LED-T-B	L: 1½ in W: ¾ in H: 7⁄8 in	Neatly houses up to two wires		Pro, Pro2, Pro3, LITE, Classic	
Wiring Box With Switch	 TB-S	L: 6¼ in W: 1½ in H: 1¼ in	Use when spanning a large gap in a system layout without leaving exposed wiring		Pro, Pro2, Pro3, LITE, Classic	
Joiner Cable	 LED-TC-IC2 LED-TC-IC6 LED-TC-IC12 LED-TC-IC36 LED-TC-IC72	2 in	Connects tape sections		Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette	
		6 in				
		12 in				
		36 in				
		72 in				
3-Way "Y" Connector	 LED-TC-Y	Connects tape sections		Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette		
4-Way "X" Connector	 LED-TC-X	Connects tape sections		Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette		
"L" Connector	 LED-TC-L	Connects tape sections		Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette		
End cap	 LED-TC-EC	1 cut end cap and 1 male end cap		Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette		

Example: **LED-T-P-12**

WAC Lighting
www.waclighting.com
Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive • Port Washington, NY 11050
Phone (516) 515.5000 • Fax (516) 515.5050



Western Distribution Center
1750 Archibald Avenue • Ontario, CA 91760
Phone (800) 526.2588 • Fax (800) 526.2585

INVISILED® ACCESSORIES


Indoor color changing electronic accessories

WAC LIGHTING

Responsible Lighting®




Type	Model	Input	Output	Max Run	Dim	Compatibility
Remote Color changing	 EN-2460D-C	120VAC	24VDC / 60W	40 feet	ELV	Includes a 6 foot lead wire Daylight to Sunset, Palette
Plug-in Color changing	 EN-2460D-C-P	120VAC	24VDC / 60W	40 feet	ELV	Includes a 6 foot lead wire Daylight to Sunset, Palette

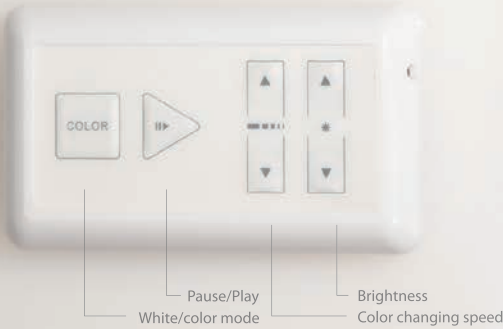





Wireless controller (accessory for wired controller)
LED-TO24-WS



Wired controller
LED-TC-CTR-MSD



Wired controller	 LED-TC-CTR-MSD	4 function wired controller with master and slave options	Allows brightness control, preset color selection, or playing a rotation of color transitions with variable speed control	Daylight to Sunset, Palette
Wireless Controller	 LED-TO24-WS	4 function wireless controller (Requires wired controller)	Allows brightness control, preset color selection, or playing a rotation of color transitions with variable speed control	Daylight to Sunset, Palette
Touch Panel and Motion Sensor	 CT-6A-R2	Includes a Touch Panel, an Occupancy Sensor, and a Controller AC/DC input at 12V(60W Max) or 24V(96W Max) Connect on secondary side of driver/transformer		Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette

Signal Wire	 LED-TC24-SW60 LED-TC24-SW120	60 in 120 in	Links master and slave controllers	Daylight to Sunset, Palette
Joiner Cable	 LED-TC-IC2 LED-TC-IC6 LED-TC-IC12 LED-TC-IC36 LED-TC-IC72	2 in 6 in 12 in 36 in 72 in	Connects tape sections	Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette
3-Way "Y" Connector	 LED-TC-Y		Connects tape sections	Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette
4-Way "X" Connector	 LED-TC-X		Connects tape sections	Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette
"L" Connector	 LED-TC-L		Connects tape sections	Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette
End cap	 LED-TC-EC		1 cut end cap and 1 male end cap	Pro, Pro2, Pro3, LITE, Classic, Daylight to Sunset, Palette

Example: **LED-TC-IC6**

WAC Lighting
www.waclighting.com
Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive • Port Washington, NY 11050
Phone (516) 515.5000 • Fax (516) 515.5050
















Western Distribution Center
1750 Archibald Avenue • Ontario, CA 91760
Phone (800) 526.2588 • Fax (800) 526.2585

INVISILED® ACCESSORIES

Outdoor electronic accessories

WAC LIGHTING

Responsible Lighting®

Type	Model	Input	Output	Max Run	Dim	Compatibility
Remote Damp Location	 EN-OD24100-RB2-T	120VAC	24VAC / 96W	30 feet	ELV	Includes a 6 foot lead wire Minimum load of 1W Pro Outdoor
Remote Wet Location	 EN-O24100-RB2-T	120 - 277VAC	24VDC / 96W	30 feet	No	Class 2 rated Includes a 6 foot lead wire Minimum load of 1W Pro Outdoor, Palette Outdoor
Master Controller	 LED-TO24-CM	4" x 2" x 1½"	Powers one run up to 40'. Connects and controls all slave controllers for runs over 40'			Palette Outdoor
Slave Controller	 LED-TO24-CS	4" x 2" x 1½"	Connects to Master Controller for runs over 40'. Uses a separate 120V power supply. Powers up to another 40'. A Slave Controller is needed for every 40' extension			Palette Outdoor
Wireless Controller (optional)	 LED-TO24-WS	4" x 2½" x 5/8"	Wireless connection to Master Controller Use to switch from color changing to white light Play/Pause the color changing effect Control the brightness and speed of the color changing effect Uses 2 AAA batteries			Palette Outdoor
Touch Panel and Motion Sensor	 CT-6A-R2	Includes a Touch Panel, an Occupancy Sensor, and a Controller AC/DC input at 12V(60W Max) or 24V(96W Max) Connect on secondary side of driver/transformer				Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
End cap	 LED-TO24-EC	Use to terminate every run to protect against contaminants. Seal cut end with silicone after adding end cap.				Pro Outdoor, Palette Outdoor
3-Way "Y" Connector	 LED-TO24-Y	Connects tape sections				Pro Outdoor
4-Way "X" Connector	 LED-TO24-X	Connects tape sections				Pro Outdoor
Joiner Cable	 LED-TO24-IC6 LED-TO24-IC12 LED-TO24-IC72 LED-TO24-IC120	6 in 12 in 72 in 120 in	Extends distance between Power Supply and Master Controller.			Pro Outdoor
RGB 3-Way "Y" Connector	 LED-TO24-Y-RGB	Connects tape sections				Palette Outdoor
RGB 4-Way "X" Connector	 LED-TO24-X-RGB	Connects tape sections				Palette Outdoor
RGB Joiner Cable	 LED-TO24-IC6-RGB LED-TO24-IC12-RGB LED-TO24-IC72-RGB LED-TO24-IC120-RGB	6 in 12 in 72 in 120 in	Use to connect two sections of InvisILED® Outdoor Palette tape.			Palette Outdoor
Signal wire	 LED-TO24-SW60 LED-TO24-SW120	5 feet 10 feet	Connects Master Controller and Slave Controller.			Palette Outdoor
DMX Signal Wire	 LED-TO24-MW60 LED-TO24-MW120	5 feet 10 feet	Connects DMX system to Master Controller.			Palette Outdoor

Example: **LED-TO24-WS**

WAC Lighting
www.waclighting.com
Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive • Port Washington, NY 11050
Phone (516) 515.5000 • Fax (516) 515.5050

Western Distribution Center
1750 Archibald Avenue • Ontario, CA 91760
Phone (800) 526.2588 • Fax (800) 526.2585