



Powerful, ultra-slim circular lamps

T5 Circular

Philips T5 Circular lamps are ultra-slim with improved color rendering, higher efficacy, and longer life. T5 HO circular lamps offer extraordinary light output.

Benefits

- Slim profile lamp and ballast enables fixtures to be 45% smaller than T9 Circline systems.
- Long Life to assist with lowering your maintenance costs and reducing waste.
- Operates on Programmed Start Electronic Ballasts.

Features

- Design flexibility.
- Improved optical control.
- Fixtures can be 45% smaller than standard T9 circline systems.
- Dimmable for additional energy savings.
- Energy efficient.
- Less material means less waste.
- Longer life.
- Available in 22 and 40 Watts with 3000, 3500, 4100 color temperatures. T5 HO Circular Lamps are available in 55 Watt with 3000, 3500 and 4100 color temperatures.

Application


- Ideal for offices and commercial establishments where smaller, more appealing fixture designs are required

Related products



C-T5 2GX13

Dimensional drawing

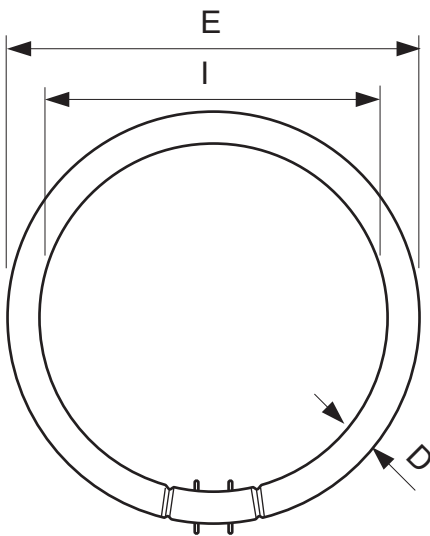

22W/830 C-T5 1CT

| Product | D (Min) | D (Max) | E (Min) | E (Max) | I (Min) | I (Max) |
|---------------|---------|---------|---------|---------|---------|---------|
| TL5-C 22W/830 | 14 | 18 | 220 | 230 | 187 | 197 |
| TL5-C 22W/840 | 14 | 18 | 220 | 230 | 187 | 197 |
| TL5-C 55W/830 | 14 | 18 | 293 | 305 | 260 | 272 |
| TL5-C 55W/840 | 14 | 18 | 293 | 305 | 260 | 272 |

General Characteristics (1/2)


| Product number | Full product name | Base | Bulb | Life to 10% fail Preheat EL,3h | Rated Avg. Life | LSF HF Preheat 2000h Rated,3h | LSF HF Preheat 4000h Rated,3h | LSF HF Preheat 6000h Rated,3h | LSF HF Preheat 8000h Rated,3h | LSF HF Preheat 12000h Rated,3h | LSF HF Preheat 16000h Rated,3h |
|----------------|---------------------------------|-------|------|--------------------------------|-----------------|-------------------------------|-------------------------------|-------------------------------|-------------------------------|--------------------------------|--------------------------------|
| 166017 | MASTER TL5 Circular 22W/830 1CT | 2GX13 | C-T5 | 8000 hr | 12000 hr | 99 % | 99 % | 96 % | 89 % | 50 % | 10 % |
| 166009 | MASTER TL5 Circular 22W/840 1CT | 2GX13 | C-T5 | 8000 hr | 12000 hr | 99 % | 99 % | 96 % | 89 % | 50 % | 10 % |
| 165936 | MASTER TL5 Circular 55W/830 1CT | 2GX13 | C-T5 | 8000 hr | 12000 hr | 99 % | 99 % | 96 % | 89 % | 50 % | 10 % |
| 165928 | MASTER TL5 Circular 55W/840 1CT | 2GX13 | C-T5 | 8000 hr | 12000 hr | 99 % | 99 % | 96 % | 89 % | 50 % | 10 % |

General Characteristics (2/2)

| Product number | Full product name | LSF HF Preheat 20000h Rated,3h |
|----------------|---------------------------------|--------------------------------|
| 166017 | MASTER TL5 Circular 22W/830 1CT | 1 % |
| 166009 | MASTER TL5 Circular 22W/840 1CT | 1 % |

| Product number | Full product name | LSF HF Preheat 20000h Rated,3h |
|----------------|---------------------------------|--------------------------------|
| 165936 | MASTER TL5 Circular 55W/830 1CT | 1 % |
| 165928 | MASTER TL5 Circular 55W/840 1CT | 1 % |

Installation diagrams

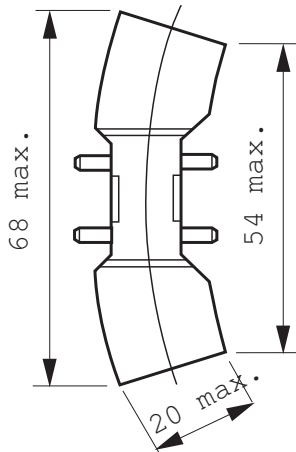

2GX13

Light Technical Characteristics (1/2)

| Product number | Full product name | Color Code | Color Rendering Index | Color Designation | Color Temperature | Luminous Flux EL 25°C, Rated | Luminous Flux EL 25°C, Nominal | Lum Efficacy Rated HF 25°C | LLMF HF 2000h Rated | LLMF HF 4000h Rated | LLMF HF 6000h Rated |
|----------------|---------------------------------|------------|----------------------------------|-------------------|-------------------|------------------------------|--------------------------------|----------------------------|---------------------|---------------------|---------------------|
| 166017 | MASTER TL5 Circular 22W/830 1CT | 830 | 80 (min), 82 (nom), 85 (max) Ra8 | Warm White | 3000 K | 1800 Lm | 1800 Lm | 82 Lm/W | 91 % | 87 % | 84 % |
| 166009 | MASTER TL5 Circular 22W/840 1CT | 841 | 80 (min), 82 (nom), 85 (max) Ra8 | Cool White | 4100 K | 1800 Lm | 1800 Lm | 82 Lm/W | 91 % | 87 % | 84 % |
| 165936 | MASTER TL5 Circular 55W/830 1CT | 830 | 80 (min), 82 (nom), 85 (max) Ra8 | Warm White | 3000 K | 4200 Lm | 4200 Lm | 76 Lm/W | 91 % | 87 % | 84 % |
| 165928 | MASTER TL5 Circular 55W/840 1CT | 841 | 80 (min), 82 (nom), 85 (max) Ra8 | Cool White | 4100 K | 4200 Lm | 4200 Lm | 76 Lm/W | 91 % | 87 % | 84 % |

Light Technical Characteristics (2/2)


| Product number | Full product name | LLMF HF 8000h Rated | LLMF HF 12000h Rated | LLMF HF 16000h Rated | LLMF HF 20000h Rated | Design Temperature | Chromaticity Coordinate X | Chromaticity Coordinate Y |
|----------------|---------------------------------|---------------------|----------------------|----------------------|----------------------|--------------------|---------------------------|---------------------------|
| 166017 | MASTER TL5 Circular 22W/830 1CT | 81 % | 77 % | 74 % | 72 % | 35 C | 440 - | 403 - |
| 166009 | MASTER TL5 Circular 22W/840 1CT | 81 % | 77 % | 74 % | 72 % | 35 C | 380 - | 380 - |

| Product number | Full product name | LLMF HF 8000h Rated | LLMF HF 12000h Rated | LLMF HF 16000h Rated | LLMF HF 20000h Rated | Design Temperature | Chromaticity Coordinate X | Chromaticity Coordinate Y |
|----------------|---------------------------------|---------------------|----------------------|----------------------|----------------------|--------------------|---------------------------|---------------------------|
| 165936 | MASTER TL5 Circular 55W/830 1CT | 81 % | 77 % | 74 % | 72 % | 35 C | 440 - | 403 - |
| 165928 | MASTER TL5 Circular 55W/840 1CT | 81 % | 77 % | 74 % | 72 % | 35 C | 380 - | 380 - |

Electrical Characteristics

| Product number | Full product name | Watts | Lamp Wattage EL 25°C, Rated | Lamp Wattage EL 25°C, Nominal | Lamp Voltage EL 25°C | Lamp Current EL 25°C | Dimmable |
|----------------|---------------------------------|-------|-----------------------------|-------------------------------|----------------------|----------------------|----------|
| 166017 | MASTER TL5 Circular 22W/830 1CT | 22 W | 22.3 W | 22 W | 75 V | 0.300 A | Yes |
| 166009 | MASTER TL5 Circular 22W/840 1CT | 22 W | 22.3 W | 22 W | 75 V | 0.300 A | Yes |
| 165936 | MASTER TL5 Circular 55W/830 1CT | 55 W | 55.0 W | 55 W | 101 V | 0.550 A | Yes |
| 165928 | MASTER TL5 Circular 55W/840 1CT | 55 W | 55.0 W | 55 W | 101 V | 0.550 A | Yes |

 
Performance diagrams



MASTER TL5 Circular


Life Expectancy 3 h

cycle

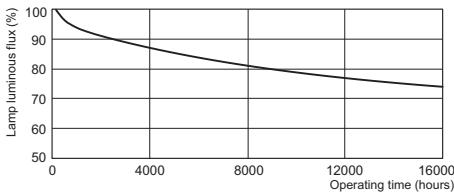

MASTER TL5 Circular Lumen Maintenance 3 h + 12

h cycle

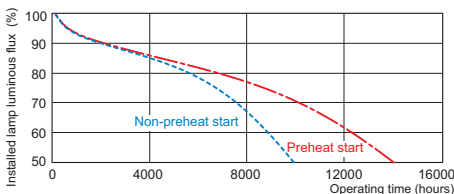

MASTER TL5 Circular Service Lifetime 3 h cycle

Environmental Characteristics

| Product number | Full product name | Energy Efficiency Label (EEL) | Mercury (Hg) Content | Energy consumption kWh/1000h |
|----------------|---------------------------------|-------------------------------|----------------------|------------------------------|
| 166017 | MASTER TL5 Circular 22W/830 1CT | A | 2.5 mg | 25 kWh |
| 166009 | MASTER TL5 Circular 22W/840 1CT | A | 2.5 mg | 25 kWh |

| Product number | Full product name | Energy Efficiency Label (EEL) | Mercury (Hg) Content | Energy consumption kWh/1000h |
|----------------|---------------------------------|-------------------------------|----------------------|------------------------------|
| 165936 | MASTER TL5 Circular 55W/830 1CT | A | 2.5 mg | 61 kWh |
| 165928 | MASTER TL5 Circular 55W/840 1CT | A | 2.5 mg | 61 kWh |

Measuring Conditions

| Product number | Full product name | Calibration Current | HF Generator Rated Voltage | Resistor |
|----------------|------------------------------------|---------------------|----------------------------|----------|
| 166017 | MASTER TL5 Circular 22W/830 1CT | 0.300 A | 150 V | 250 ohm |
| 166009 | MASTER TL5 Circular 22W/840 1CT | 0.300 A | 150 V | 250 ohm |

| Product number | Full product name | Calibration Current | HF Generator Rated Voltage | Resistor |
|----------------|------------------------------------|---------------------|----------------------------|----------|
| 165936 | MASTER TL5 Circular 55W/830 1CT | 0.550 A | 202 V | 185 ohm |
| 165928 | MASTER TL5 Circular 55W/840 1CT | 0.550 A | 202 V | 185 ohm |



© 2013 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2013, August 28
data subject to change