


Classic Mini Wallpack LED Series

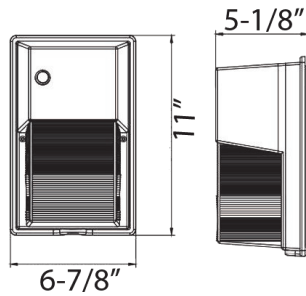


Lower Pricing Higher Lumens!

- ▶ Phillips LUMILED LUXEON 3030 LEDs
- ▶ TOWIN Driver
- ▶ 71418, 71419, 71422 & 71423 include 120 Volt Photocell (Can only operate on 120 Volt)
- ▶ 71420 & 71421 do not include Photocell
- ▶ Photo control can be installed on fixture if needed
- ▶ Polycarbonate Housing - Bronze or White
- ▶ Polycarbonate Lens
- ▶ Die Cast Aluminum Mounting Plate
- ▶ Stainless Steel Hardware
- ▶ Voltage: 120/208/240/277VAC
- ▶ Color Temperature: 5000K
- ▶ CRI: 80+
- ▶ Light Pattern: 180° Beam Angle
- ▶ Operation Temperature: -40°F to 131°F
- ▶ 50,000+ Hour LED Life Expectancy
- ▶ 1 Bottom Threaded Aperture, 1 Back Wiring Knockout
- ▶ Weight: 5 Lbs
- ▶ IP65 (NEMA 4X) Dust & Water Tight
- ▶ cULus listed for Wet Locations
- ▶ 5 Year Warranty

Cat. No.	Photocell	Watts	Housing Color	Color Temp	Delivered Lumens	Replaces Metal Halide	Voltage	Case Qty
Traditional Square Lens - No Photocell								
71420	No	20	Bronze	5000K	1500	70W	120-277	6
71421	No	30	Bronze	5000K	3000	100W	120-277	6

Cat. No.	Photocell	Watts	Housing Color	Color Temp	Delivered Lumens	Replaces Metal Halide	Voltage	Case Qty
Traditional Square Lens - Photocell Included								
71422	Yes	20	Bronze	5000K	1500	70W	120-277	6
71418	Yes	20	White	5000K	1500	70W	120-277	6
71423	Yes	30	Bronze	5000K	3000	100W	120-277	6
71419	Yes	30	White	5000K	3000	100W	120-277	6

Designer Mini Wallpack LED Series

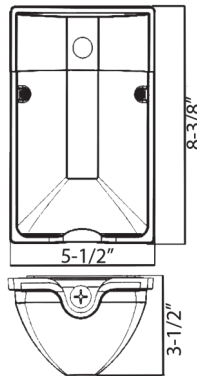

Lower Pricing

DLC LISTED

UL LISTED

- ▶ Phillips LUMILED LUXEON 3030 LEDs
- ▶ Fixture includes 120 Volt Photocell (Can only operate on 120 Volt)
- ▶ Die Cast Aluminum Housing & Mounting Plate
- ▶ Color: Bronze or White
- ▶ Polycarbonate Lens
- ▶ Stainless Steel Hardware
- ▶ Voltage: 120V AC
- ▶ Color Temperature: 5000K Cool White & 4000K Neutral
- ▶ CRI: 80
- ▶ Light Pattern: 180° Beam Angle
- ▶ Power Factor: .99
- ▶ Operation Temperature: -40°F to 131°F
- ▶ 50,000+ Hour LED Life Expectancy
- ▶ 1 Bottom Threaded Aperture, 1 Back Wiring Knockout
- ▶ Weight: 5 Lbs
- ▶ IP54 (NEMA 3) Dust & Water Tight
- ▶ cULus listed for Wet Locations
- ▶ 5 Year Warranty

Cat. No.	Photocell	Watts	Housing Color	Color Temp	Delivered Lumens	Replaces Metal Halide	Voltage	Case Qty
Designer Curved Lens - Photocell Included								
71521	Yes	17	Bronze	4000K	1684	70W	120	12
71522	Yes	17	White	4000K	1684	70W	120	12
71523	Yes	17	Bronze	5000K	1752	70W	120	12
71524	Yes	17	White	5000K	1752	70W	120	12
71525	Yes	25	Bronze	4000K	2126	100W	120	12
71526	Yes	25	White	4000K	2126	100W	120	12
71527	Yes	25	Bronze	5000K	2235	100W	120	12
71528	Yes	25	White	5000K	2235	100W	120	12