

EMT Conduit Bodies with Cover and Gasket

Set Screw T Type

Features

- Set screw T type with cover and gasket
- Suitable for use in concrete

Applications

- Provides access to conductors for pulling, splicing and maintenance

Standard Material


- Copper free aluminum die cast
- Steel screws
- Cover - Stamped steel
- Gasket - Neoprene rubber

Standard Finish

- Powder coat



UL Standard: 514A
Fed. Spec. W-C-586D
NEMA FB 1

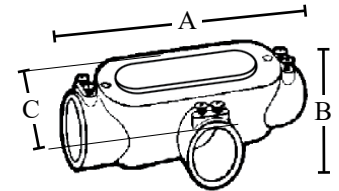

Catalog Number	UPC	Size	Wire Size		Unit Carton	Ship Case	Weight/Case	Inches		
			Max. Number	Max. Size				A	B	C
ET1CG	20691	1/2"	1	6 AWG	10	100	38	4.72	1.37	2.03
ET2CG	20701	3/4"	2	6 AWG	10	50	30	5.57	1.625	2.335
ET3CG	20711	1"	3	6 AWG	5	25	20	6.46	1.90	2.705
ET4CG	20721	1-1/4"	3	2 AWG	2	10	19	8.528	2.77	3.63
ET5CG	20731	1-1/2"	3	2 AWG	2	10	21	8.528	2.77	3.63
ET6CG	20745	2"	3	2/0 AWG	1	5	5	10.831	3.335	3.98
ET7CG	20746	2-1/2"	3	4/0 AWG	---	1	8	13.50	4.06	5.825
ET8CG	20747	3"	3	250 MCM	---	1	8	13.50	4.685	5.825
ET9CG	20748	3-1/2"	3	350 MCM	---	1	11	15.937	5.45	7.06
ET10CG	20749	4"	4	350 MCM	---	1	11	15.937	5.45	7.06