

LZ

Designer Emergency Lighting Unit 15W

EMERGENCY LIGHTING



FEATURES

- Emergency unit for designer commercial applications
- High impact, 5VA flame rated, UV stabilized, white thermoplastic housing
- High-output halogen lamps in adjustable eyeball style (optional LED lamps)
- Maintenance free-sealed lead-calcium battery in 6 VDC with fully automatic charger
- 120/277 60 Hz VAC operation, test switch and LED AC-On indicator light
- Transformer isolation, surge, transient and low voltage disconnect protection
- Reverse polarity, short circuit and AC lockout protection
- Temperature range: 20°C to 30°C (68°F to 86°F), damp: 10°C to 40°C (50°F to 104°F)
- UL 924 Listed (optional damp location listed)
- U.S. Patent Nos. D400,991, D419,708, D400,995, 6,280,042 and 6,019,477

ORDERING INFORMATION

MODEL	CAPACITY	BATTERY TYPE	RATING	OUTPUT VOLTS	SELF DIAGNOSTICS	OPTIONS
LZ	2 10 Watts 15 15 Watts 25 25 Watts ⁹ 30 30 Watts	Blank Lead-Calcium	Blank Standard Model D Damp Location Listing ^{4,5}	Blank 6 Volts	Blank None I Spectron® Self-test/ Self-diagnostic Electronics ²	Blank 5W Halogen lamps V Voltmeter 03L 3W LED Lamps ³ 10W 10-Watt Halogen Lamps ¹ 0 Unit Supplied Without Lampheads ⁶ A31 Auxiliary 3-Conductor Line Cord (120VAC only) ⁸ A21 Auxiliary 3-conductor line cord, 120 VAC only ⁷ B Black

¹ Available on units with capacities of 20 watts or more

² Must order with damp location listing on LZ2 model

³ Not available with LZ21 and LZ15I Spectron® equipped unit

⁴ Not available with -03L (LED) option

⁵ Only available with LZ2 or LZ25

⁶ Available with LZ30 model only

⁷ Available on LZ2 only

⁸ Available on all models except LZ2

⁹ LZ25 must include "D" for damp listing

SPECIFICATIONS

BASE CATALOG NUMBER	ELECTRICAL				
	OUTPUT VOLTS	OUTPUT WATTS		STANDARD LAMP	REMOTE CAPABILITY
		1.5 HOURS	2 HOURS		
LZ2	6	10	--	5W HAL	No
LZ2D	6	10	--	5W HAL	No
LZ15	6	15	12	5W HAL	Yes
LZ25D	6	25	19	5W HAL	Yes
LZ30	6	30	24	5W HAL	Yes


MATCHING INDOOR REMOTE FIXTURES

WHITE SINGLE	BLACK SINGLE	VOLTS	WATTS
LZRSW0605	LZRSB0605	6	5
LZRSW0603L	LZRSB0603L	6	3

For other indoor or outdoor remote fixture styles, see the "Remote Heads and Fixtures" section on page 955.

ACCESSORIES

MODEL	DESCRIPTION
VRS	Vandal resistant shield
VRS-4X	Vandal resistant shield gasketed
WGLZ	Wire Guard for LZ2, LZ15
WGEL	Wire Guard for LZ25D and LZ30
PMLZTW	12½" Pendant mounting kit (white)
PMLZTB	12½" Pendant mounting kit (black)

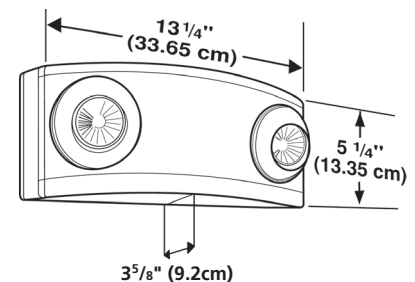

Note:
LZ2, LZ15 dimensions shown
LZ30 housing depth is 5 1/8"

