



# Classic Large Wallpack

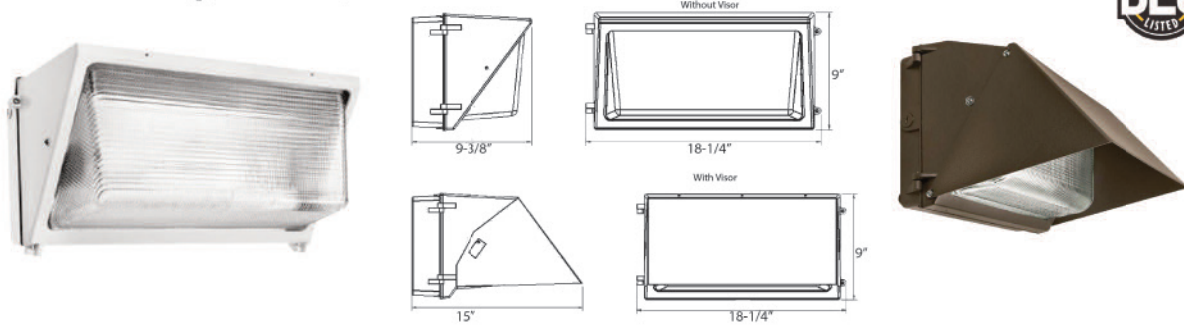

- Lumileds LUXEON 3030 LEDs
- Die Cast Aluminum Housing - Bronze or White Finish
- High Impact Heat Resistant Borosilicate Glass
- 4 Threaded Apertures - (1)Top, (1)Back, (2)Sides
- Stainless Steel Hardware
- Operation Temperature: -40°F to 131°F
- 50,000+ Hour LED Life Expectancy
- Photo Control (not included) Can Be Installed on Fixture
- Light Pattern: 115° Beam Angle
- Voltage: 120/208/240/277VAC
- Color Temperature: 5000K Cool White
- Power Factor: .98
- CRI: 83
- IP54 (NEMA 3) Dust & Water Tight
- cULus listed for Wet Locations
- DLC Listed
- Visor (Order Separately for Full Cutoff Applications)
- 5 Year Warranty

Cat. No.	Old Cat No.	Watts	Volts	Housing Color	Delivered Lumens	Replace Metal Halide	Dimming	Weight (Lbs)	Case Qty
71440A	71440	120	120-277	Bronze	13,520	400W	0-10V/PWM/VR	25	1
71441A	71441	120	120-277	White	13,520	400W	0-10V/PWM/VR	25	1
71442	Full Cutoff Visor Bronze								1
71443	Full Cutoff Visor White								1

# WallPack - Directed Optic Lens

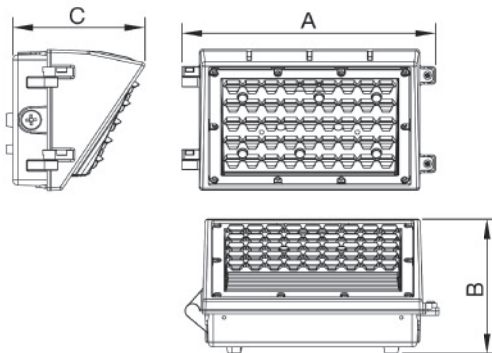

- High Impact Polycarbonate Directed Optics Lens
- Lumileds LUXEON 3030 LEDs
- Die Cast Aluminum Housing - Bronze Finish
- 4 Threaded Apertures - (1)Top, (1)Back, (2)Sides
- Stainless Steel Hardware
- Light Pattern: 107° Beam Angle
- Color Temperature: 5000K
- CRI: >77
- 0-10V Dimmable
- Input Voltage: 120/208/240/277 Volts
- Operation Temperature: -40°F to 131°F
- Photo Control (not included) Can be Installed on Fixture
- 50,000+ Hour Life Expectancy
- 5 Year Warranty

Cat. No.	Watts	Volts	Housing Color	Delivered Lumens	Replace Metal Halide	Dimming	Dimensions (Inches)			Weight (Lbs)	Case Qty
							A	B	C		

## Directed Optics Wall Packs

71444	28	120-277	Bronze	3,460	100W	0-10V/PWM/VR	10	5-7/16	5-1/8	15	4
71445	48	120-277	Bronze	6,595	150W	0-10V/PWM/VR	14-1/4	9-1/4	7-1/2	15	1
71446	75	120-277	Bronze	9,978	250W	0-10V/PWM/VR	14-1/4	9-1/4	7-1/2	15	1
71447	120	120-277	Bronze	15,000	400W	0-10V/PWM/VR	18-1/2	8-5/8	9-1/8	15	1