


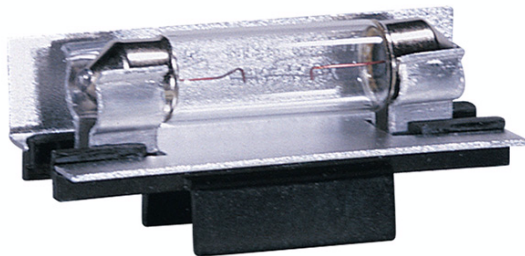

9830-12: Lx Festoon Accent Task Lampholder



Dimensions:

Length:	2"
Width:	3/4"
Height:	13/16"

Bulbs:

- 1 - Xenon Festoon T3 5w Max. 12v - Not included
- 1 - Xenon Festoon T3 10w Max. 12v - Not included
- 1 - Xenon Festoon T3 5w Max. 24v - Not included
- 1 - Xenon Festoon T3 10w Max. 24v - Not included
- 1 - Xenon Festoon T3 7w Max. 24v - Not included
- 1 - LED Festoon T3 0.708w Max. 12v - Not included
- 1 - LED Festoon T3 0.708w Max. 24v - Not included
- 1 - LED Festoon T3 0.633w Max. 12v - Not included
- 1 - LED Festoon T3 0.633w Max. 24v - Not included
- 1 - LED Festoon T3 0.661w Max. 12v - Not included
- 1 - LED Festoon T3 0.661w Max. 24v - Not included

Material List:

- 1 Body - Polycarbonate - Black
- 1 Reflector - Aluminum - Satin Aluminum

Collection: Lx Festoon Lampholders

For use with our highly specified LED and Xenon festoon lamps. Ambiance Lx Festoon Lampholders feature a high quality reflector and base for directing light the way you need it. This accent task socket has an L shape design that provides illumination for general applications that require crisp linear lighting including cabinets, coves and showcases. Snap your lampholder onto Lx track and cable with ease and space to your design criteria and lamp source. Lamp source, track and cable sold separately. Recommended Minimum Spacing: Two inches on center with xenon, four inches on center with LED.

UPC #:785652983023

Finish: Black (12)

Safety Listing:

- cETL Listed for Damp Locations
- C-UL-US Listed for Damp Locations

Instruction Sheets:

- English (HC-662)

Replacement Bulb Data:

Product #			Type	Base	Watts	Watts Consumed	Volts	Hours	Lumens	Temp (°K)	CRI
97118-32	Clear Glass Lens	Xenon	T3	Festoon	5	4.2	12v	16000	33	2550	90
97118-33	Frosted Glass Lens	Xenon	T3	Festoon	5	4.2	12v	16000	33	2550	90
97119-32	Clear Glass Lens	Xenon	T3	Festoon	10	8.4	12v	12000	83	2650	90
97119-33	Frosted Glass Lens	Xenon	T3	Festoon	10	8.4	12v	12000	83	2650	90
97120-32	Clear Glass Lens	Xenon	T3	Festoon	5	4.2	24v	16000	33	2550	90

97121-32	Clear Glass Lens	Xenon	T3	Festoon	10	8.4	24v	12000	83	2650	90
97122-33	Frosted Glass Lens	Xenon	T3	Festoon	7	6.7	24v	95000	46	2420	90
96116S-32	Clear Glass Lens		T3	Festoon	0.708	0.708	12v	35000	29	2700	90
96117S-32	Clear Glass Lens		T3	Festoon	0.708	0.708	24v	35000	29	2700	90
96118S-32	Clear Glass Lens		T3	Festoon	0.633	0.633	12v	35000	25	3000	90
96120S-32	Clear Glass Lens		T3	Festoon	0.633	0.633	24v	35000	25	3000	90
96119S-32	Clear Glass Lens		T3	Festoon	0.661	0.661	12v	35000	26	4000	85
96121S-32	Clear Glass Lens		T3	Festoon	0.661	0.661	24v	35000	26	4000	85

Shipping Information:

Package Type	Product #	Quantity	UPC	Length	Width	Height	Cube	Weight	Fr. Class	UPS Ship
Individual	9830-12	1	785652983023	3.18	3.18	2	0.012	0.01	100	Yes
Master Pack		50	10785652983020	5.25	5.25	6.63	0.106	0.5	100	Yes
Shipping Master		1000	20785652983027	30.58	13.25	13.38	3.137	27.5	100	Yes
NJ Pallet		20000		48	40	72	80	616		No
NV Pallet		21000		48	40	52	57.778	420		No