

## Rigid Non-Metallic Conduit Bodies & Covers

### T&B Catalog Number:



**UPC Number:**  
**Status:**  
**Description:**

E984H  
03448106565  
Active

Type LL Conduit Body, Volume 32 Cubic Inches, Size 1-1/2 Inch, Length 7-31/32 Inches, Material PVC, Color Gray, For use with Schedule 40 and 80 Conduit

#### Features

Textured lids  
Foam-in-place gasket

#### Application


For use with Rigid Conduit

#### General

Trade Size (inches)	1-1/2
Material	Non-Metallic
Volume (cu.in.)	32
Conduit Body Shape	LL

#### Dimension Information

C (inches)	1 3/32
H (inches)	2 5/16
L1 (inches)	7 31/32
L2 (inches)	6 13/32
L3 (inches)	6
Q (inches)	2 1/2
W (inches)	2 3/4

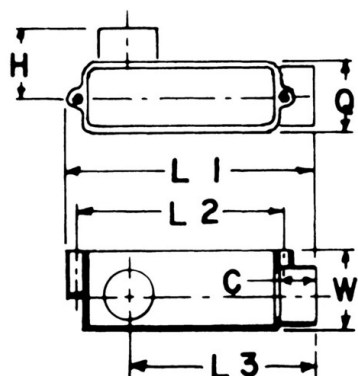

#### Packaging

T&B Order Multiple	10
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	77 lbs. per 100

#### Application Support

T&B Sales Drawings	wsd-ac04834
Rigid Non-metallic Conduit Bodies	Available on Website
Specifications & Applications	Available on Website

#### Certifications

RoHS Compliance	Yes
-----------------	-----

#### Certifications



File Nbr:  
E11461

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com