

Carlon®

Rigid Non-Metallic Conduit Fittings & Accessories T&B Catalog Number:



E977GC

UPC Number:

03448106944

Status:

Active

Description:

Conduit Clamp, Size 1-1/4 Inch, Length 3.28 Inches, Width 0.64 Inches, Height 1.89 Inches, Material PVC, Color Gray, Pack of 50

Features

Non-metallic clamps offer the same chemical resistance as Carlon non-metallic conduits for a complete, corrosion resistant system.

Application

UV inhibited for use in direct sunlight.

General

Trade Size (inches)	1 1/4
Material	Non-Metallic

Dimension Information

A (mm)	43.5
B (mm)	68
E (mm)	3.8
C (mm)	83.3
D (mm)	16.2
F (mm)	21
A (inches)	1.714
B (inches)	2.68
C (inches)	3.28
D (inches)	0.64
E (inches)	0.15
F (inches)	0.83
G (inches)	1.687
H (inches)	1.89
H (mm)	48
J (inches)	0.32
Size (mm)	35

Packaging

T&B Order Multiple	50
Package in Units	50
T&B Sold in UOM	Each
T&B Weight Per UOM	2.5 lbs. per 100


Application Support

T&B Sales Drawings	wsd-ac03405
Specifications & Applications	Available on Website

Notes

To be used in accordance with conduit spacing requirements per NEC, Section 352.30

Certifications

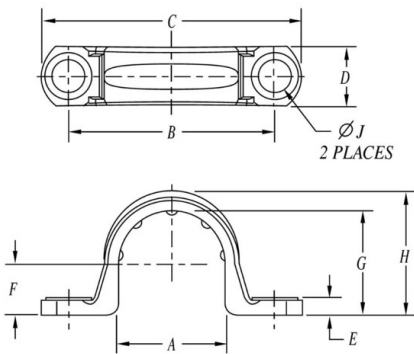

RoHS Compliance

Yes

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com