



Rigid Non-Metallic Conduit Bodies & Covers
T&B Catalog Number:

E986E-CAR

UPC Number:

03448113249

Status:

Active

Description:

Type LB Conduit Body, Volume 12 Cubic Inches, Size 3/4 Inch, Length 5-9/32 Inches, Width 1-3/4 Inches, Material PVC, Color Gray, For use with Schedule 40 and 80 Conduit, Pack of 10

Features

Textured lids

Foam-in-place gasket

Application

For use with Rigid Conduit

General

Trade Size (inches)

3/4

Material

Non-Metallic

Volume (cu.in.)

12

Conduit Body Shape

LB

Dimension Information

C (inches)

29/32

H (inches)

1 25/32

L1 (inches)

6 9/32

L2 (inches)

5 9/32

L3 (inches)

4 25/32

Q (inches)

1 3/4

W (inches)

2 1/32

Packaging

T&B Order Multiple

10

Package in Units

10

T&B Sold in UOM

Each

T&B Weight Per UOM

37.5 lbs. per 100

Application Support

T&B Sales Drawings

wsd-ac05071

Rigid Non-metallic Conduit Bodies

Available on Website

Specifications & Applications

Available on Website

Certifications

RoHS Compliance

Yes


Certifications



File Nbr:

E11461

For further technical assistance, please contact us...

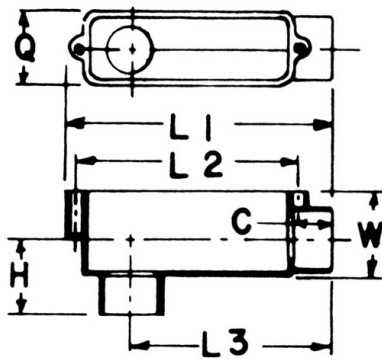

8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com