


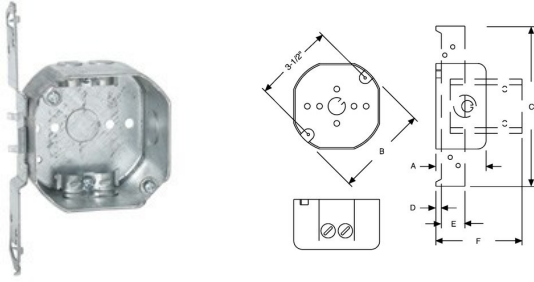

4 IN. OCTAGON DRAWN BOXES WITH NONMETALLIC SHEATHED CABLE CLAMPS

4 in. Octagon Box, 2-1/8 in. Deep - Drawn with Nonmetallic Sheathed Cable Clamps
TS Bracket, 1/2 in. Setback

A41



Catalog #: 177

APPLICATIONS

RACO® Octagon Boxes are used in the installation of ceiling or wall lighting fixtures
N/A

PRODUCT FEATURES

RACO® offers a variety of labor saving mounting brackets that allow for easy positioning of box along studs or joists
Reference the Box Selection section in the front of this catalog for complete description of bracket types and features
Combination screw heads provide for faster installation

UL LISTED

File E195978

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable

RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.: No
Fixture (Static) Lbs.: 50

CONFIGURATION

Cable Prioouts: 4
Bracket Type: TS, for Metal or Wood Studs
Bracket Setback: 1/2 in.
Drawn or Welded: Drawn
Raised Ground: No
Side Knockout(s): (1) 1/2 in.
Bottom Knockouts(s): (1) 1/2 in.

DRAWING DIMENSIONS

Dimension A: 2-1/8 in.
Dimension B: 4 in.
Dimension C: 7 in.
Dimension D: 1/2 in.
Dimension E: 1-1/16 in.

PRODUCT MEASUREMENTS

Depth: 2-1/8 in.
Cubic Inches (cm3): 21.5 (352.3)
Wt. Ea. (Lbs.): 0.796
Product Length (in.): 2.19
Product Width (in.): 7.00
Product Height (in.): 3.88

PACKAGING

Minimum Pack Qty.: 25
Std. Pkg.: 25
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 79.60
Ship Carton Length (in.): 19.00
Ship Carton Width (in.): 9.00
Ship Carton Height (in.): 7.75
Ctn Weight (Lbs.): 19.90
Pallet Qty: 1750
UPC Number: 050169001776
I2of5: 50050169001771