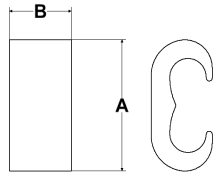



[On Line Catalog](#)


BURNDY Catalog Number
UPC Number
Description
Status

YGHC26C26
 7818102210377
 1-2/0 TO 1-2/0 CU GRD C
 Active

Web Use
 BURNDY Product Line

B Length (in)
 Diameter (in) - Total

Dimensional

0.75
 1.54

General

Product Description

Copper Compression C Connector,
 1 - 2/0 AWG(Str), 3/8" Rod (Run)
 & 1 - 2/0 AWG(Str) (Tap)

Conductor(s)

Copper Tap Range
 Copper Stranded Run (Range)
 Rod Size Run (Range)
 Copper Solid Tap (Range)
 Rebar Run Size (Range)
 Copper Solid Run Size (Range)

1 AWG-2/0 AWG
 1 AWG-2/0 AWG
 3/8 in
 N/A
 N/A
 N/A

Physical

Type of Plating
 Connector Type
 Plated (Yes or No)
 Index Number
 Product Material

Unplated
 Tap
 N
 0
 Copper

Approvals / Certifications

Rated for Direct Burial
 UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards

Y
 Y
 Y
 Compliant
 N
 N
 UL468A-468B,UL467,IEEE 837

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175