

InvisiLED® Pro 2

24V LED Tape Light

WAC LIGHTING

Responsible Lighting®



Tape Section



5 LED "L" Connector

Fixture Type:

Catalog Number:

Project: _____

Location: _____

PRODUCT DESCRIPTION

Professional grade white tape light that delivers optimal color consistency and brightness. An ideal system for task or accent lighting applications.

FEATURES

 
- Ultra thin profile at 1/8"
- Diodes spaced evenly at 1" on center
- Minimum run length of 1'
- May be field cut every 6" at the end of a run
- Specially rated for installation in the storage area of a clothes closet
- 80,000 hour rated life
- 5 year WAC Lighting product warranty

SPECIFICATIONS

- Construction:** Flexible, silicone cased tape light. Peel and stick 3M construction adhesive on back. Indicating marks on back for field cutting.
- Power Supply:** Remote and plug-in electronic Class 2 transformers
120VAC 50/60Hz input, 24V 60W and 96W output
- Light Source:** 12 LEDs per foot
- Dimming:** May be dimmed with electronic low voltage (ELV) dimmer.
- Operating Temp:** -4°F – 122°F (-20°C – 50°C) at relative humidity 95%
- Standards:** CEC Title 24 (See below for list of models)
UL & CUL Listed for damp locations.

ORDER NUMBER – TAPE SECTION

Model	Watts/ft	Color Temp	CRI	Lumens/ft	Title 24	Length	Qty	Tape Color	
LED-TX24	4W/ft	22 2200K	90	275	No	6IN 6 inches	1	WT White	
		27 2700K	90	325	Yes		1 1 foot		1
		30 3000K	90	300	Yes		1-40 1 foot		40
		35 3500K	90	330	Yes		5 5 feet		1
		45 4500K	85	330	No				




LED-TX24___ - ___-WT

Example: LED-TX2445-1-40-WT

ORDER NUMBER – 5 LED "L" CONNECTOR

Model	Watts	Color Temp	CRI	Lumens	Title 24	Tape Color
LED-TX24	2W/ft	22 2200K	90	110	No	5L-WT White
		27 2700K	90	130	Yes	
		30 3000K	90	130	Yes	
		35 3500K	90	135	Yes	
		45 4500K	85	135	No	

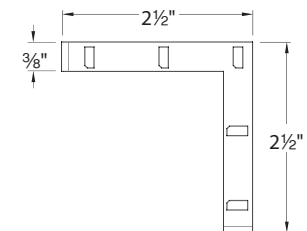

LED-TX24___ -5L-WT

Example: LED-TX2435-5L-WT

waclighting.com

Phone (800) 526.2588

Fax (800) 526.2585

Headquarters/Eastern Distribution Center

44 Harbor Park Drive

Port Washington, NY 11050

Central Distribution Center

1600 Distribution Ct

Lithia Springs, GA 30122

Western Distribution Center

1750 Archibald Avenue

Ontario, CA 91760




InvisiLED® Pro 2

24V LED Tape Light





















WAC LIGHTING

Responsible Lighting®

Class 2 Power Supply (Required)

Type	Model	Input	Output	Max Run	Dim		
Remote		EN-2460-RB2-T	120VAC	24VAC / 60W	15 feet	ELV	<i>Includes a 6 foot lead wire</i>
		EN-24100-RB2-T	120VAC	24VAC / 96W	25 feet	ELV	
Plug-in		EN-2460-P-AR-T	120VAC	24VAC / 60W	15 feet	ELV	<i>Includes a 6 foot lead wire</i>
		EN-24100-P-AR-T	120VAC	24VAC / 96W	25 feet	ELV	
Remote 277V		EN-24100-277-RB2-T	277VAC	24VDC / 96W	25 feet	0-10V	<i>Includes a 6 foot lead wire</i>

Accessories

Aluminum Channel		LED-T-CH	5 feet	<i>Includes a diffuser, two end caps, and five screws</i>				
Deep Aluminum Channel		LED-T-CH1	5 feet	<i>Includes a diffuser, two end caps, and five screws</i>				
45° Angled Aluminum Channel		LED-T-CH2	5 feet	<i>Includes a diffuser, two end caps, and ten screws</i>				
Fixed Angle Channel Clip		LED-T-CL3-PT	5 feet	<i>Used to mount any aluminum channel Includes 2 pieces, 4 screws</i>				
Adjustable Channel Clip		LED-T-CL2-PT	5 feet	<i>Used to mount any aluminum channel Adjusts 50° from center either way Includes 2 pieces, 4 screws</i>				
Retrofit Channel		LED-T-RC	3 feet	<i>Creates fixed curves</i>				
Clip		LED-T-CL	10 pcs	<i>Holds the tape from the underside Includes 10 pieces, 10 screws</i>				
Curve Clip		LED-T-CL1	10 pcs	<i>Runs over the tape to secure the angled tape Includes 2 pieces, 4 screws</i>				
Lead Wire		LED-TC-P-2	Black	2 ft	<i>Alternative lengths for plug-in power supplies</i>			
		LED-TC-P-2-WT	White	2 ft				
		LED-TC-P-12	Black	12 ft				
		LED-TC-P-12-WT	White	12 ft				
Extension Cable		LED-TC-EXT-144	Black	12 ft	<i>Extends distance between a hard wired power supply or wiring box to a tape section</i>			
		LED-TC-EXT-144-WT	White	12 ft				
Low Voltage Wiring Box With Feed		LED-TC-B-2	Black	L: 1½" W: ¾" H: 7/8"	<i>Neatly houses up to two wires with 2" female feed</i>			
		LED-TC-B-2-WT	White					
Low Voltage Wiring Box		LED-T-B	White	L: 1½" W: ¾" H: 7/8"	<i>Neatly houses up to two wires</i>			
Wiring Box With Switch		TB-S	White	L: 6¼" W: 1½" H: 1¼"	<i>Use when spanning a large gap in a system layout without leaving exposed wiring</i>			
Joiner Cable		LED-TC-IC2	Black		LED-TC-IC2-WT	White	2 in	<i>Connects tape sections</i>
		LED-TC-IC6	Black		LED-TC-IC6-WT	White	6 in	
		LED-TC-IC12	Black		LED-TC-IC12-WT	White	12 in	
		LED-TC-IC36	Black		LED-TC-IC36-WT	White	36 in	
		LED-TC-IC72	Black		LED-TC-IC72-WT	White	72 in	
3-Way "Y" Connector		LED-TC-Y LED-TC-Y-WT	Black White	<i>Connects tape sections</i>				
4-Way "X" Connector		LED-TC-X LED-TC-X-WT	Black White	<i>Connects tape sections</i>				
"L" Connector		LED-TC-L LED-TC-L-WT	Black White	<i>Connects tape sections</i>				
End cap		LED-TC-EC LED-TC-EC-WT	Black White	<i>1 cut end cap and 1 male end cap</i>				
Male to male connector		LED-TC-MM	Black	50 Qty				