


Type \_\_\_\_\_

-09 -31  
P8047

Catalog No.	Finish Brushed		Dimensions (Inches)	
	Nickel	Black	A	B
P8047	-09	-31	5	3-1/2

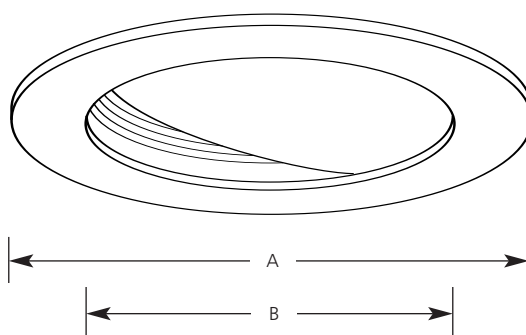

<u>Lamp Wattage</u>		
Housing	IC	Non-IC
P831-AT	40w PAR16,35w R20/PAR20	40w PAR16,35w R20/PAR20
P830-TG	40w PAR16,35w R20/PAR20	40w PAR16,35w R20/PAR20
P832-TG	40w PAR16,35w R20/PAR20	40w PAR16,35w R20/PAR20

**Specifications:**

Flange

- Bright white powdered painted metal flange
- No light leaks around trim flange
- Covers irregular ceiling openings

Labels

- UL-CUL damp location listed

Trim

- Steel construction
- Push-in Leaf Spring installation
- Lamp tilts 20 degrees., 360-degree positioning
- Black internal baffle
- Socket mounts to trim for optimum performance and consistent lamp position
- Bright white powdered painted eyelid



# P8047-31 / P830TG or P831AT or P832TG

## 4" Wall Washer

Report No. 98252

No. Lamps: 1    Type: 30R20    Lumens: 300

Reflectances: 80% Ceil., 50% Wall, 20% Floor

### INITIAL FOOTCANDLE READINGS

#### Two Feet from Wall

Dist. from Ceiling	Two Foot Centers		Three Foot Centers		
	Fixture	Fixture	Fixture	Fixture	Fixture
1	0.5	0.5	0.5	0.5	0.5
2	0.9	0.9	0.8	0.8	0.8
3	1.5	1.5	1.1	1.2	1.1
4	1.5	1.5	1.0	1.1	1.0
5	1.3	1.3	0.9	1.0	0.9
6	1.1	1.1	0.8	0.9	0.8
7	1.0	1.0	0.7	0.8	0.7
8	0.9	0.9	0.6	0.7	0.6
9	0.8	0.8	0.6	0.7	0.6

#### Three Feet from Wall

Dist. from Ceiling	Three Foot Centers			Four Foot Centers		
	Fixture	Fixture	Fixture	Fixture	Fixture	Fixture
1	0.2	0.2	0.2	0.2	0.2	0.2
2	0.3	0.3	0.3	0.3	0.3	0.3
3	0.4	0.5	0.4	0.4	0.4	0.4
4	0.6	0.7	0.6	0.5	0.6	0.5
5	0.7	0.8	0.7	0.6	0.6	0.6
6	0.6	0.8	0.6	0.6	0.6	0.6
7	0.6	0.7	0.6	0.5	0.6	0.5
8	0.6	0.7	0.6	0.5	0.6	0.5
9	0.6	0.7	0.6	0.5	0.6	0.5