

# FIN - model: WP-LED1

## Endurance Wallpack

# WAC LIGHTING

Responsible Lighting®



### PRODUCT DESCRIPTION

Die cast aluminum factory sealed housings with patent pending design for a water and dust proof IP66 rated outdoor luminaire

### FEATURES

- Factory-Sealed LED Light Engine
- 20° Forward Throw Illumination
- Photo/Motion Sensor Compatible (Sold Separately)
- Built-in Level For Easy Adjustment
- Suitable to install in all directions
- Multi-Function Dimming: ELV (120V) or 0-10V
- 85 CRI
- 100,000 hour rated life

### ORDER NUMBER

		Power	Comparable	Color Temp	Delivered Lumens	CBCP	Finish
	<b>WP-LED119</b>	19W	39W HID	30 3000K	1390	1030	<b>aBZ</b> Architectural Bronze <b>aGH</b> Architectural Graphite <b>aWT</b> Architectural White
				50 5000K	1460	1048	
	<b>WP-LED127</b>	27W	70W HID	30 3000K	2075	1461	
				50 5000K	2135	1467	
	<b>WP-LED135</b>	35W	100W HID	30 3000K	2750	1930	
				50 5000K	2825	1921	

-  -

Example: **WP-LED119-50-BZ**

### ACCESSORIES

	Motion Sensor (120V)	<b>MS-120-BZ</b> Bronze <b>MS-120-GY</b> Gray <b>MS-120-WT</b> White
--	----------------------	--

	Photo Sensor (120V)	<b>PC-120-BZ</b> Bronze <b>PC-120-GY</b> Gray <b>PC-120-WT</b> White
--	---------------------	--

Fixture Type:

Catalog Number:

Project: \_\_\_\_\_

Location: \_\_\_\_\_

### SPECIFICATIONS

**Construction:** Die-cast aluminum

**Power:** Integral driver in luminaire. Universal voltage input (120V-277V)

**Dimming:** 100% - 30% with 0 - 10V dimmer (120V - 277V)

100% - 15% with Electronic Low Voltage (ELV) dimmer (120V only)


**Finish:** Architectural Bronze, Graphite, and White

**Standards:** Energy Star®, IP66, Wet Location, ETL & cETL Listed

**Total Harmonic Distortion:** 35%

**Operating Temperature:** -40°C (-40°F) to 40°C (104°F)

### PHOTOMETRY

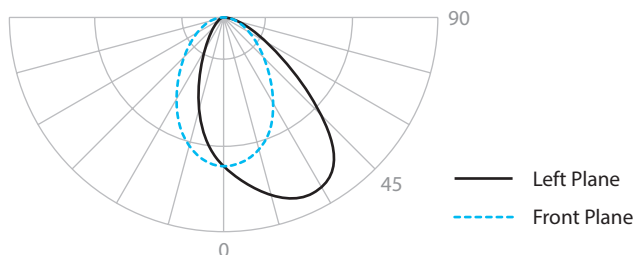

WAC Lighting  
www.waclighting.com  
Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center  
44 Harbor Park Drive • Port Washington, NY 11050  
Phone (516) 515.5000 • Fax (516) 515.5050

Western Distribution Center  
1750 Archibald Avenue • Ontario, CA 91760  
Phone (800) 526.2588 • Fax (800) 526.2585