


PAR30 12.5W DIM. TITANIUM CRI^{SP} LED SERIES 4.0

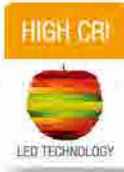

12.5W REPLACES



75W Hal.

80% Energy Savings

CRISP



\$239 Savings per lamp*

- Full-face REFINE optic and sleek design
- Exceptional color rendering CRI 90
- Richer reds and natural skin tones (R9 50, R13 90)
- Tight LED binning for consistent CCT across all lamps
- High efficacy 68 LPW in Warm White
- Suitable for use in totally enclosed fixtures



40,000 H



DIMMABLE



68 LPW EFFICACY



5 YR WARRANTY



CRI (Ra) 90



ENCLOSED**



PATENT PENDING REFINE OPTIC

The innovative REFINE optic provides a high candela to lumen ratio, optimizing light usage for directional applications.



REFLECTOR
Directs light



FOCUS LENS
Focuses center beam

 
SHAPING LENS
Refines beam pattern



WATCH THE VIDEO


ILLUMINANCE & CANDELA DISTRIBUTION

14.5PAR30G4DIM/930SP15




Height	Diameter	Footcandles
3'	0.8	694
6'	1.6	174
9'	2.4	77
12'	3.2	49
15'	3.9	28

12.5PAR30G4DIM/930NF25

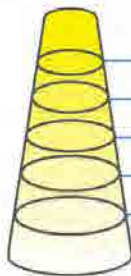


Height	Diameter	Footcandles
3'	1.3	400
6'	2.7	100
9'	4.0	44
12'	5.3	26
15'	6.7	16


12.5PAR30G4DIM/930FL40

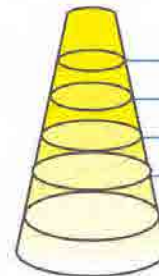


Height	Diameter	Footcandles
3'	2.2	206
6'	4.4	51
9'	6.6	23
12'	8.7	13
15'	10.9	8

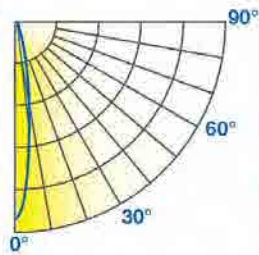

Degree	Candela
0	6250
5	3820
15	936
25	169
35	82
45	46

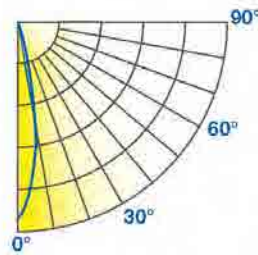


Degree	Candela
0	3600
5	3100
15	1230
25	258
35	74
45	44

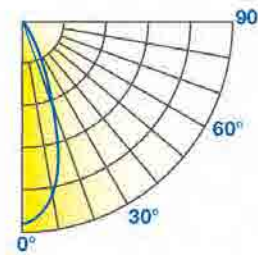

Degree	Candela
0	1850
5	1784
15	1261
25	441
35	121
45	58

For other CCT use the following multipliers: 2700K .95, 4000K 1.08

- Base:** E26
- Voltage:** 120V
- Dimmable:** Yes***
- PF:** 0.9
- Lifetime:** 40,000 hrs
- Weight:** 0.52lb / 236g

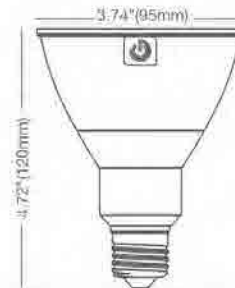

SPECIFICATIONS

Model	Product	Power (W)	CCT	CRI (typ.)	R9° / R13 (typ.)	Lumens	LPW	Beam Angle	CBCP (cd)
14.5PAR30G4DIM/927SP15	16111	14.5	Warm White 2700K	90	50 / 90	725	50	SP 15°	6155
12.5PAR30G4DIM/927NF25	16112	12.5	Warm White 2700K	90	50 / 90	815	65	NF 25°	3350
12.5PAR30G4DIM/927FL40	16113	12.5	Warm White 2700K	90	60 / 90	815	65	FL 40°	1750
14.5PAR30G4DIM/930SP15	16114	14.5	Warm White 3000K	90	50 / 90	760	52	SP 15°	6250
12.5PAR30G4DIM/930NF25	16115	12.5	Warm White 3000K	90	50 / 90	850	68	NF 25°	3600
12.5PAR30G4DIM/930FL40	16116	12.5	Warm White 3000K	90	60 / 90	850	68	FL 40°	1850
12.5PAR30G4DIM/940FL40	16119	12.5	Natural White 4000K	90	50 / 90	900	72	FL 40°	2050
14.5PAR30G4DIM/930SP15/B •	16208	14.5	Warm White 3000K	90	50 / 90	760	52	SP 15°	6250
12.5PAR30G4DIM/930NF25/B •	16209	12.5	Warm White 3000K	90	50 / 90	850	68	NF 25°	3600
12.5PAR30G4DIM/930FL40/B •	16210	12.5	Warm White 3000K	90	60 / 90	850	68	FL 40°	1850

• Black finish

* Savings per lamp based on \$0.11 / kw energy cost, 12 hrs / day lamp usage, \$8 halogen with 1500-hr lifetime, \$28 LED with 40,000-hr lifetime

** Suitable for use in totally enclosed fixtures

*** List of tested dimmer switches available on website

**** Suitable for damp locations. Not for use where directly exposed to weather or water