



# Superstrut<sup>®</sup>

**Metal Channels**

**T&B Catalog Number:**

A1200HS 10SS

**UPC Number:**

61601310024

**Status:**


Active

**Description:**

Channel, 12 Gauge, 1-5/8 Inch x 1-5/8 Inch, Length 10 Feet, Half Slotted Stainless Steel with 9/16 Inch x 1-1/8 Inch Slots on 2 Inch Centers

**Application**

Used to mount, brace, support or connect structural loads in building construction such as pipe or electrical or data wire

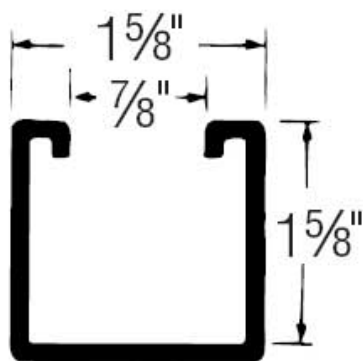

**General**

Material	Stainless Steel
Finish	304 Stainless Steel

**Dimension Information**

Length (feet)	10
Dimensions (inches)	1-5/8 x 1-5/8
Slot Size (inches)	9/16 x 1-1/8
Slot Spacing On Centers (inches)	2
Material Thickness (ga.)	12

**Packaging**

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	500
T&B Sold in UOM	Feet
T&B Weight Per UOM	185 lbs. per 100

**Application Support**

MSDS Number	sds-00046-tb2
Metal Framing Channels-Series 1000	Available on Website
Finishes	Available on Website

**Certifications**

RoHS Compliance	Yes
-----------------	-----

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com