


# Brackenheath ispot® Driverless LED Floodlight

10-50W

IP65

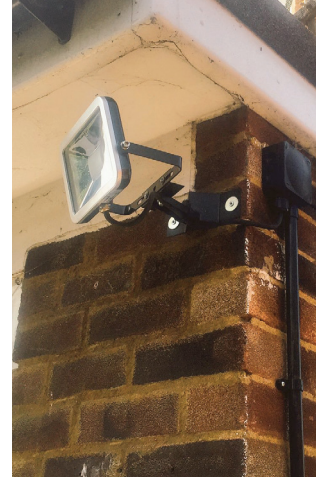

Available Colour:



FEATURES

- Innovative high voltage Nichia LED chips - no driver required
- Energy efficient super bright LED
- Daylight and warm white options
- 100-110° beam angle
- High quality toughened glass with attractive silver bezel
- Smart engineered mounting bracket allows the ispot to be rotated through 360°
- High grade aluminium and steel construction, including hex head bolts for additional security
- Available in black and white finishes
- Complete with mounting bracket and 900mm flex
- Rated life of 36,000 hours
- 230V
- IP65



Exterior

Wattage	Dimensions (mm)	Beam Angle	Lumen Output	Colour Temperature	Finish	Product Code
10W	152x130x25	105°	680lm	5700K	White	I1010W
10W	152x130x25	105°	680lm	5700K	Black	I1010B
10W	152x130x25	105°	640lm	3000K	White	I1011W
10W	152x130x25	105°	640lm	3000K	Black	I1011B
20W	213x180x28	100°	1500lm	5700K	White	I1020W
20W	213x180x28	100°	1500lm	5700K	Black	I1020B
20W	213x180x28	100°	1460lm	3000K	White	I1021W
20W	213x180x28	100°	1460lm	3000K	Black	I1021B
30W	275x265x38	110°	2100lm	5700K	White	I1030W
30W	275x265x38	110°	2100lm	5700K	Black	I1030B
30W	275x265x38	110°	2060lm	3000K	White	I1031W
30W	275x265x38	110°	2060lm	3000K	Black	I1031B
50W	275x265x38	105°	3500lm	5700K	White	I1040W
50W	275x265x38	105°	3500lm	5700K	Black	I1040B
50W	275x265x38	105°	3460lm	3000K	White	I1041W
50W	275x265x38	105°	3460lm	3000K	Black	I1041B

