




Image File Name: F624-WHF.jpg

Item # F624-WHF	UPC Code: 706411054235
Product Family Name: Roto XL	Finish: Flat White
Category: EXTERIOR FAN	Category Type: Ceiling Fan
Certification 4000048	
Patents: U.S. Patent(s): D750,221; Add'l U.S. Patent(s) Pending	
Notes:	

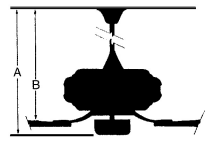

MEASUREMENTS

Blade Finish:					Reversible Blades: No
Blade Material: ABS CONSTRUCTION					Slope: Yes
Blade Sweep: 62"	No. of Blades: 3	Blade Pitch: 20 DEGREES	Hanging Weight: 13.76		
Downrod 1: 6	Downrod 1 Outside Dia: 0.75	Downrod 2: 80	Downrod 2 Outside Dia:		
Ceiling to Lowest Point: (Dim A) 10.25	Ceiling to Blade (Dim B) 8.75	Lead Wire: 80	Motor Size: 172X16MM		
RPM:	Low 65	Low/Med. 136	Medium 0.44	Med/High 0.59	High 188
Amps:	0.22				0.59
Watts:	9.75				70.69
CFM:	2185.0				7567.0
CFM/Watts:	224.1				107.04

LAMPING

No. of Bulbs: 0	Light Type:			
Max Bulb Wattage:	Socket:			
Light Kit: No	Dimmable: No	Ballast:	Rated Life Hours:	Uplight: No
Bulb/LED Included:	Color Temp.:	CRI:	Initial Lumens:	Delivered Lumens:

GLASS

Description:	Material:
Part No.:	Quantity:
Width:	Height:
	Length:



FAN CONTROLS

Pull Chain Control: No	Works with Remote Control: No	Works with Wall Control: Yes
	Included Remote Control:	Included Wall Control: WC115
	Compatible Remote Control(s):	Compatible Wall Control(s):



SHIPPING

Carton Width: 10.0	Carton Height: 7.88	Carton Length: 30.25
Carton Weight: 16.28	Carton Cubic Feet: 1.379	Small Package Shippable: Yes
Master Pack Width:	Master Pack Height:	Master Pack Length:
Master Pack Weight:	Master Cubic Feet:	Multi-Pack: Master Pack: 1



Wet Location



ETL Intertek