

CS220-2GY



UPC Code: 07847781577

Country Of Origin: United States

* Eligible for ARRA funded projects

Made in USA



CS220-2GY

Brand Features

Leviton's Commercial Specification Grade switches are designed to offer outstanding reliability and top performance in commercial settings. Ideal applications include municipal facilities, government buildings, malls, department stores, hospital and health care facilities, office buildings, schools, colleges, universities, houses of worship and cultural institutions. Leviton offers a large selection of 15 and 20 Amp Commercial switches, available in a wide variety of colors, wiring options and other features.

Item Description

20 Amp, 120/277 Volt, Toggle Double-Pole AC Quiet Switch, Commercial Spec Grade, Grounding, Side Wired - GRAY

Technical Information

AC Horsepower Ratings

HP Rating: 1HP-120V 2HP-240V-277V

Electrical Specifications

Dielectric Voltage: Withstands 1500V for 1 minute

Temperature Rise: Maximum 30 degrees C rise

Voltage: 120/277 Volt

Max. Amperage: 16 Amp

Amperage: 20 Amp

Environmental Specifications

Operating Temperature: -40°C to 65°C

Flammability: Rated V-2 per UL94

Material Specifications

Strap Material: Steel

Body Material: Thermoplastic

Contacts: Silver-Cadmium .031 Thick

Terminal Screws: Steel 8-32

Toggle: Polycarbonate

Color: Gray

Cover Material: Nylon

Base Material: PBT

Actuator Material: Thermoplastic

Mechanical Specifications

Product ID: Stamped on Strap

Terminal ID: Brass-Hot, Green-Ground, Silver-Neutral

Termination: Side

Terminal Accom.: 14-12 AWG

Torque Range: 12-14 inch pounds

Product Features

Warranty: 10-Year Limited

Voltage: 120/277 Volt

Color: Gray

HP Rating: 1HP-120V 2HP-240V-277V

Actuator Material: Thermoplastic

Standards and Certifications

CSA C22.2 No. 111: File #152105

Warranty: 10-Year Limited

UL Standard: UL 20


UL Fed Spec WS896E: File #E7458

ANSI: C-73


NOM: 057

NEMA: WD-1 & WD-6

Dimensional Diagram

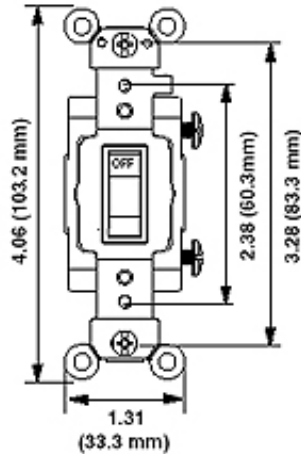

Wiring Diagram Double Pole

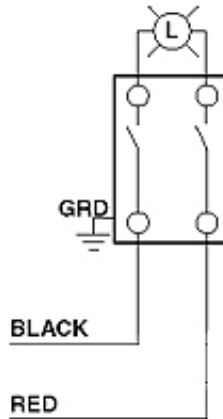

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Teléfono: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): +1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2012 Leviton Manufacturing Co., Inc. Todos los derechos reservados. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts/



**Leviton is the smart choice, providing the most comprehensive range of solutions to meet the needs of today's residential, commercial and industrial buildings. Leveraging more than a century of experience, Leviton helps customers create sustainable, intelligent environments through its electrical wiring devices, network and data center connectivity solutions, and lighting energy management systems. From switches and receptacles, to daylight harvesting controls, networking systems, and equipment for charging electric vehicles, Leviton solutions help customers achieve savings in energy, time and cost, all while enhancing safety.*