

LED PL : DIRECT REPLACEMENT LAMPS

DESCRIPTION

LED PL Replacement Lamps directly replace fluorescent PL lamps at a fraction of the energy cost.

FEATURES


- Plug-and-play installation for 4-pin G24Q and GX24Q bases
- Lasts 5x longer than compact fluorescent lamps
- Consumes up to 1/3 the energy of conventional CFL
- Base rotates for precision orientation once installed in fixture
- Shatter-resistant for reduced risk of injury and breakage
- Instant-on with no warmup, unlike CFLs
- 9W G24Q replaces 18-42W CFL
- Suitable for use in 6" cans
- Non-dimmable
- **Not compatible with all ballasts. See eiko.com for list of tested ballasts**

WARRANTY

- 5 year limited warranty; see eiko.com for warranty details

APPLICATIONS

- Commercial/Residential
- Hotel/Hospitality
- Education
- Healthcare
- Retail
- Property Management

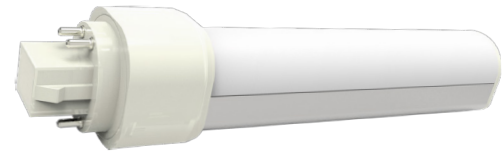

G24Q base
Horizontal



G24Q base
Vertical



PERFORMANCE	Power Consumption	9W
	Lumens	900/950/1,000
	Efficacy (LPW)	100/106/111
	CRI	80+
	Beam	140°
	CCT	2700K, 3000K, 3500K, 4000K
	Life (L70)	50,000 hours
ELECTRICAL	Power Factor	≥0.9
	THD	<20%
	Input Voltage	120-277V
	Operating Temperature	-4°F to 113°F (-20°C to 45°C)
CONSTRUCTION	Base	G24Q; GX24Q
LISTINGS	Certification(s)	cULus Classified; LM70
	Material Usage	RoHS Compliant; no mercury or lead
	Environment	UL/cUL Classified for damp locations; Enclosed fixture rated

PERFORMANCE SUMMARY

Order Code	Item #	Lumens	Watts	CCT	CRI	MOL	Orientation	Base	Beam	Life/Hours	Replaces Fluor
09938	LED9W4PH/827DR-G7	900	9W	2700K	80+	6.65"	Horizontal	G24Q/GX24Q	140°	50K	18-42W CFL
09901	LED9W4PH/830DR-G7	950	9W	3000K	80+	6.65"	Horizontal	G24Q/GX24Q	140°	50K	18-42W CFL
09902	LED9W4PH/835DR-G7	950	9W	3500K	80+	6.65"	Horizontal	G24Q/GX24Q	140°	50K	18-42W CFL
09903	LED9W4PH/840DR-G7	1,000	9W	4000K	80+	6.65"	Horizontal	G24Q/GX24Q	140°	50K	18-42W CFL
09939	LED9W4PV/827DR-G7	900	9W	2700K	80+	4.69"	Vertical	G24Q/GX24Q	140°	50K	18-42W CFL
09940	LED9W4PV/830DR-G7	950	9W	3000K	80+	4.69"	Vertical	G24Q/GX24Q	140°	50K	18-42W CFL
09925	LED9W4PV/835DR-G7	950	9W	3500K	80+	4.69"	Vertical	G24Q/GX24Q	140°	50K	18-42W CFL
09926	LED9W4PV/840DR-G7	1,000	9W	4000K	80+	4.69"	Vertical	G24Q/GX24Q	140°	50K	18-42W CFL

NOTE: Use order code when ordering. Visit eiko.com for complete ballast compatibility information. Not for use with emergency ballasts.

DIMENSIONS

