

FIRST ALERT

# Onelink

SAFE & SOUND

## 3 IN 1 Home Safety & Entertainment Solution



Smoke & Carbon  
Monoxide Alarm



Premium  
Home Speaker



Embedded  
Alexa

Add smart smoke & co protection to the home or residence.



### Intelligent Smoke & CO Protection

Provides notification to homeowners if something is not right in their home (via phone).



### Easy, Breezy Installation

Requires AC power. Interconnects with most existing hardwire alarms without re-wiring with our easy-adapter plug.

\*Wi-Fi not needed for third-party installer.



### Customizable Night Light

Select the color tone and brightness of the device's nightlight. Lights the way at night time.

The ceiling works as an acoustic backdrop for a great sound experience.



### Leverages the Home's Hardwire

Optimal ceiling placement fills the room with immersive, crisp omni-directional audio.



### Audio & Entertainment

Superior sound clarity and quality with optimal acoustic backdrop.



### Play Music

Play favorite songs from Spotify, Pandora, Amazon Music or play from a music library via Bluetooth.

Talk to Amazon Alexa on Safe & Sound.



### Built-in Alexa Voice Services

Full Alexa functionality. No additional hardware required for usage.



### Just Ask

 
Ask to play music, hear the news, check weather, control smart home devices, and more.



### Control

Use hands-free commands or turn privacy mode on through the app.

## Compatibility



CAT **1040931**

# Safe & Sound WiFi Combination Alarm, AVS, 120V Hardwired

## SYSTEM REQUIREMENTS:



### Wireless Network

Required to use a 2.4 GHz wireless connection and a compatible 802.11 b/g/n/ac router.


### Android or iOS Device

Onelink Safe & Sound can be paired with Android 5 or later and with iOS 10 or later.


### Onelink Home App

Search and download the Onelink Home app from the App Store or Google Play.


## PARTS OF THIS ALARM:

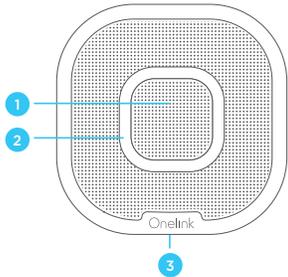

1. Speaker
2. Color Indicator Ring
3. Test / Silence Button  
(on the side of the product)

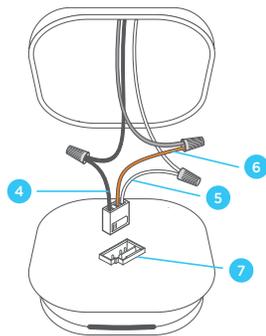

4. Hot (black) AC Wire
5. Neutral (white) AC Wire
6. Interconnect (orange) AC Wire
7. Quick Connect Power Connector

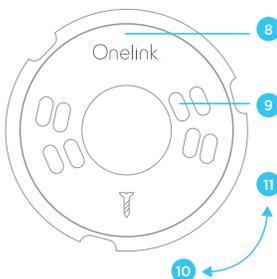

8. Mounting Bracket
9. Mounting Slots
10. Turn Alarm Clockwise on Bracket to Attach
11. Turn Alarm Counter Clockwise to Remove from Bracket

## TECHNICAL SPECIFICATIONS:

Alarm Dimensions:	6.8"L x 6.8"W x 2.26"H
Alarm Weight:	1.50 lbs
Operating Voltage:	120V AC with 10 year lithium battery backup
Power (Standby/Alarm):	.134A
Smoke Sensor:	Photoelectric
CO Sensor:	Electrochemical
Temperature Range:	40° F (4° C) to 100° F (38° C)
Humidity Range:	10% to 95% relative humidity (RH)
Audio Alarm:	85dB at 10 feet
Speaker:	28mm BMR speaker
Voice Output:	Choice of 14 pre-programmed locations
BLE Wireless Frequency:	2.4 GHz. FCC approved. Complies with Part 15 of the FCC rules.
Wi-Fi:	IEEE 802.11 b/g/n Radio/WLAN
Test/Silence:	Electronically simulates smoke and/or CO conditions causing the unit to alarm. Press and hold test/silence button.
Alarm Reset:	Automatic when smoke and/or CO clears.
Interconnections:	Interconnects with a maximum of 12 BRK/First Alert compatible hardwired alarms or devices.
Warranty:	3 Years
Agency Model:	1039102
Listing:	ETL to UL217 and UL2034 Standards Replace alarm 120 months after installation



## SHIPPING SPECS:

Individual Carton Dimensions:	3.3" L x 8.2" W x 8.0"H
Weight:	1.76 lbs
Cube:	.13 ft <sup>3</sup>
UPC:	0 29054 01941 7

Master Carton Dimensions:	7.25" L x 8.88" W x 9.63"D
Master Pack Qty:	2
Weight:	3.7 lbs
Cube:	0.36 ft <sup>3</sup>
I2of5:	100 29054 01941 7

Pallet Information:	
Cases per Layer:	29
Number of Layers:	4
Cases per Pallet:	116
Units per Pallet:	132
Cube:	48.7 ft <sup>3</sup>
Weight:	486 lbs.



©2018 BRK Brands, Inc. All rights reserved. Distributed by BRK Brands, Inc. 3901 Liberty Street, Aurora, Illinois 60504. BRK Brands, Inc. is a subsidiary of Newell Brands Inc. (NYSE:NWL). BRK is a registered trademark of BRK Brands, Inc.

[www.brkelectronics.com/onelink](http://www.brkelectronics.com/onelink)