



A-Shape LED

8A19/LED/850/ND 120V 2PK/4

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal Lifetime (Nom)	10950 h
Switching Cycle	50000X
Technical Type	8-60W
Light Technical	
Color Code	850 [CCT of 5000K]
Luminous Flux (Nom)	800 lm
Luminous Flux (Rated) (Nom)	800 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	100 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	8 W
Lamp Current (Nom)	115 mA
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5

Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	100 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Frosted
Approval and Application	
Suitable For Accent Lighting	No
Energy Consumption kWh/1000 h	8 kWh
Product Data	
Order product name	8A19/LED/850/ND 120V 2PK/4
EAN/UPC - Product	50046677462166
Order code	929001135234
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001135234
Net Weight (Piece)	0.052 kg

A-Shape LED



Dimensional drawing

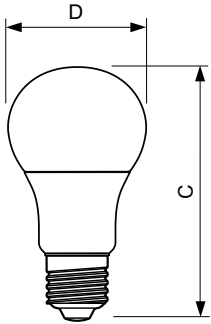

Bulb A19 120V 8W-60W 150D 5000K E26 ND

Product	D	C
8A19/LED/850/ND 120V 2PK/4	61.0 mm	107.4 mm

Photometric data

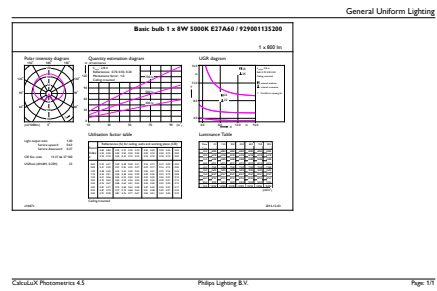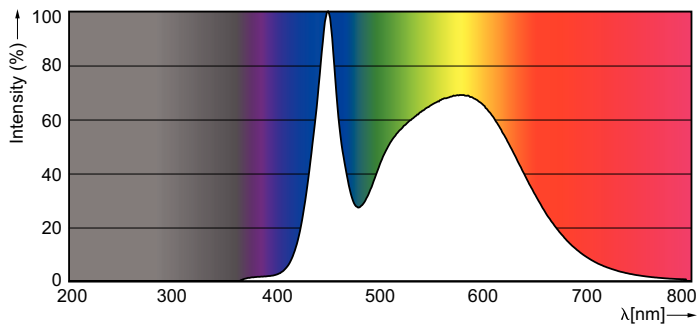

LEDbulb, Bulb A19 8W-60W 5000K 800lm

