

Project:

Type:

Prepared By:

Date:



UPC: 19813748733



Features and Benefits

- PREMIUM DECORATIVE BULB REPLACEMENT - Replaces conventional decorative lamps
- ENERGY SAVINGS - Save up to 85% on energy
- 90 CRI - Produces rich and vibrant colors
- 15,000-HOUR LIFESPAN - Lasts up to 13.7 years at 3 hours per day
- DAMP RATED - Suitable for damp locations
- ENCLOSED FIXTURE RATED - May be used in both enclosed and open fixtures
- FROSTED GLASS - Simulate the appearance of conventional lamps
- 360° LIGHT OUTPUT - Well suited for decorative lighting applications
- DIMMABLE - Compatible with many commonly available dimmers.

Technical Specifications

Product Type	Decorative
Bulb Shape	G25
Finish	Frosted
Wattage	3W
Wattage Equivalency	40W Incandescent
Typical Lumen Output	350
Efficacy	92 lm/W
Color Temperature	2700K Soft White
CRI	90
Base Type	E26
L70 Lifespan	15,000 hours
Operating Temperature	-20°C - 45°C
Dimmable	Yes, down to 10%
Beam Angle	360°
Warranty	3-Year, No-Compromise Warranty
For Use in Emergency Fixtures	No
For Use Outdoors in Open Fixtures	No


Electrical Characteristics

Input Voltage	120V
Power Factor	0.7
Flicker	<30%

Listings

ETL Qualified	Yes
ENERGY STAR V2.0	This product is ENERGY STAR® Version 2.0 Certified
Energy Star ID	2330365
CEC Status	Lawful for sale in California

Light Distribution

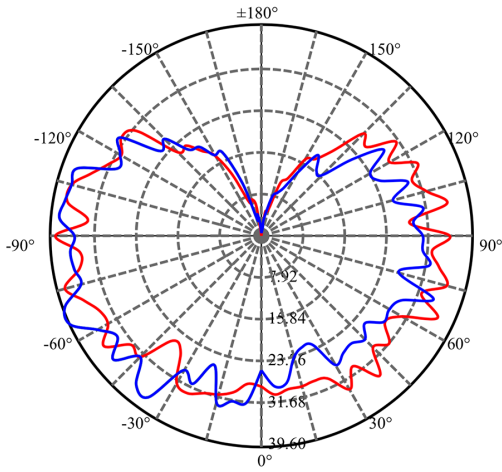

Case and Pallet Dimensions

	QTY	LENGTH	WIDTH	HEIGHT
CASE	6	10.4	7	5.7
PALLET	528	42.5	38.5	39.5

Dimension

