

Project:

Type:

Prepared By:

Date:



UPC: 19813749617



Features and Benefits

- PAR REPLACEMENT - Replaces conventional PAR lamps
- ENERGY SAVINGS - Save up to 85% on energy
- DAMP RATED - Suitable for damp locations
- ENCLOSED FIXTURE RATED - May be used in enclosed and open fixtures
- DIMMABLE - Compatible with most common dimmer models
- SHATTERPROOF - Plastic lamps for rugged applications
- 90 CRI - Produces rich and vibrant colors

Technical Specifications

Product Type	PAR
Bulb Shape	PAR30L
Wattage	11W
Wattage Equivalency	75W Halogen
Typical Lumen Output	900
Efficacy	82 lm/W
Color Temperature	2700K Soft White
CRI	90
Base Type	E26
L70 Lifespan	40,000 hours
Operating Temperature	-20°C - 40°C
Dimmable	Yes, down to 10%
Beam Angle	35°
Warranty	5-Year, No-Compromise Warranty
For Use in Emergency Fixtures	No
For Use Outdoors in Open Fixtures	No


Electrical Characteristics

Input Voltage	120V
Power Factor	0.9
Flicker	<30%

Listings

UL Listed	Yes
ENERGY STAR V2.0	This product is ENERGY STAR® Version 2.0 Certified
Energy Star ID	2328351
CEC Status	Lawful for sale in California

Light Distribution

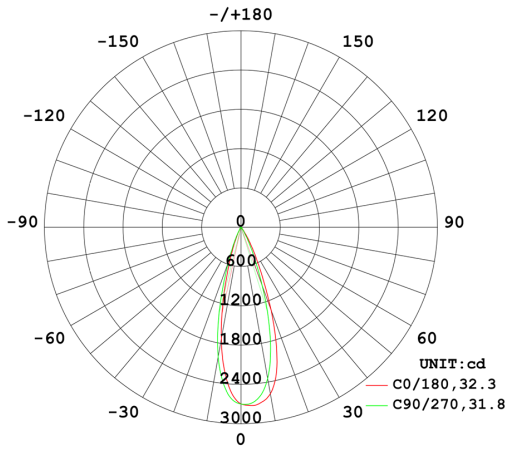

Case and Pallet Dimensions

	QTY	LENGTH	WIDTH	HEIGHT
CASE	6	12.4	8.3	7.1
PALLET	576	45.5	37.2	35.4

Dimension

