

Project:

Type:

Prepared By:

Date:



UPC: 19813748313



Features and Benefits

- REPLACE conventional halogen and incandescent bulbs
- ENERGY SAVINGS - Save up to 85% on energy
- DAMP RATED - Suitable for damp locations
- 15,000-HOUR LIFESPAN - Last up to 13.7 years at 3 hours per day
- ENCLOSED FIXTURE RATED - May be used in both enclosed and open fixtures
- SHATTERPROOF - Plastic lamps for rugged applications
- 80 CRI - Ideal for general lighting applications
- DIMMABLE - Compatible with most common dimmer models

Technical Specifications

Product Type	A-Line
Bulb Shape	A19
Wattage	13W
Wattage Equivalency	75W Incandescent
Typical Lumen Output	1100
Efficacy	80 lm/W
Color Temperature	3000K Warm White
CRI	80
Base Type	E26
L70 Lifespan	15,000 hours
Operating Temperature	-20°C - 45°C
Dimmable	Yes, down to 10%
Beam Angle	230°
Warranty	3-Year, No-Compromise Warranty
For Use in Emergency Fixtures	No
For Use Outdoors in Open Fixtures	No


Electrical Characteristics

Input Voltage	120V
Power Factor	≥0.7
Operating Frequency	60 Hz
Input Current @ 120V	183mA

Listings

UL Listed	Yes
ENERGY STAR V2.0	This product is ENERGY STAR® Version 2.0 Certified
Energy Star ID	2329694
CEC Status	Not lawful for sale in California

Light Distribution

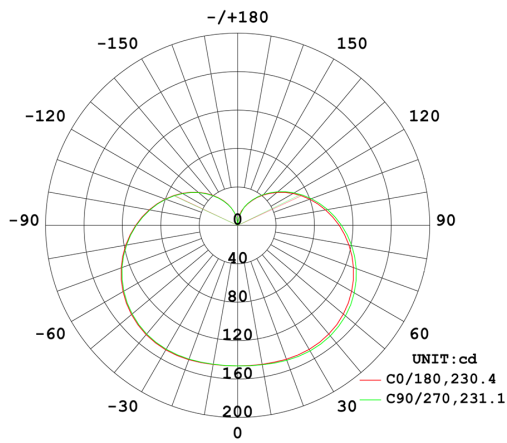

Case and Pallet Dimensions

	QTY	LENGTH	WIDTH	HEIGHT
CASE	12	15.4	5.2	4.9
PALLET	2016	47.2	39.4	45.7

Dimension

