

# LED B11

## 3.3B11/PER/927-922/CL/G/E26/WGX1FB T20

Philips LED B11 candles offer energy saving ambiance with the elegant effect of incandescent candles. These designs provides light in an omnidirectional manner, giving lighting designers a long life alternative to standard incandescent sources.


### Product data

General Information	
Base	E26 [ Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	3.3-40W
Light Technical	
Color Code	927-922 [ CCT of 2700K-2200K]
Initial lumen (Nom)	300 lm
Color Designation	Warm Glow(WG)
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Power (Rated) (Nom)	3.3 W
Lamp Current (Nom)	35 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s

Power Factor (Nom)	0.75
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	50 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Clear
Product Data	
Order product name	3.3B11/PER/927-922/CL/G/E26/WGX1FB T20
EAN/UPC - Product	046677549589
Order code	549584
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929002047204
Net Weight (Piece)	0.016 kg

# LED B11



## Dimensional drawing

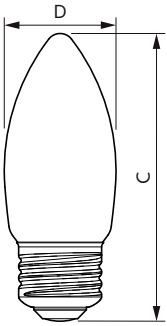

Candle B11 120V 4.5?-40W 300lm 2700-2200

Product	D	C
3.3B11/PER/927-922/CL/G/E26/WGX1FB T20	35 mm	92 mm


## Photometric data

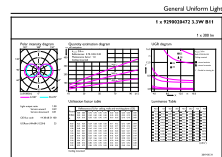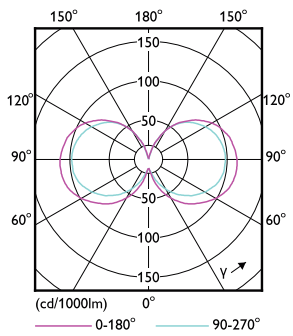

©2020 Philips Lighting B.V. Philips Lighting B.V. Page 1/1

LEDbulb E12 E26 BA11 B11 927 CL-LDD


LEDbulb 3.3W E26 B11 927 CL

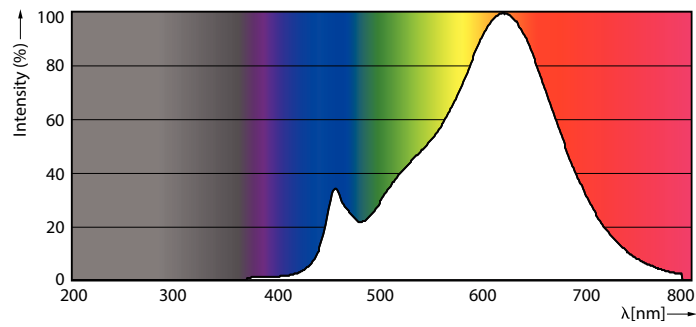

LEDbulb 927 CL-POC

# LED B11

## Lifetime

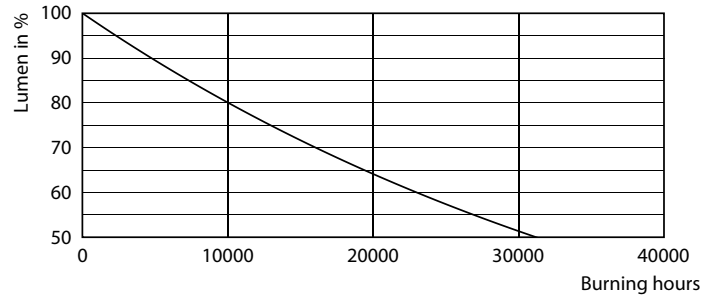

15K LED

15K LMP

