



Low Pressure Sodium - SOX

SOX 35W BY22d 1SL/12

High energy efficiency low pressure sodium lamps for indoor and outdoor applications.

Product data

General Information	
Cap-Base	BY22D [BY22d]
Operating Position	H110 [Hanging +/-110D or Base Up (BU)]
Life To 5% Failures (Nom)	6000 h
Life To 20% Failures (Nom)	12000 h
Life To 50% Failures (Nom)	18000 h
ANSI Code HID	L70
Light Technical	
Luminous Flux (Rated) (Nom)	4550 lm
Lumen Maintenance 2000 h (Nom)	95 %
Lumen Maintenance 5000 h (Nom)	90 %
Correlated Color Temperature (Nom)	1800 K
Luminous Efficacy (rated) (Nom)	129 lm/W
Operating and Electrical	
Power (Rated) (Nom)	37 W
Lamp Current (Nom)	0.53 A
Voltage (Nom)	70 V
Controls and Dimming	
Dimmable	No


Approval and Application	
Energy Efficiency Label (EEL)	A+
Mercury (Hg) Content (Nom)	0 mg
Energy Consumption kWh/1000 h	40 kWh

Luminaire Design Requirements	
Bulb Temperature (Max)	150 °C
Cap-Base Temperature (Max)	150 °C

Product Data	
Order product name	SOX 35W BY22d 1SL/12
EAN/UPC - Product	8711500179739
Order code	928145500028
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	928145500028
Net Weight (Piece)	0.217 kg
ILCOS Code	LS-35-BY22d

Low Pressure Sodium - SOX

Dimensional drawing

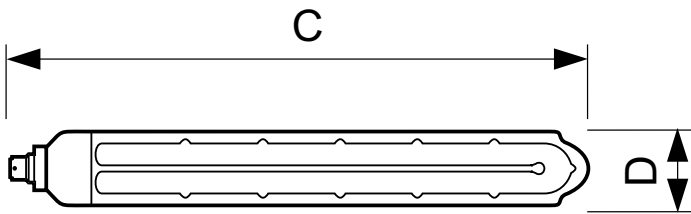

Product	D (max)	C (max)
SOX 35W BY22d 1SL/12	52 mm	311 mm

SOX 35W BY22d T50

