


SPECIFICATIONS/DATA

12" x 12" PX Style (Nestable) Assembly

Covers (Blank unless logo is specified)

DESCRIPTION	PART NO.	WEIGHT #	DESIGN/TEST LOAD #	ANSI TIER*
Ⓜ W/2 Bolts	PC1212CA00	12 (5.4 kg)	8,000 / 12,000	8
Ⓜ Gasketed w/4 Bolts	PC1212CG00	12 (5.4 kg)	8,000 / 12,000	8
Ⓜ No Bolts	PC1212WA00	12 (5.4 kg)	8,000 / 12,000	8
Ⓜ Heavy Duty w/2 Bolts	PC1212HA00	12 (5.4 kg)	15,000 / 22,500	15
Ⓜ Gasketed Heavy Duty w/4 Bolts	PC1212HG00	12 (5.4 kg)	15,000 / 22,500	15

* Gasketed covers and bolt grommets must be used with a gasketed box. Gaskets reduce the inflow of fluids but do not make the enclosure water tight.

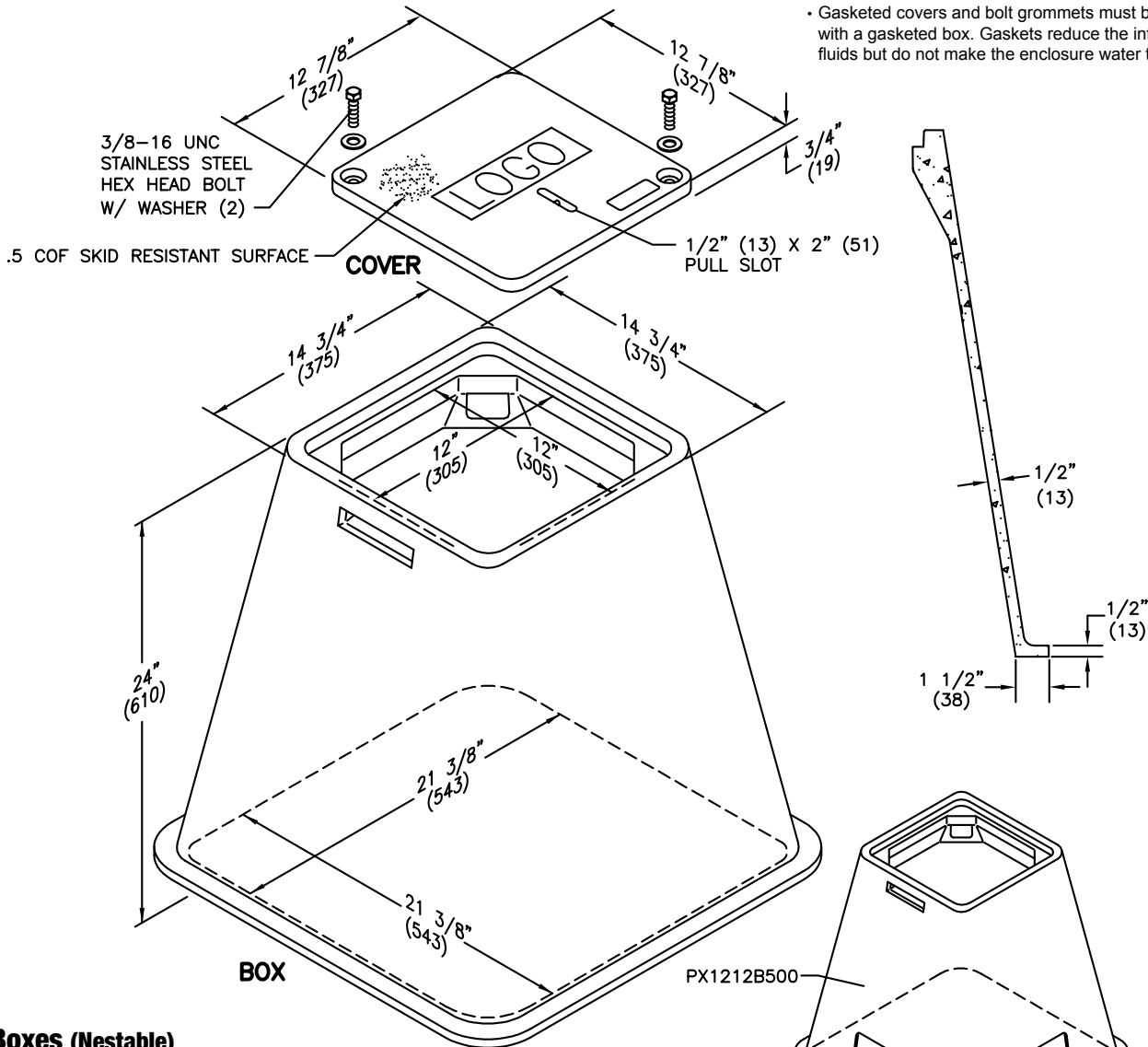

ENCLOSURE DRAWINGS

Boxes (Nestable)

DESCRIPTION	PART NO.	WEIGHT #	DESIGN/TEST LOAD #	ANSI TIER*
Open Bottom	PX1212BA24	85 (39 kg)	15,000 / 22,500	15
Open Bottom w/Gasket	PX1212BG24	85 (39 kg)	15,000 / 22,500	15
Open Bottom w/Knockouts	PX1212B500	84 (38 kg)	15,000 / 22,500	15

Dimensions & weights in parentheses are metric equivalent.
 * Loadings comply with ANSI/SCTE 77 (see page 9).

